

EM2791 Series EuroMag Terminal Blocks

Screwless; 10.16 Centers

SPECIFICATIONS

Rating: 10A, 300V

Center Spacing: 0.40" (10.16mm)

Wire Range: #14-24 AWG

Housing Material: UL rated 94V0 Thermoplastic


Contact Material: Tin-Plated Brass

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

Recommended PCB Hole Diameters: 0.051" (1.30mm)

Construction: Mold-to-Length


Agency Information: UL File E62622; CE Certified

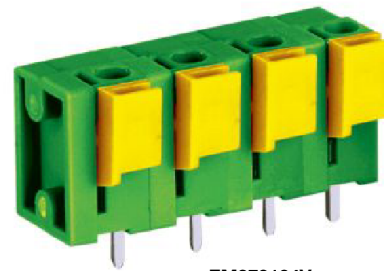


EM279104V

Dimensions - mm (in)

VERTICAL

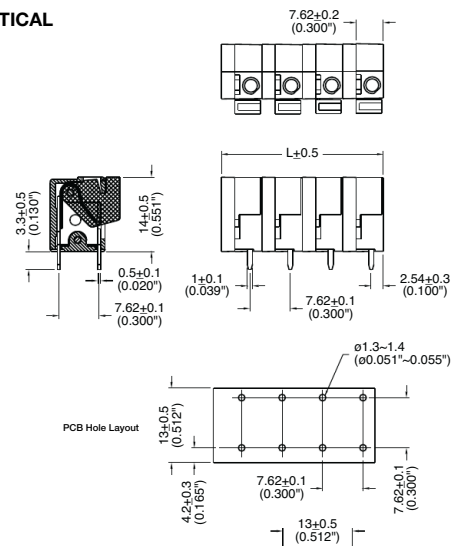

HORIZONTAL

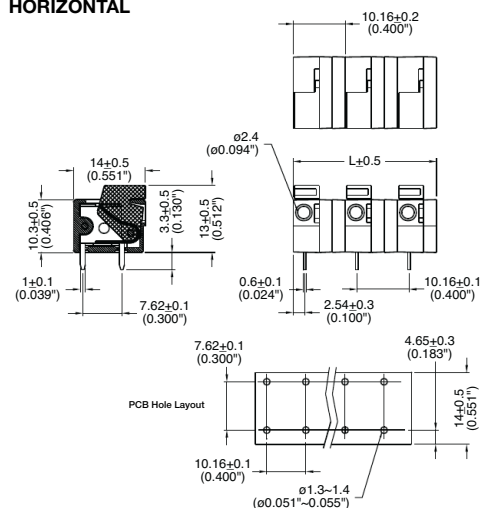

Poles	L (mm)	Poles	L (mm)
2	17.78	10	99.06
3	27.94	11	109.22
4	38.10	12	119.38
5	48.26	13	129.54
6	58.42	14	139.70
7	68.58	15	149.86
8	78.74	16	160.02
9	88.90		

To convert to inches, divide by 25.4

Part Numbering System

Series

EM2791

of Poles

02 to 16

Orientation

H - horizontal
V - vertical

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM279110H](#) [EM279113H](#) [EM279116H](#) [EM279104H](#) [EM279115H](#) [EM279102H](#) [EM279103H](#) [EM279111H](#)
[EM279112H](#) [EM279106H](#) [EM279107H](#) [EM279108H](#) [EM279105H](#) [EM279114H](#) [EM279109H](#) [EM279106V](#)
[EM279111V](#) [EM279116V](#) [EM279104V](#) [EM279109V](#) [EM279102V](#) [EM279103V](#) [EM279113V](#) [EM279110V](#)
[EM279108V](#) [EM279107V](#) [EM279115V](#) [EM279114V](#) [EM279105V](#) [EM279112V](#)