

EM2795 Series EuroMag Terminal Blocks

Screwless; 5.08 Centers

SPECIFICATIONS

Rating: 10A, 300V

Center Spacing: 0.20" (5.08mm)

Wire Range: #14-24 AWG

Housing Material: UL rated 94V0 Thermoplastic


Contact Material: Tin-Plated Brass

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

Recommended PCB Hole Diameters: 0.051" (1.30mm)


Construction: Mold-to-Length

Agency Information:  File E62622; CE Certified

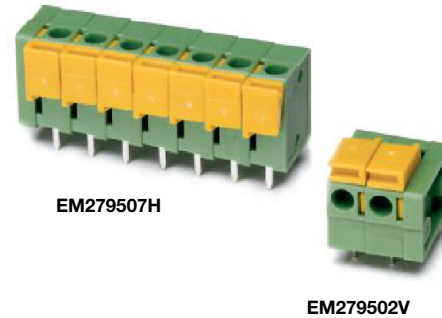


Dimensions - in (mm)

VERTICAL

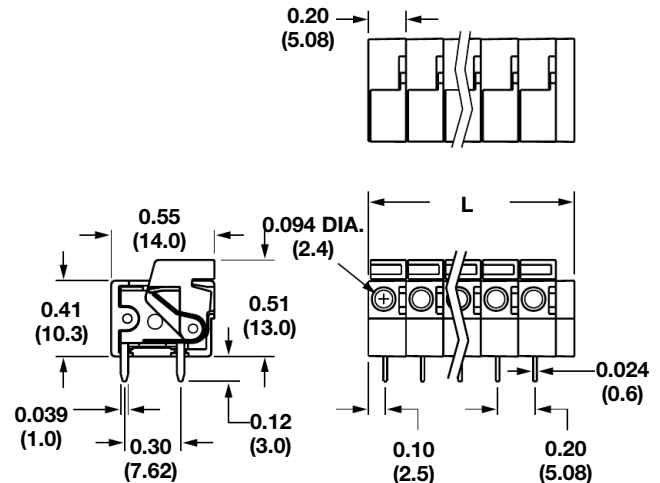

HORIZONTAL

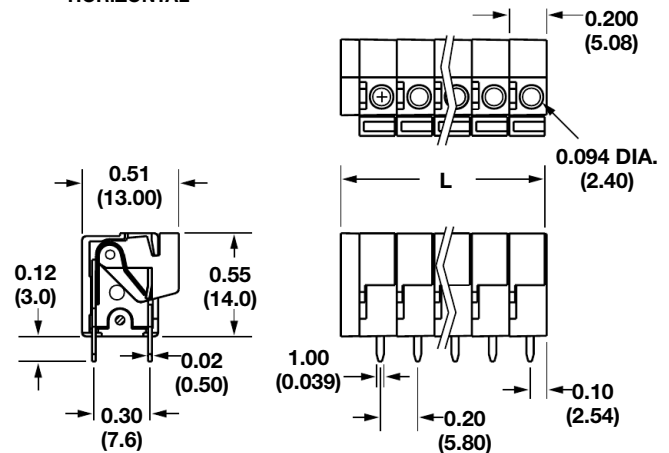

Part Numbering System

Series

EM2795

of Positions

02 to 16

Orientation

H - horizontal
V - vertical

Poles	L (mm)	Poles	L (mm)
2	12.70	10	68.58
3	17.78	11	73.66
4	22.86	12	78.74
5	27.94	13	83.82
6	33.02	14	88.90
7	38.10	15	93.98
8	43.18	16	99.06
9	48.26		

To convert to inches, divide by 25.4

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM279502H](#) [EM279502V](#) [EM279503H](#) [EM279503V](#) [EM279504H](#) [EM279504V](#) [EM279505H](#) [EM279505V](#)
[EM279506H](#) [EM279506V](#) [EM279507V](#) [EM279512H](#) [EM279513V](#) [EM279516H](#) [EM279513H](#) [EM279514H](#)
[EM279507H](#) [EM279508H](#) [EM279509H](#) [EM279515H](#) [EM279510H](#) [EM279511H](#) [EM279508V](#) [EM279516V](#)
[EM279511V](#) [EM279514V](#) [EM279515V](#) [EM279512V](#) [EM279509V](#) [EM279510V](#)