

EM2796 Series

EuroMag Terminal Blocks

Screwless; 7.62 Centers

SPECIFICATIONS

Rating: 10A, 300V

Center Spacing: 0.30" (7.62mm)

Wire Range: #14-24 AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Tin-Plated Brass

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

Recommended PCB Hole Diameters: 0.051" (1.30mm)

Construction: Mold-to-Length

Agency Information:  File E62622; CE Certified




EM279606V




EM279603H

Dimensions - mm (in)

VERTICAL

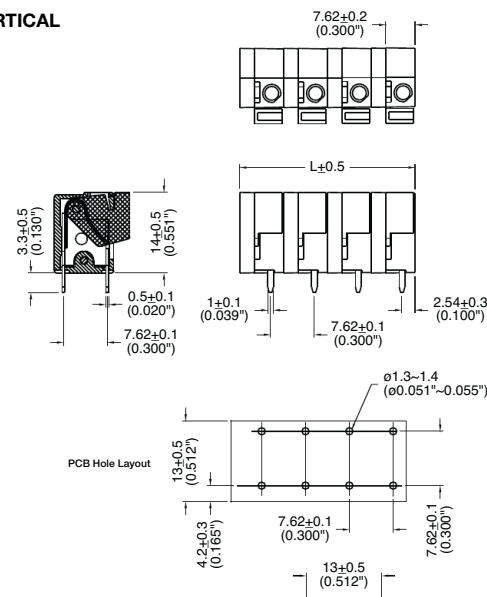

HORIZONTAL

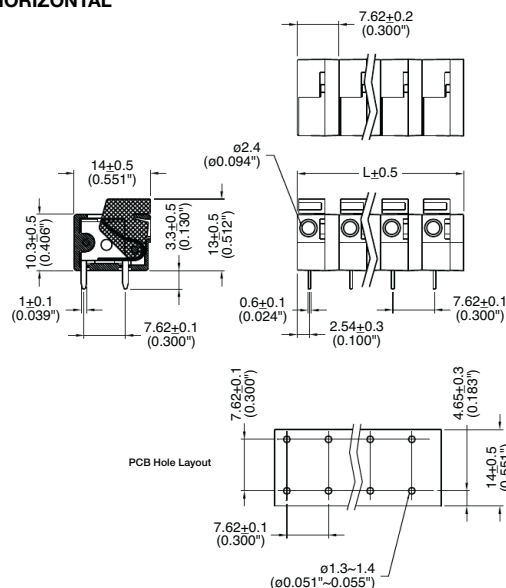

Poles	L (mm)	Poles	L (mm)
2	15.24	10	76.20
3	22.56	11	83.82
4	30.48	12	91.44
5	37.19	13	99.07
6	45.72	14	106.69
7	53.34	15	114.31
8	60.96	16	121.93
9	68.58		

To convert to inches, divide by 25.4

Part Numbering System

Series

EM2796

of Poles

02 to 16

Orientation

H - horizontal
V - vertical

Terminal Blocks:
Single Row

EuroMag Series
Screwless

Edge Connectors,
One-Sided Boards

Compliance
References

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM279608H](#) [EM279614H](#) [EM279610H](#) [EM279609H](#) [EM279616H](#) [EM279607H](#) [EM279611H](#) [EM279613H](#)
[EM279605H](#) [EM279604H](#) [EM279603H](#) [EM279602H](#) [EM279615H](#) [EM279606H](#) [EM279612H](#) [EM279603V](#)
[EM279605V](#) [EM279604V](#) [EM279614V](#) [EM279609V](#) [EM279613V](#) [EM279610V](#) [EM279616V](#) [EM279612V](#)
[EM279606V](#) [EM279615V](#) [EM279611V](#) [EM279607V](#) [EM279602V](#) [EM279608V](#)