

EM2855 Series

EuroMag Terminal Blocks

Three Tier; 5.00 Centers

SPECIFICATIONS

Rating: 16A, 300V

Center Spacing: 0.197" (5.00mm)

Wire Range: #14-26 AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Brass Tin-Plated

Cage Material: Brass Nickel-Plated

Screw Size: M2.6 Zinc-Plated Steel


Operating Temperature: 105°C max., -55°C min.

Torque Rating: 4.5 lb-in

Recommended PCB Hole Diameters: 1.30mm (0.051")


Construction: Mold-to-Length

Agency Information:  File E62622; CE Certified

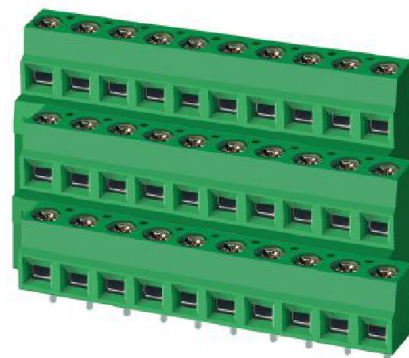

EM285510

Dimensions - mm (in)

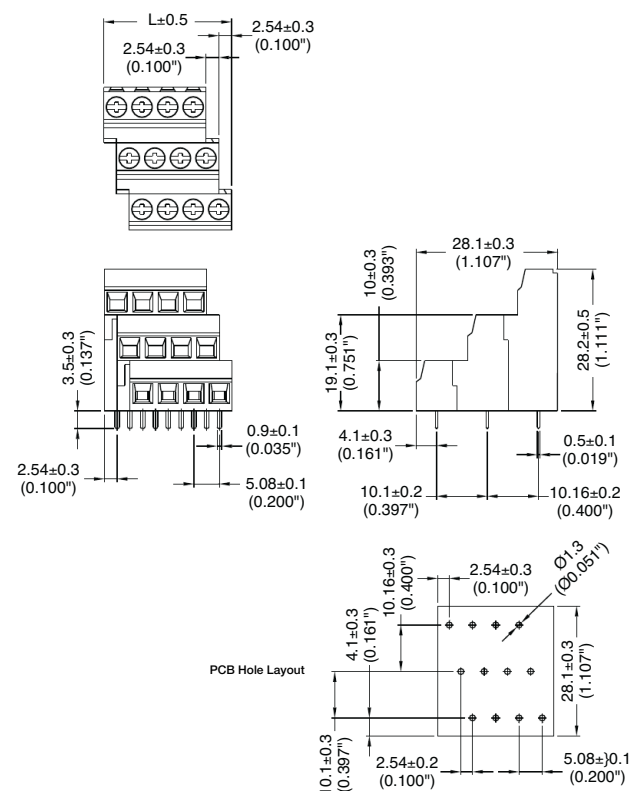

Poles	L (mm)
2	12.5
3	17.5
4	22.5
5	27.5
6	32.5

To convert to inches, divide by 25.4

Part Numbering System

Series

of Poles

EM2855

02 06

02 to 06

Terminal Blocks:
Single Row

EuroMag Series
Two & Three Tier

Edge Connectors,
One-Sided Boards

Compliance
References

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM285505](#) [EM285506](#) [EM285502](#) [EM285504](#) [EM285503](#)