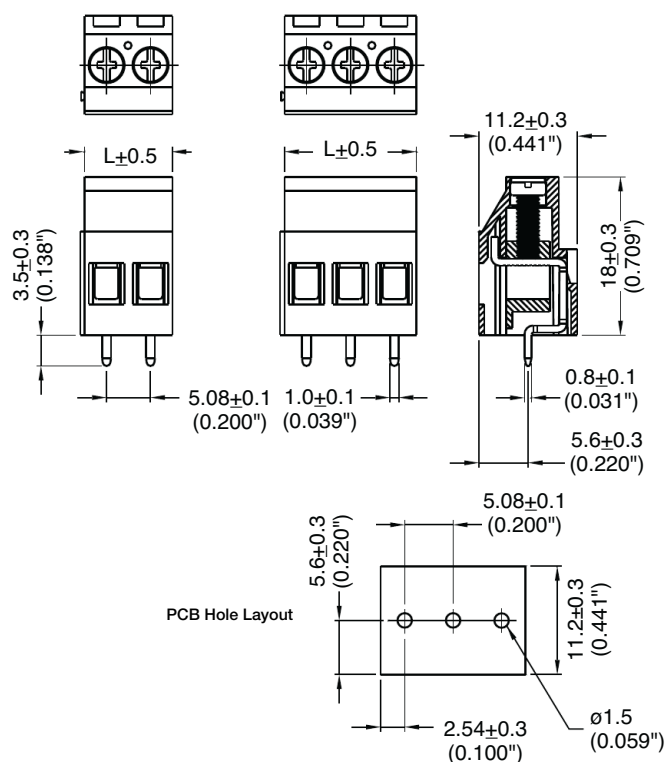


EM2908 Series**EuroMag Terminal Blocks**

High Current; 5.08 Centers; Modular

SPECIFICATIONS**Rating:** 25A, 300V**Center Spacing:** 0.20" (5.08mm)**Wire Range:** #10-24 AWG**Housing Material:** UL rated 94V0 Thermoplastic**Contact Material:** Brass Tin-Plated**Cage Material:** Brass, Nickel-Plated**Screw Size:** M2.6 Zinc-Plated Steel**Operating Temperature:** 105°C (221°F) max., -40°C (-40°F) min.**Torque Rating:** 6.0 lb-in.**Recommended PCB Hole Diameters:** 0.055" (1.40mm)**Construction:** Modular design features dovetails for interlocking to achieve longer lengths**Agency Information:**  File E62622; CE Certified

EM290808

Dimensions - mm (in)

Poles	L (mm)	Poles	L (mm)
2	10.16	14	71.12
3	15.24	15	76.20
4	20.32	16	81.28
5	25.40	17	86.36
6	30.48	18	91.44
7	35.56	19	96.52
8	40.64	20	101.60
9	45.72	21	106.68
10	50.80	22	111.76
11	55.88	23	116.84
12	60.96	24	121.92
13	66.04		

To convert to inches, divide by 25.4

Part Numbering System

Series

of Poles

EM2908

□□

02 to 24

Terminal Blocks:
Single RowEuroMag Series
High CurrentEdge Connectors,
One-Sided BoardsCompliance
References

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM290816](#) [EM290815](#) [EM290811](#) [EM290821](#) [EM290809](#) [EM290813](#) [EM290802](#) [EM290803](#) [EM290808](#)
[EM290814](#) [EM290810](#) [EM290805](#) [EM290812](#) [EM290817](#) [EM290822](#) [EM290824](#) [EM290806](#) [EM290823](#)
[EM290820](#) [EM290807](#) [EM290818](#) [EM290819](#) [EM290804](#)