

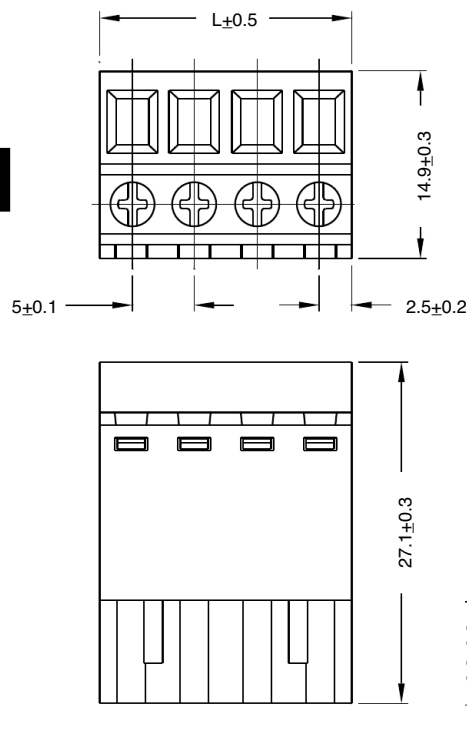
EM3105 Series**EuroMag Terminal Blocks**

Pluggable Block; Top Entry

(Mates with EM2535 Series); 5.00 Centers

SPECIFICATIONS**Rating:** 16A, 300V**Center Spacing:** 0.197" (5.00mm)**Wire Range:** #12-24 AWG**Housing Material:** UL rated 94V0 Thermoplastic**Contact Material:** Tin-Plated Phos Bronze**Cage Material:** Brass, Nickel-Plated**Screw Size:** M2.6 Zinc-Plated Steel**Operating Temperature:** 105°C (221°F) max., -40°C (-40°F) min.**Torque Rating:** 4.5 lb-in.**Construction:** Mold-to-Length**Agency Information:**  File E62622; CE Certified

EM310508

Dimensions - mm

Poles	L (mm)	Poles	L (mm)
2	10.0	8	40.0
3	15.0	9	45.0
4	20.0	10	50.0
5	25.0	11	55.0
6	30.0	12	60.0
7	35.0		

To convert to inches, divide by 25.4

Part Numbering System

Series

of Poles

EM3105

□□

02 to 12

Mating Header: EM2535 pg. 88

Terminal Blocks:
Single RowEuroMag Series
Plug & HeaderEdge Connectors,
One-Sided BoardsCompliance
References

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM310504](#) [EM310505](#) [EM310502](#) [EM310503](#) [EM310507](#) [EM310506](#)