

EM3115 Series**EuroMag Terminal Blocks**

Pluggable Block; Top Entry (Mates with EM2215 Series); 5.00 Centers

SPECIFICATIONS

Rating: 16A, 300V

Center Spacing: 0.197" (5.00mm)

Wire Range: #12-24 AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Brass Tin-Plated

Cage Material: Brass, Nickel-Plated

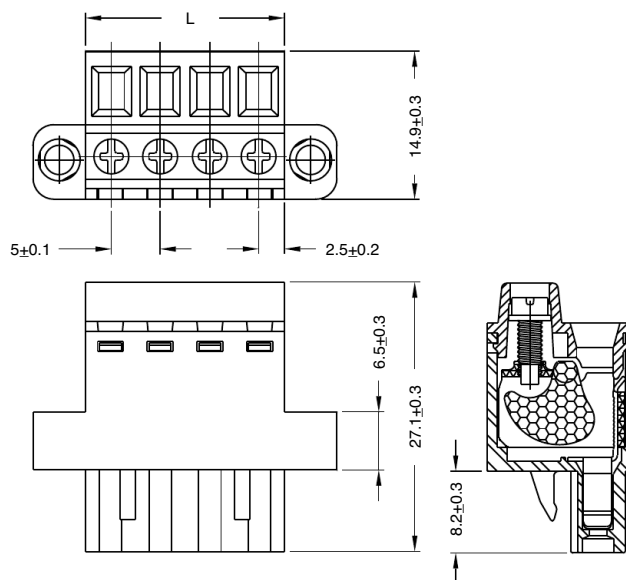
Screw Size: M2.6 Zinc-Plated Steel

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

Torque Rating: 4.5 lb-in.

Construction: Mold-to-Length

Agency Information:  File E62622; CE Certified

**EM311503****Dimensions - mm**

Poles	L (mm)	Poles	L (mm)
2	20.0	14	80.0
3	25.0	15	85.0
4	30.0	16	90.0
5	35.0	17	95.0
6	40.0	18	100.0
7	45.0	19	105.0
8	50.0	20	110.0
9	55.0	21	115.0
10	60.0	22	120.0
11	65.0	23	125.0
12	70.0	24	130.0
13	75.0		

To convert to inches, divide by 25.4

Part Numbering System

Series

of Poles

EM3115

02

02 to 22

Mating Header: EM2215 pg. 95

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eaton:](#)

[EM311522](#) [EM311521](#) [EM311506](#) [EM311503](#) [EM311509](#) [EM311502](#) [EM311519](#) [EM311517](#) [EM311514](#)
[EM311515](#) [EM311516](#) [EM311512](#) [EM311513](#) [EM311518](#) [EM311520](#) [EM311524](#) [EM311508](#) [EM311504](#)
[EM311523](#) [EM311510](#) [EM311507](#) [EM311511](#) [EM311505](#)