

EM3553 Series EuroMag Terminal Blocks

(Mates with EM3593 Series);
3.81 Centers

SPECIFICATIONS

Rating: 10A, 300V

Center Spacing: 0.15" (3.81mm)

Consult factory for 0.30" (7.62mm)

Wire Range: #16-26 AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Brass Tin-Plated

Screw Size: M2.0 Zinc-Plated Steel

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

Torque Rating: 3.0 lb-in.


Construction: Mold-to-Length

Agency Information:  File E62622; CE Certified



EM355308

Dimensions - mm (in)

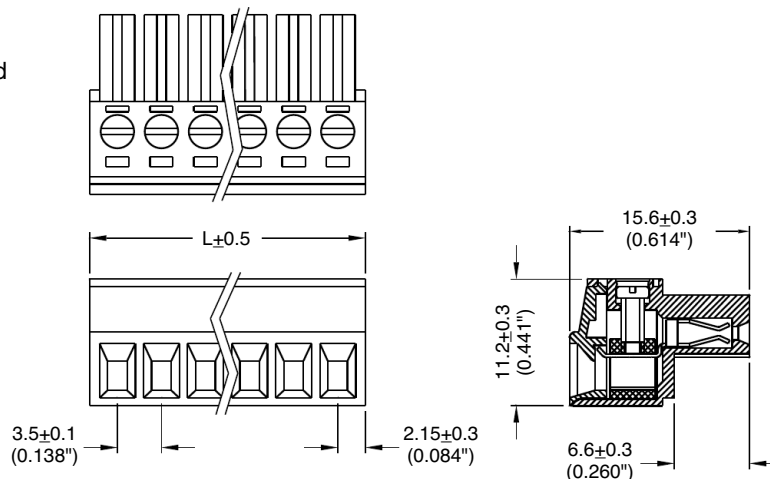

To convert to inches, divide by 25.4

Part Numbering System

Series

of Positions

EM3553

02 to 12

Mating Header: EM3593 pg. 81

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eaton:](#)

[EM355306](#) [EM355304](#) [EM355302](#) [EM355303](#) [EM355307](#) [EM355312](#) [EM355309](#) [EM355305](#) [EM355310](#)
[EM355308](#) [EM355311](#)