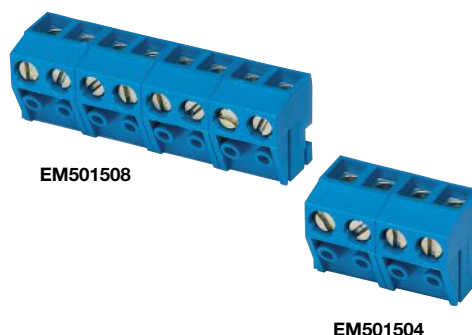
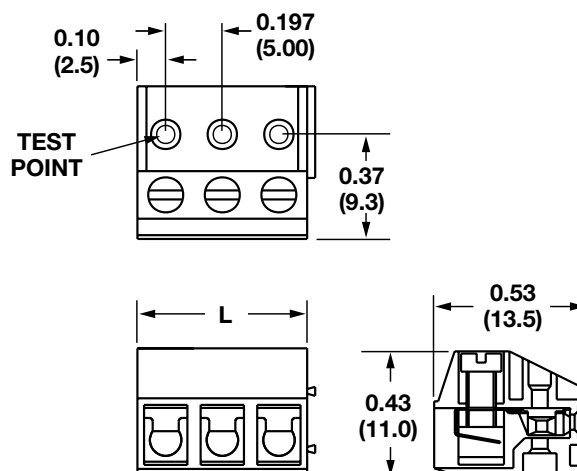


EM5015 Series**EuroMag Terminal Blocks**

Pluggable Block


(Mates with EM5025 Series); 5.00 Centers

SPECIFICATIONS**Rating:** 15A, 300V**Center Spacing:** 0.197" (5.00mm)**Wire Range:** #16-24 AWG**Housing Material:** Blue UL 94V0 Thermoplastic**Contact Material:** Tin-Plated Brass**Screw Size:** M2x6 Chromatized Steel**Operating Temperature:** 120°C (221°F) max., -40°C (-40°F) min.**Torque Rating:** 3.0 lb-in.**Construction:** Modular design features dovetails for interlocking to achieve longer lengths**Connector Style:** Spring and Screw**Agency Information:**  File E62622; CE Certified**Dimensions - in (mm)**

Poles	L (mm)	Poles	L (mm)
2*	10.0	14	70.0
3*	15.0	15	75.0
4	20.0	16	80.0
5	25.0	17	85.0
6	30.0	18	90.0
7	35.0	19	95.0
8	40.0	20	100.0
9	45.0	21	105.0
10	50.0	22	110.0
11	55.0	23	115.0
12	60.0	24	120.0
13	65.0		

To convert to inches, divide by 25.4

*Mold-to-Length

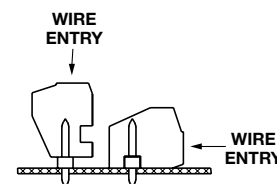**Mating orientations****Part Numbering System****Series****# of Poles****Mating Header:** EM5025 pg. 104

EM5015

□□

02 to 24

Terminal Blocks:
Single RowEuroMag Series
Plug & HeaderEdge Connectors,
One-Sided BoardsCompliance
References

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[EM501502](#) [EM501503](#) [EM501504](#) [EM501506](#) [EM501510](#) [EM501512](#) [EM501514](#) [EM501505](#) [EM501511](#)
[EM501517](#) [EM501521](#) [EM501508](#) [EM501507](#) [EM501522](#) [EM501513](#) [EM501520](#) [EM501523](#) [EM501515](#)
[EM501509](#) [EM501518](#) [EM501516](#) [EM501524](#) [EM501519](#)