

# HVI

## 1/4" x 1-1/4" In-line water resistant fuse holder




### Product features

- For 1/4" x 1-1/4" (6.3 mm x 32 mm) fuses
- IP54 rating for exposed locations
- Accepts #16 to #12 AWG copper wire
- Copper crimp lead material
- High temperature, flame retardant, phenolic meets UL 94 HB
- Crimp or 1/4" quick connect terminals
- In-line connection
- Recommended crimp tools:
  - Thomas & Betts – ERG4002
  - Channellock No. 909
  - Thomas & Betts WT-112M

### Dimensions-Inches

Drawing not to scale

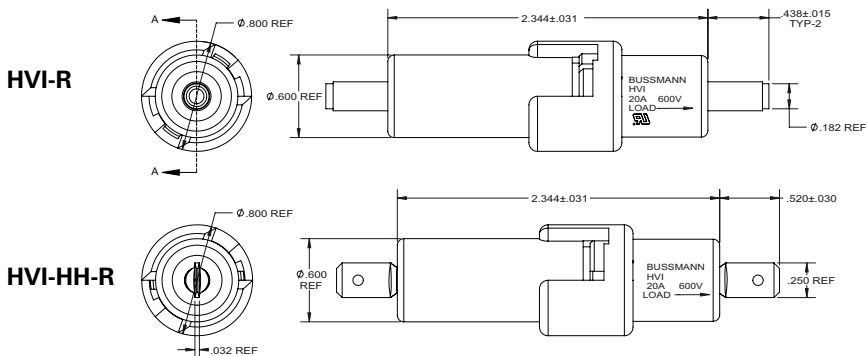

Life Support Policy: Eaton does not authorize the use of any of its products for use in life support devices or systems without the express written approval of an officer of the Company. Life support systems are devices which support or sustain life, and whose failure to perform, when properly used in accordance with instructions for use provided in the labeling, can be reasonably expected to result in significant injury to the user.

Eaton reserves the right, without notice, to change design or construction of any products and to discontinue or limit distribution of any products. Eaton also reserves the right to change or update, without notice, any technical information contained in this bulletin.

**Eaton**  
**Electronics Division**  
 1000 Eaton Boulevard  
 Cleveland, OH 44122  
 United States  
[Eaton.com/electronics](http://Eaton.com/electronics)

© 2020 Eaton  
 All Rights Reserved  
 Printed in USA  
 Publication No. 11124 BU-MC20106  
 June 2020

### Ordering codes

Specify the packaging code prefix before the part number

### Packaging prefixes

- Blank (10 parts in a carton)
- BK- (20 parts in a carton)

### Agency information

- UL Recognized: File number: E14853, (HVI-R)

### General specifications

- Temperature rating (RTI): +150 °C
- IP54 rating for exposed locations

### Product specifications

Part number	Voltage rating (V)	Ampere rating (A)	Body material	Terminal
HVI-R	600	20	Phenolic	Crimp
HVI-HH-R	600	20	Phenolic	1/4" quick connect

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[BK-HVI-HH-R](#) [BK-HVI-R](#) [HVI-HH-R](#) [HVI-R](#)