


DisplayPort to Mini DisplayPort Adapter Video Converter , 4K 60 Hz (M/F), 6 in. (15.2 cm)

MODEL NUMBER: P134-06N-MDP

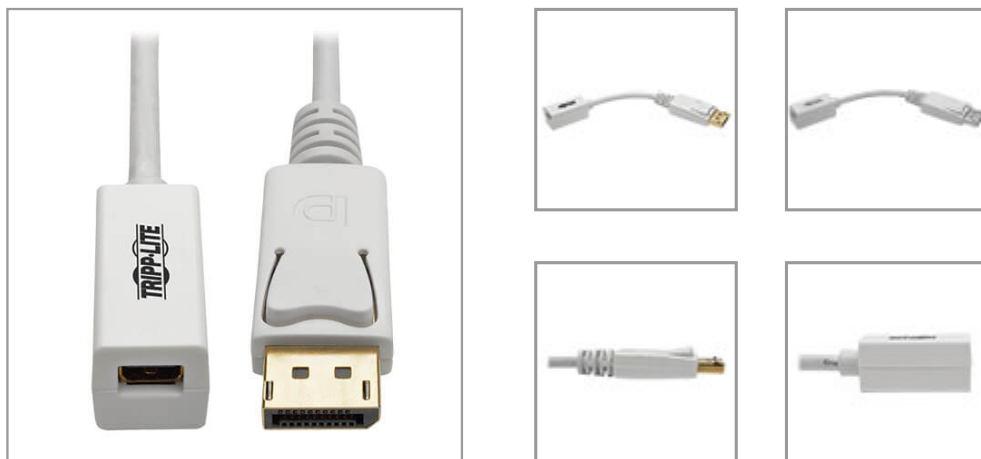

Connects a Mini DisplayPort (mDP) monitor to a computer with a DisplayPort output.

Features

Sends UHD DisplayPort Audio/Video to a Mini DisplayPort Monitor or an mDP Computer to a DisplayPort Monitor

- Connects a DisplayPort computer to an mDP monitor or a mDP computer to a DisplayPort monitor
- Recommended for displaying DisplayPort video on a large monitor or digital sign
- Allows you to continue using an existing mDP display, instead of buying a new monitor

Vibrant, Superior Video Quality

- Supports UHD video resolutions up to 3840 x 2160 (4K x 2K) @ 60 Hz, including 1080p
- 3840 x 2160 (4K x 2K) @ 60 Hz video resolutions supported up to 10 ft. (Including P134 adapter cable)
- 3840 x 2160 (4K x 2K) @ 30 Hz video resolutions supported up to 16 ft. (Including P134 adapter cable)
- Works with both Single-Mode and Dual-Mode (DP++) DisplayPort graphics cards

Superior Materials for Superior Performance

- Gold-plated connectors and contacts for excellent conductivity
- Integral strain relief for long life
- Plug and play—no software or drivers require

Specifications

OVERVIEW	
UPC Code	037332198624
Product Type	Video Adapter
Technology	DisplayPort
CONNECTIONS	

Highlights

- Supports UHD video resolutions up to 3840 x 2160 (4K x 2K) @ 60Hz
- Works with both Single-Mode and Dual-Mode graphics cards
- Gold-plated connectors and contacts
- Integral strain relief
- Plug and play—no software or drivers required

System Requirements

- Computer with a DisplayPort or Mini DisplayPort output
- Monitor with a Mini DisplayPort or DisplayPort input

Package Includes

- P134-06N-MDP DisplayPort to Mini DisplayPort Cable Adapter (M/F), 6 in.

Side A - Connector 1	DISPLAYPORT (MALE)
Side B - Connector 1	MINI DISPLAYPORT (FEMALE)
PHYSICAL	
Color	White
Cable Length (ft.)	0.05
Cable Length (m)	0.02
Cable Length (in.)	6
Cable Length (cm)	15.24
Shipping Dimensions (hwd / in.)	9.15 x 7.25 x 0.50
Shipping Dimensions (hwd / cm)	23.24 x 18.42 x 1.27
Shipping Weight (lbs.)	0.10
Shipping Weight (kg)	0.05
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[P134-06N-MDP](#)