


Dual DisplayPort KVM Cable Kit - DP, USB, 3.5 mm Audio (3xM/3xM) + DP (M/M), 4K, 4:4:4, 6 ft. (1.83 m), Black

MODEL NUMBER: **P783-006-DP**

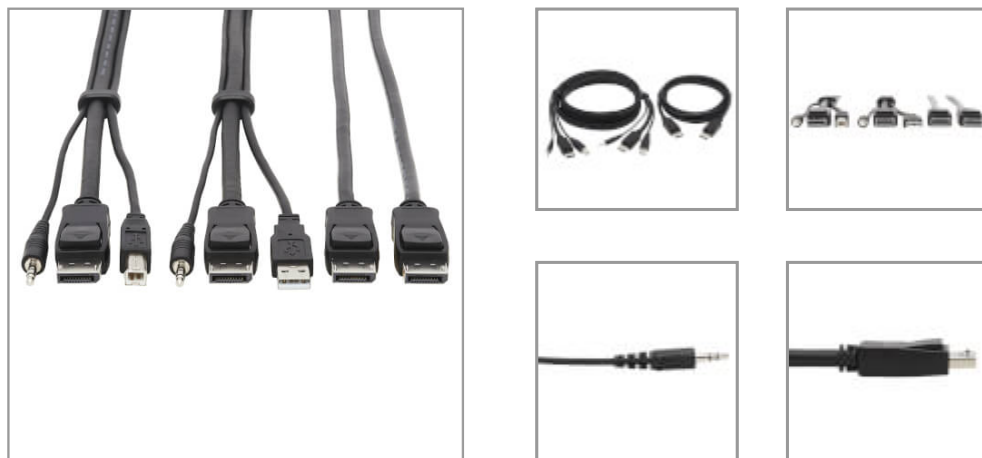

Dual DisplayPort KVM cable kit with DP, USB A/B and 3.5 mm plugs connects your computer to a Tripp Lite B002-DP2A4 or other compatible NIAP KVM.

Features

6-ft. (1.83 m) Cables Connect Your Computer and 2 DisplayPort Monitors to a NIAP KVM This DisplayPort cable kit includes two 6-foot cables for connecting a computer with two monitors to a KVM switch. The P783-006 features DisplayPort, USB A/B and 3.5 mm audio connectors on both ends for connecting your computer to a KVM switch. The P580-006 is a DisplayPort cable with male connectors on each end.

Specifically Designed for Select KVMs to Save You Time and Money Recommended for the NIAP KVM Series. The cables support DisplayPort video resolutions up to 3840 x 2160 (4K x 2K) at 60 Hz with true 4:4:4 chroma subsampling. They are compatible with HDCP 2.2 and DisplayPort 1.2 standards. The P783-006 also supports USB 2.0 data transfer speeds up to 480 Mbps. By combining several different cables into one convenient kit, you cut down on unnecessary clutter and save money.

Highlights

- Cuts cable clutter and saves money by combining essential KVM cables into just 2
- Includes 6-ft. (1.83 m) DisplayPort cable and 6-ft. (1.83 m) 3-in-1 DP, USB and 3.5 mm audio cable
- Delivers UHD picture quality at resolutions up to 3840 x 2160 (4K x 2K) @ 60 Hz
- Supports true 4:4:4 chroma subsampling to meet latest color standards
- Plug-and-play operation with no software required for easy, immediate installation

Applications

- Connect a headless computer with dual displays to a Tripp Lite KVM switch
- Upgrade or replace worn or lost KVM cables
- Eliminate clutter and save money by replacing multiple cables with one new kit
- Extend the distance between the KVM switch and computer to 6-ft. (1.83 m)

System Requirements

- B002-DP2A4 NIAP KVM or other compatible KVM switch

Package Includes

- P783-006 DisplayPort KVM cable kit, 3 in 1 (M/M), 6-ft. (1.83 m)
- P580-006 DisplayPort monitor cable (M/M), 6-ft. (1.83 m)

Specifications

OVERVIEW	
UPC Code	037332241634
Accessory Type	Cable Kit
Technology	DisplayPort
Accessory Class	KVM Switch Accessories
VIDEO	



Powering Business Worldwide

TRIPP LITE
SERIES

Max Supported Video Resolution	3840 x 2160 @60Hz
CONNECTIONS	
Side A - Connector 1	3.5MM (MALE); DISPLAYPORT (MALE); USB A (MALE)
Side A - Connector 2	DISPLAYPORT (MALE)
Side B - Connector 1	3.5MM (MALE); DISPLAYPORT (MALE); USB B (MALE)
Side B - Connector 2	DISPLAYPORT (MALE)
Contact Plating	Gold
PHYSICAL	
Color	Black
Cable Jacket Color	Black
Cable Length (ft.)	6
Cable Length (m)	1.83
Cable Length (in.)	72
Shipping Dimensions (hwd / in.)	1.25 x 10.10 x 12.50
Shipping Dimensions (hwd / cm)	3.18 x 25.65 x 31.75
Shipping Weight (lbs.)	0.80
Shipping Weight (kg)	0.36
Unit Dimensions (hwd / in.)	0.000 x 0.000 x 0.000
ENVIRONMENTAL	
Operating Temperature Range	14° to 122°F (-10° to 50°C)
Storage Temperature Range	5° to 140°F (-15° to 60°C)
Relative Humidity	0-90% non-condensing
FEATURES & SPECIFICATIONS	
USB Specification	USB 2.0 (up to 480 Mbps)
Displayport Specification	1.2
HDCP Specification	2.2
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty



Powering Business Worldwide

TRIPP LITE
SERIES

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[P783-006-DP](#)