


SmartRack Wall-Mount Roof Fan Kit - 2-120V high-performance fans; 210 CFM; 5-15P plug

MODEL NUMBER: SRFANWM

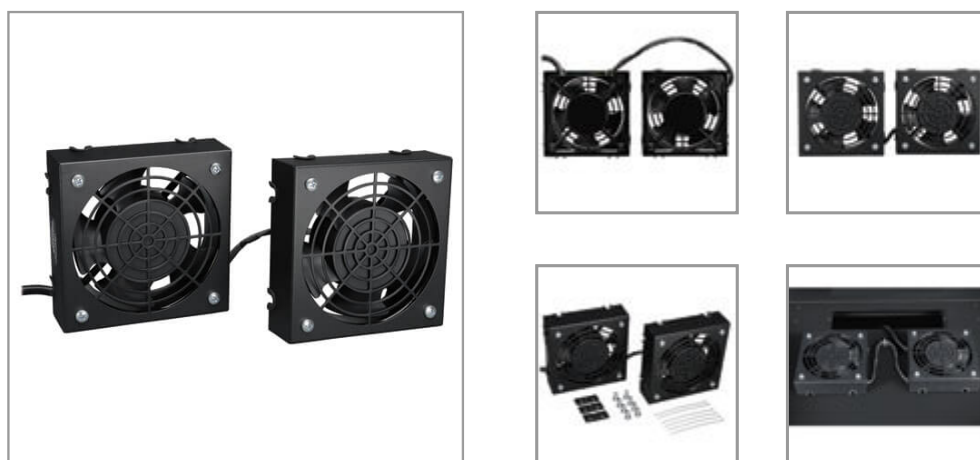

Increase airflow in wall-mount rack enclosures. The SRFANWM is ideal for expelling heat through a roof mounted fan system.

Features

- (2) 120V High-Performance Fans (210 CFM total)
- 50 dB sound rating
- 3-ft. (0.91 m) AC input cord with 5-15P input plug

Specifications

OVERVIEW	
UPC Code	037332166616
Accessory Type	Fan Kit
Accessory Class	Cooling Accessories
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Nominal Input Voltage Description	120V AC 50/60 Hz
Input Connection Type	NEMA 5-15P
Input Plug Features	NEMA 5-15P
Voltage Compatibility (VAC)	120
Input Frequency	50/60 Hz
Input Cord Length (ft.)	3
Input Cord Length (m)	0.91

Highlights

- Wall-Mount Roof Fan Kit - 120V
- Features (2) 120V high-performance fans, 3-ft. (0.91 m) cord
- 50 dB sound rating

Package Includes

- (2) 120V high-performance fans with 3-ft. (0.91 m) power cord
- (2) Fan guards
- Mounting hardware
- Owner's manual

COOLING	
Cooling Type	Passive
PHYSICAL	
Shipping Dimensions (hwd / in.)	3.10 x 7.80 x 11.66
Shipping Dimensions (hwd / cm)	7.87 x 19.81 x 29.62
Shipping Weight (lbs.)	5.08
Shipping Weight (kg)	2.30
Unit Dimensions (hwd / in.)	5.200 x 5.200 x 1.610
Unit Dimensions (hwd / cm)	Per Fan 13.21 x 13.21 x 4.1
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; EIA/ECA-310-E
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	2-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[SRFANWM](#)