
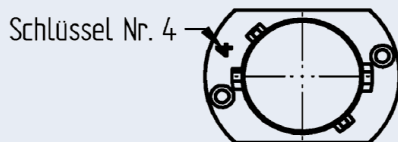


Alu-Socket for Spot - Downlight Modules GH36d-4

32.920 - Alu-Socket for Spot - Downlight Modules GH36d-4

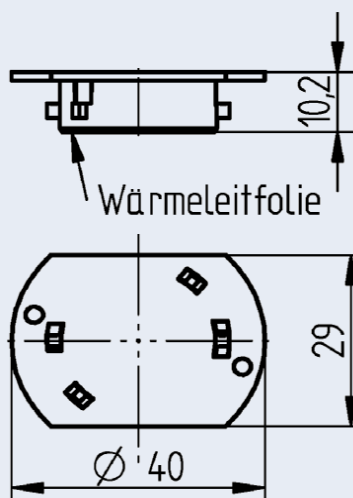

Part no.
32.920.3001.36

Alu-Socket for Spot - Downlight Modules GH36d-4

- Twist and Lock System

Maximum power depends on the respective heat sink, but max. 25 W.

| Mechanical data | |
|--------------------------------------|-------------------------|
| Height | 10,2 mm |
| width | 29 mm |
| length | Ø 40 mm |
| Code | 4 |
| Material data | |
| Material | Aluminium |
| TIM between Alu_Socket and heat sink | graphite foil |
| Weight | 16 g |
| Electrical data | |
| Max. | Max. 25 W (typ. 700 mA) |
| Commercial data | |
| Packaging quantity | 250 |
| Environmental requirements | |
| Max. Operating temperature | 140°C |

| | |
|--------------------|---------------------|
| Countersunk screws | M2,6x4 cross recess |
| Packaging quantity | 1000 |
| Weight | 0,123 g |

Part no.
32.920.-801.12

- 2 countersunk screws M2.6x4 cross recess nickel-plated each for fastening the lower part to be ordered separately.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[BJB Electric:](#)

[32.920.3001-000-00](#)