
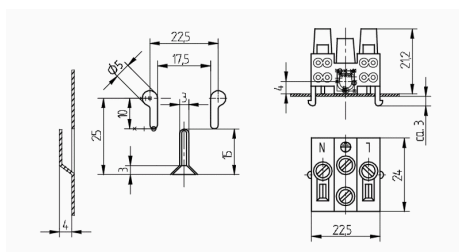


Terminal block 3 poles

Article number: 48.141.0311-0

EAN: 4049853

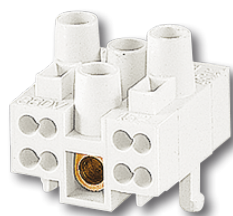

Product information "Terminal block 3 poles"

Screw / pushwire terminals

Screw / screw terminal (for earth)

Nominal cross section: 1.5 mm²

Pushwire terminals: 0.5 - 1.5 mm²

Screw terminals will also accept wires with ferrule.

Color:	natural colour
Housing width:	22,5 mm
Lettering:	N $\perp$ L
Luminaire wall thickness:	0.8 - 1.0
Material:	Housing: PA 6.6
Note warranty conditions:	*Warranty conditions of BJB GmbH & Co. KG as stated as available via the Internet under https://www.bjb.com/en/legal-information/general-terms-and-conditions/ are valid.

Number of poles:	3
Packaging quantity:	1000
Producttype:	3 pole - screw / push-wire terminals
Screw terminals:	ø 3.4
Series:	Screw / push-wire terminals
Weight:	10 g
mounting method 1:	Snap fixing
old article number:	48.141.0311.51

Available Downloads

- > [BJB_Brochure_Terminal_block_and_Connectors_Update_01_2020](#)
- > [BJB_Prospekt_Verbindungsklemmen_und_Steckverbinder_Update_01_2020](#)
- > [US_General_Information](#)
- > [Allgemeine_Informationen](#)

Available CAD Downloads

- > [3D-CAD_\(STEP,_Parasolid,_IGES,_3D-PDF\)007-Q01-06](#)

Certifications

Article Number	Documents
48.141.0311-0	Genehmigung_liegt_vor-Approval_at_hand749986
48.141.0311-0	Genehmigung_liegt_vor-Approval_at_hand718207
48.141.0311-0	Genehmigung_liegt_vor-Approval_at_hand4070828



16 A
450 V



ø 3,4

T 85



0,8 - 1,0

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[BJB Electric:](#)

[48.141.0311-001-07](#)