


# COB holder for Spot - Downlight Modules GH36d

32.920 - COB holder for Spot - Downlight Modules GH36d

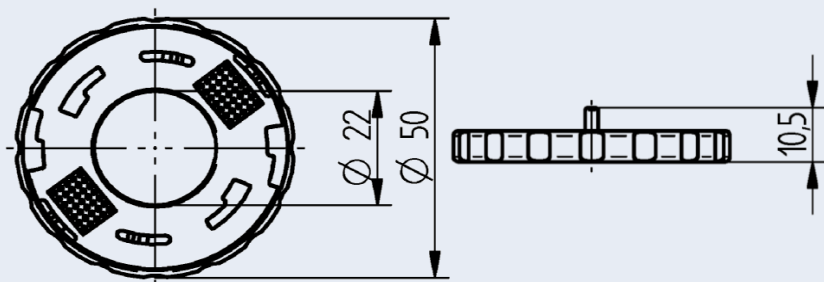

Part no.  
32.920.1102.50

## COB holder for Twist 'n' Spot LED Module

- Twist and Lock System

Maximum power depends on the respective heat sink, but max. 32 W.

Please note the polarity of the LED

Please observe the specifications of the LED manufacturer

When connecting LED modules in series, the creepage and clearance distances of the individual modules must be designed for the total voltage of the series connection

### Mechanical data

|                                       |               |
|---------------------------------------|---------------|
| Countersunk Tapping screws for socket | M 2,6 x 4     |
| Max. torque                           | 0,3 Nm        |
| Integrated interface for reflektors   | yes           |
| Max. reflector weight                 | 30 g          |
| With glass cover                      | no            |
| COB pre-fixing                        | yes           |
| For COB format                        | 24 mm x 24 mm |

### Material data

|                  |       |
|------------------|-------|
| Material housing | PPT   |
| Colour           | white |
| Contacts COB     | CuAu  |
| Contacts socket  | CuSn  |
| Weight           | 6 g   |

### Electrical data

|                |       |
|----------------|-------|
| Voltage rating | 150 V |
| Current rating | 2 A   |

### Commercial data

|                    |     |
|--------------------|-----|
| Packaging quantity | 250 |
|--------------------|-----|

### Environmental requirements

|                            |       |
|----------------------------|-------|
| Max. Operating temperature | 140°C |
|----------------------------|-------|

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[BJB Electric:](#)

[32.920.1102-000-00](#)