


COB holder for Spot - Downlight Modules GH36d

32.920 - COB holder for Spot - Downlight Modules GH36d

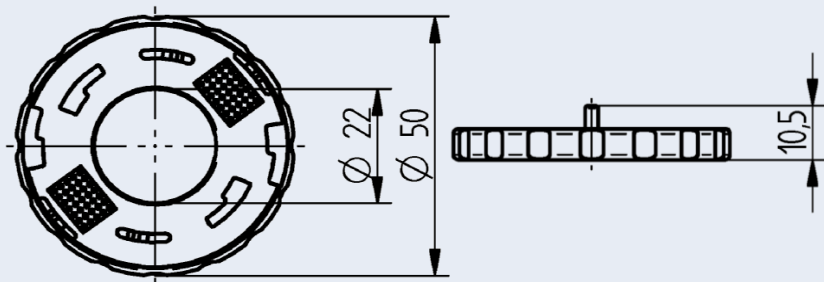

Part no.
32.920.1103.50

COB holder for Twist 'n' Spot LED Module

- Twist and Lock System

Maximum power depends on the respective heat sink, but max. 32 W.

Please note the polarity of the LED

Please observe the specifications of the LED manufacturer

When connecting LED modules in series, the creepage and clearance distances of the individual modules must be designed for the total voltage of the series connection

Mechanical data	
Countersunk Tapping screws for socket	M 2,6 x 4
Max. torque	0,3 Nm
Integrated interface for reflektors	yes
Max. reflector weight	30 g
With glass cover	no
COB pre-fixing	yes
For COB format	17,85 mm x 17,85 mm
Material data	
Material housing	PPT
Colour	white
Contacts COB	CuAu
Contacts socket	CuSn
Weight	6 g
Electrical data	
Voltage rating	150 V
Current rating	2 A
Commercial data	
Packaging quantity	250
Environmental requirements	
Max. Operating temperature	140°C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[BJB Electric:](#)

[32.920.1103-000-00](#)