
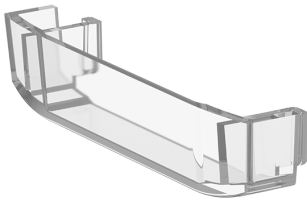
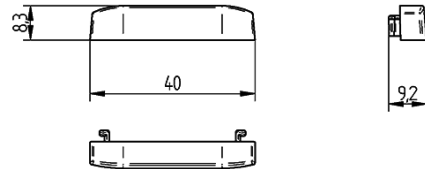


Endcap for single row optics

35.324

35.903.-304.85

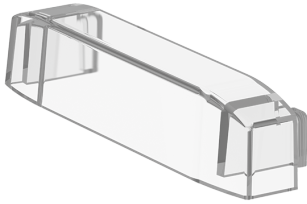

CAD

110°C



0,5 - 1,0 mm

Endcap for single row optics

35.324

35.903.-304.85



DESCRIPTION

Suitable for all LED module thicknesses
Applying of customised logos possible

Product name:	Endcap for single row optics 35.324
Short description:	Universally applicable for both optic sides
Mounting method 1:	Slide in fixing
Material:	PC
Operating temperature:	max. 110° C
Color:	clear
Weight:	2
Pkg.:	450