


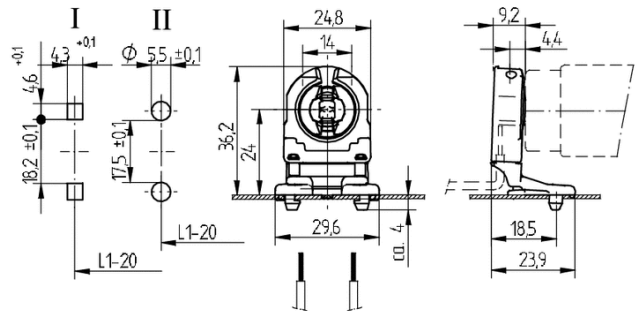

Fluorescent lampholder G13

26.307.6023.50



120°C
115°C



18 AWG



0,5 - 1,1



660 W
600 V

Fluorescent lampholder G13

26.307.6023.50



DESCRIPTION

Snap in pins for IP 40

A pair of lampholders provides a lamp length tolerance compensation of 3 mm

Instantstart version for USA and Canada: with integrated short circuiting bridge

Product name:	Fluorescent lampholder G13
Mounting method 1:	Push-in pins (for hole pattern 5.5 mm dia. or 4.3 x 4.6 mm)
Lamp center:	24
Material:	Housing: PC Rotor: PBT
T-Marking:	130
Protection class according to IEC:	IP 40
Wiring:	through the body
Approval:	cULus
cULus file no.:	E-92235
Material thickness:	0.5 - 1.1
Front Test:	yes
Rotor:	with
Top Test:	yes
Pkg.:	500