



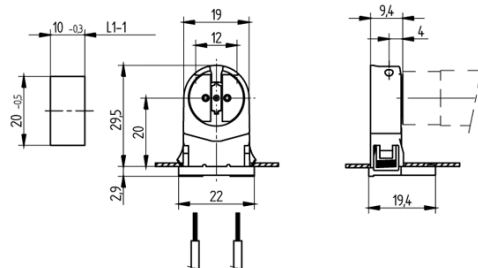

Fluorescent lampholder G5

26.620.2006.50

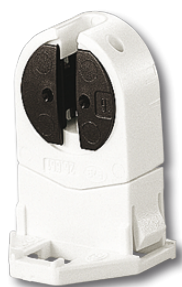

T 130

Tm110



18 AWG 0,5 -1,0
mm²



0,5 - 1,5

Fluorescent lampholder G5

26.620.2006.50



DESCRIPTION

For enclosed cut-outs: 10 x 20 mm

A pair of lampholders provides a lamp length tolerance compensation of 2 mm

Product name:	Fluorescent lampholder G5
Symbol Ausprägung:	0,5 -1,0 mm²
Mounting method 1:	Push through mount
Lamp center:	20
Material:	Housing: PC Rotor: PBT
Approval:	cULus
cULus file no.:	E-92235
Material thickness:	0.5 - 1.5
Front Test:	yes
Rotor:	with
Top Test:	yes
Color:	white
Weight:	3
Pkg.:	1000