


Fluorescent lampholder G5

26.641.2001.50

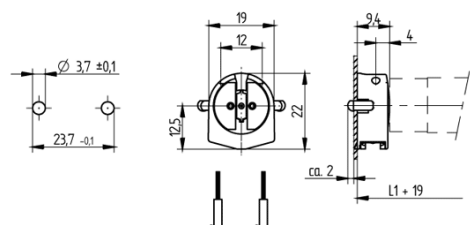

T 130

Tm110



18 AWG 0,5 -1,0
mm²



0,6 - 1,0



Fluorescent lampholder G5

26.641.2001.50



DESCRIPTION

For cut-outs open at the rear or enclosed cut-outs with 4.5 mm dia. locating hole
A pair of lampholders provides a lamp length tolerance compensation of 3 mm

Product name:	Fluorescent lampholder G5
Symbol Ausprägung:	0,5 -1,0 mm²
Mounting method 1:	Snap-in pins
Material:	Housing: PC Rotor: PBT
T-Marking:	130
Wiring:	through the body
Approval:	cULus
cULus file no.:	E-92235
Material thickness:	0.6 - 1.0
Front Test:	yes
Rotor:	with
Top Test:	yes
Color:	white
Weight:	3
Pkg.:	1000