
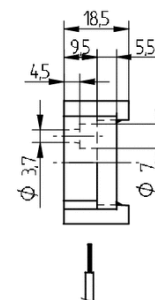
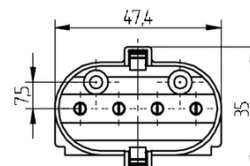


# Lampholder 2G11

26.726.4805.50

---

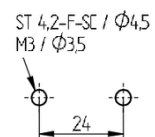

T 140

U out  
500 V



18 AWG 0,5 - 1,0  
mm<sup>2</sup>

# Lampholder 2G11

## 26.726.4805.50



### DESCRIPTION

Holes: ø 3.7 mm: for screws ISO 1207 - M3 or for self-tapping screws with locating groove ISO 1481 - ST 4.2 - F/ ISO 4753 - SC  
For cable insertion direction please refer to drawing

Product name:	Lampholder 2G11
Country of origin:	DE
Packaging type:	Bag
Packaging quantity:	250.000
Short description:	Supports for TC-L lamps
Mounting method 1:	Vertical screw mount
Material:	Housing: PBT
Approval:	additional cULus
cULus file no.:	E-92235
Color:	white
Weight:	13
Pkg.:	250