

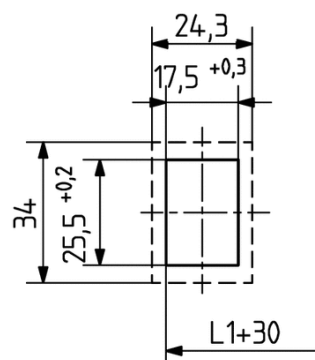


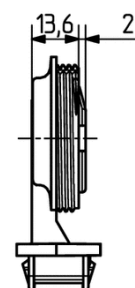

Technology for Light

# Lampholder Water and Dustproof 27.240.U301.81

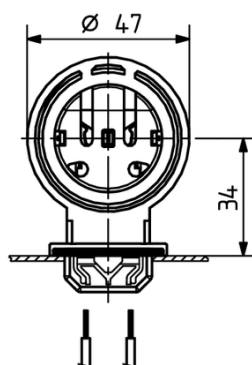

T 140



0,5 - 1,0 mm<sup>2</sup>



1,4 - 2,0

IP  
65/67



Technology for Light

# Lampholder Water and Dustproof

## 27.240.U301.81

---

### DESCRIPTION

Max. permissible temperature at front of face plate (T):140°C

Max. permissible temperature at the rear of the lampholder (Tm): 110° C

Quick and easy wiring achieved by tapered wiring channels

Tensile interior of lampholder provides a lamp length tolerance compensation of 3 mm per pair of lampholders

Suitable gaskets: 27.240.-703 u. 27.240.-707

Product name:	Lampholder Water and Dustproof
Mounting method 1:	Snap-in foot 25.5 x 17.5 mm
Lamp center:	34
Material:	Housing: PC Rotor: PBT
T-Marking:	140
Protection class according to IEC:	IP 65/67
Wiring:	through snap in foot
Material thickness:	1.4 - 2.0
Gasket:	Gasket: without foot gasket
Single- / twin lampholder:	Single lampholder
Color:	white, gray
Weight:	21
Pkg.:	100