



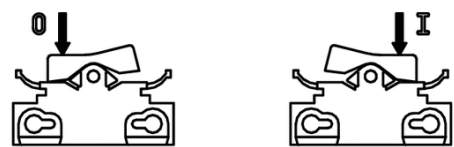

Switch

43.409.U614.50

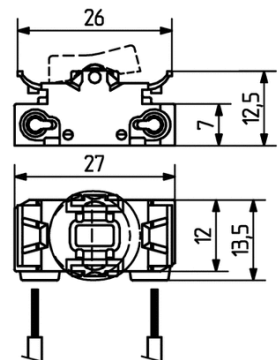

T 130

Tm 110

U out
500 V



18 AWG 0,5 - 1,0
mm²



0,4 - 2,0



Switch

43.409.U614.50



DESCRIPTION

UL Recognized Component: approved only with round and square rockers.
Protected against electric shock after insertion of conductor. Additional cover not required.
Stripping of wires: 7 mm
cURus: File E-101848 (only with round or square rockers)

Product name:	Switch
Country of origin:	DE
Packaging type:	Bag
Packaging quantity:	1000.000
Mounting method 1:	Snap-in mounting
Material:	Contacts: silver / silver
Approval:	cURus
Material thickness:	0.5 - 1.0
Switch - Components:	Housing
Color:	white
Weight:	3
Pkg.:	1000