



Terminal block 3 poles

46.413.1114.50

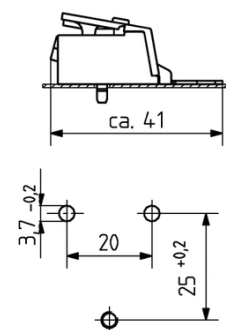

T 85
-40°C

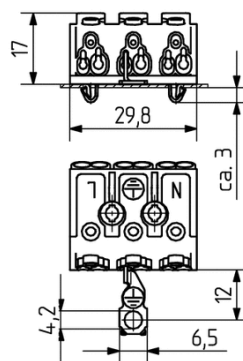

max. $\varnothing$ 1,8 mm



max. $\varnothing$ 1,8 mm



0,5 - 1,0

16 A
450 V



Terminal block 3 poles

46.413.1114.50



DESCRIPTION

Internal wiring: only for solid conductors and 7 stranded wire ends

Cable diameters:

External: 2 x 0.5 - 2.5 mm²

Internal:

- a) 1 x 0.5 - 1.0 mm², releasable

- b) 1 x 0.5 - 2.5 mm², releasable

- c) Suppression capacitor: 1 x 0.5 - 0.75 mm², not releasable

Further markings on request

Product name:	Terminal block 3 poles
Mounting method 1:	Push through mount
Material:	Housing: PC
Marking:	N ? L
Earth contact:	Earth bracket
Material thickness:	0.5 - 1.0
Contact opening:	With integral cable release
Quantity of poles:	3
Color:	white
Weight:	9
Pkg.:	500