



## 10.4-inch VGA Color TFT



### TCG104VGLAAANN-AN00/AN20



Kyocera offers two versions of 10.4" VGA TFT LCDs: the AN00 is the normal brightness version with 400nits brightness and the AN20 is the same panel but with the CCC ( constant current circuit) built-in. Both products feature long life LED with 70K hours lifetime, wide operating temperature range and standard CMOS interface.

Item	Specification
Resolution / Pixel Configuration	640 x 480 / RGB Stripe
Outline Dimensions (W x H x D mm)	240.7 x (180.2) x 9
Active Area (W x H mm)	211.2 x 158.4
Backlight Type / Backlight Lifetime	White LED / 70,000 hrs
Luminance (cd/m <sup>2</sup> )	400 cd/m <sup>2</sup>
Contrast Ratio	500:1
Electrical Interface	CMOS
Viewing Angle	H: +/-70° ; V: -70~60° (CR ≥ 10)
Temperature Range	Operating: -20 ~ 70° C / Storage: -30 ~ 80° C
Special Feature(s)	AN20: CCC built-in

Note: Specifications are subject to change without notice.

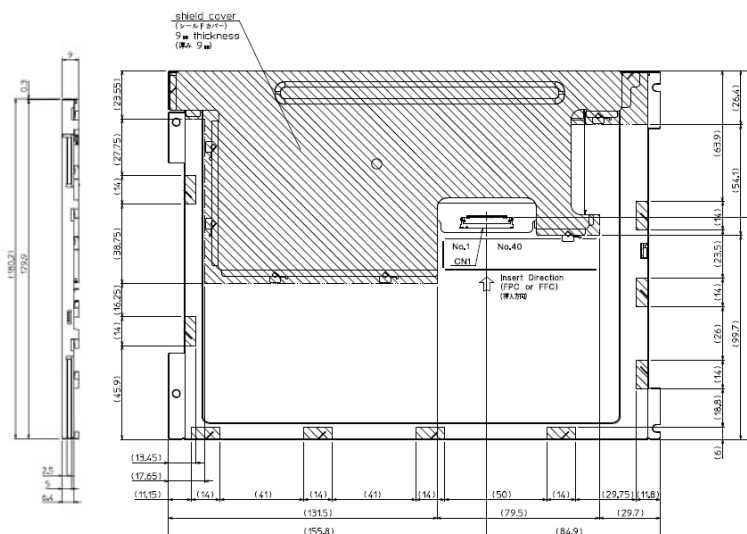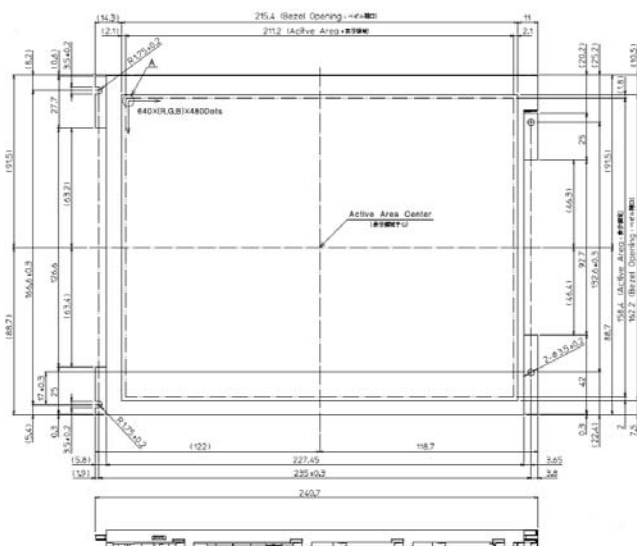

Ask us about the Value-Added Program

Let us attach your chosen touch screen, connector or provide you with custom cables to meet your needs

For complete technical specifications, application notes or inventory information call 734-416-8500 or visit our website at [www.kyocera-display.com](http://www.kyocera-display.com)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kyocera:

[TCG104VGLAAANN-AN00](#) [TCG104VGLAAANN-AN20](#)