

T1A

### FEATURES

- ※ Compact-size 2.8\*1.9mm
- ※ Low profile with 0.60mm
- ※ Long operation cycles


### APPLICATION

- ※ Smart phone
- ※ Digital camera, Medical
- ※ Portable electronic device
- ※ 3C products

### SPECIFICATION

Contact Rating	10uA, 1V DC to 50mA, 12V DC
Contact Resistance	500mΩ max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	100V AC/1 minute
Operating Force	160±50gf / 200±50gf
Travel	0.13mm
Operating Life	300,000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-40°C ~ +85°C

### CIRCUIT

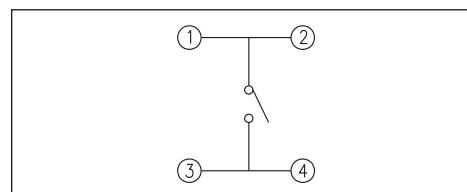

### PACKAGE

<Tape & Reel>  
16000 pcs

### HOW TO ORDER

T 1 A □ Q R


 
 

Package:  
Tape & Reel

Halogen Free

Operating Force:  
2=160gf  
3=200gf

TACT SWITCH

### T1A

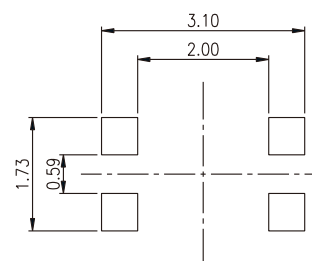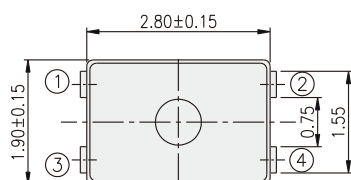

P.C.B. LAYOUT

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

T1A3QR T1A2QR