

FEATURES

- ※Double switch
- ※Two Circuit

APPLICATION

- ※Audio, OA equipment
- ※Instrumentation
- ※Setup box

SPECIFICATION


Contact Rating	50mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	180±50gf
Travel	0.20mm
Operating Life	100,000 cycles
Operating Temp.	-20°C ~ +70°C
Storage Temp.	-30°C ~ +80°C

HOW TO ORDER

T7A-□14KQP

- 1=Single Stem
- 2=Double Stem
- Stem High: 3.80mm
- Package: Bulk Pack
- Halogen Free
- Stem Color: Black
- Operating Force: 180gf

CIRCUIT

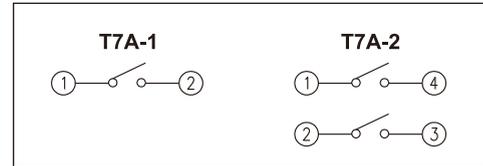


PACKAGE


<Bag>
400 pcs

TACT SWITCH

T7A-1

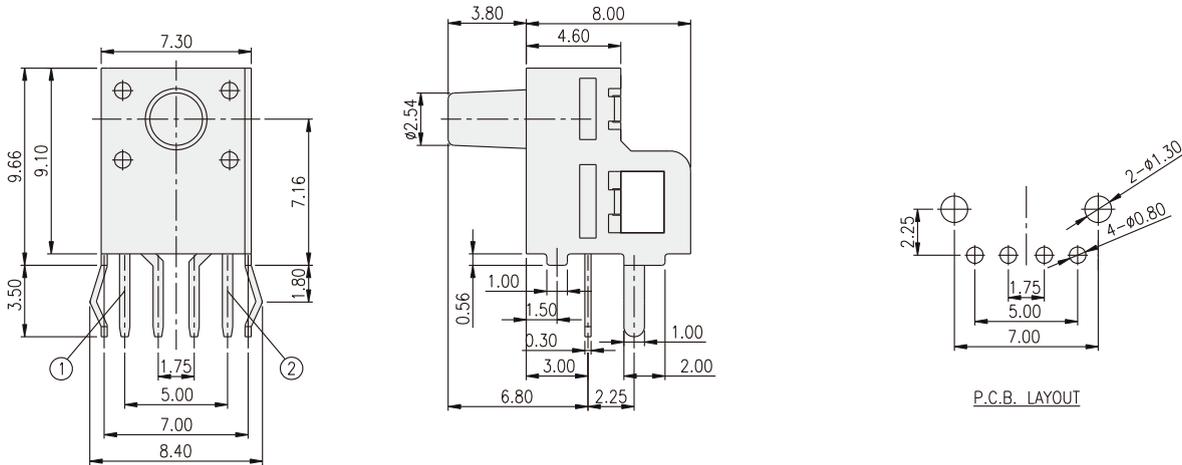

T7A-2

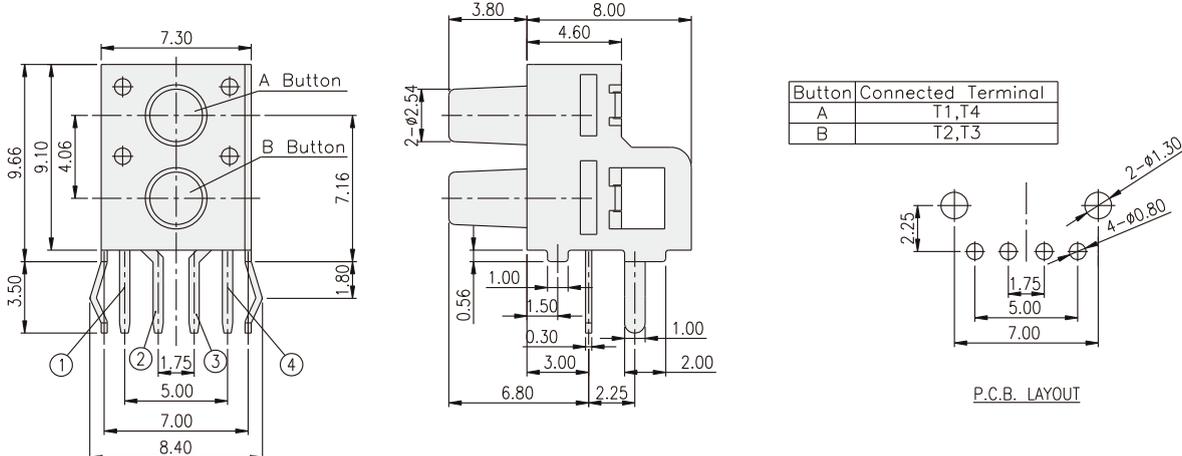

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Diptronics:](#)

[T7A-114KQP](#) [T7A-214KQP](#)