

FEATURES

- ※ Sealed
- ※ Long life of 10million
- ※ Variety of actuator lengths


APPLICATION

- ※ Music instrument
- ※ Intercom system
- ※ Industrial

SPECIFICATION

Contact Rating	0.5~50mA, 24V DC
Contact Resistance	30mΩ max.
Insulation Resistance	10MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	300±75gf
Travel	1mm
Operating Life	10,000, 000 cycles
Operating Temp.	-40°C ~ +160°C
Storage Temp.	-40°C ~ +160°C

CIRCUIT

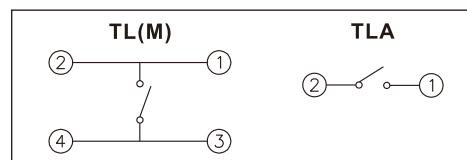

PACKAGE

<Tube>

TL(A): 45 pcs

<Tape & Reel>

TLM: 650 pcs

HOW TO ORDER

TL - A 2 1 4 K - Q - + TL - A - PC K

 = Through Hole
M = S.M.T.
A = Right Angle


Package:
B = Tube
(For Through Hole Type)
T/R = Tape & Reel (For S.M.T. Type)

Halogen Free




Button Color:
Black

Operating Force:
300gf

TL-A214K+TL-A-PC K

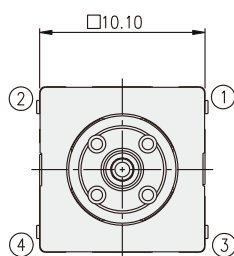


PART NO.	H
TL-A214K-Q-B+TL-A-PC1K	8.00
TL-A214K-Q-B+TL-A-PC2K	9.50
TL-A214K-Q-B+TL-A-PC3K	10.40
TL-A214K-Q-B+TL-A-PC4K	11.00
TL-A214K-Q-B+TL-A-PC5K	12.00
TL-A214K-Q-B+TL-A-PC6K	15.00

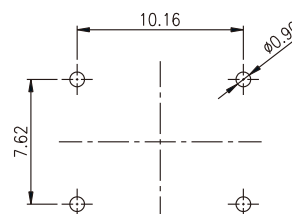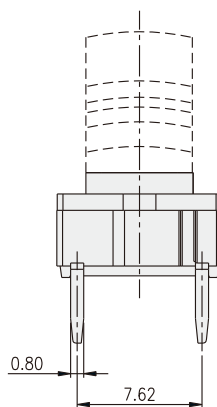
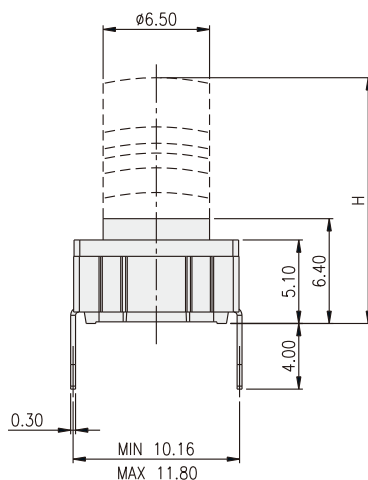


P.C.B. LAYOUT

TLM-A214K+TL-A-PC□K

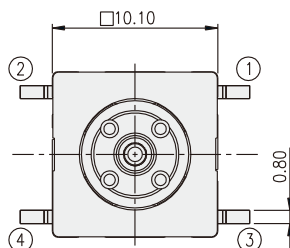


PART NO.	H
TLM-A214K-Q-B+TL-A-PC1K	8.00
TLM-A214K-Q-B+TL-A-PC2K	9.50
TLM-A214K-Q-B+TL-A-PC3K	10.40
TLM-A214K-Q-B+TL-A-PC4K	11.00
TLM-A214K-Q-B+TL-A-PC5K	12.00
TLM-A214K-Q-B+TL-A-PC6K	15.00

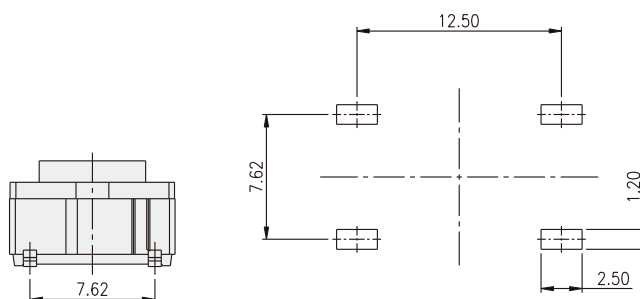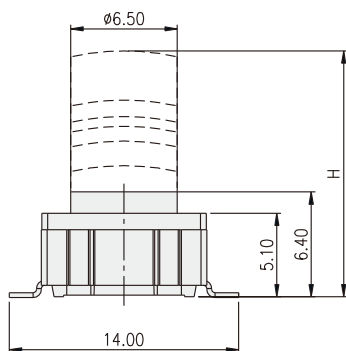



P.C.B. LAYOUT

TACT SWITCH

TLA-A214K+TL-A-PC□K

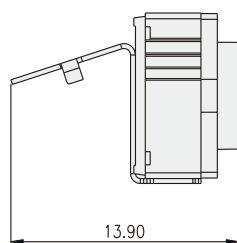

PART NO.	H
TLA-A214K-Q-B+TL-A-PC1K	8.00
TLA-A214K-Q-B+TL-A-PC2K	9.50
TLA-A214K-Q-B+TL-A-PC3K	10.40
TLA-A214K-Q-B+TL-A-PC4K	11.00
TLA-A214K-Q-B+TL-A-PC5K	12.00
TLA-A214K-Q-B+TL-A-PC6K	15.00

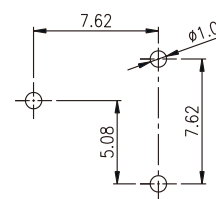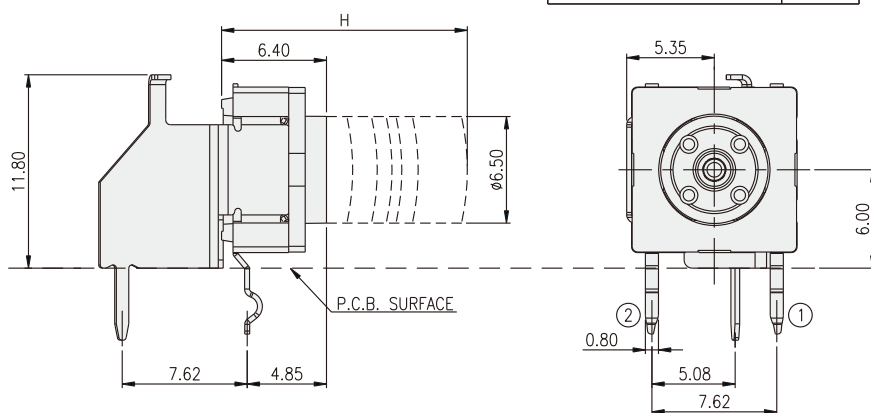

P.C.B. LAYOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[TLM-A214K-Q-T/R](#) [TL-A214K-Q-B](#) [TL-A224K-Q-B](#)