


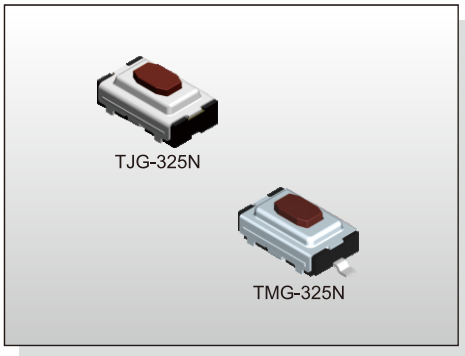

FEATURES

- ※ Thinner type 2.5mm height
- ※ High density mounting
- ※ With anti-ESD of ground terminal


APPLICATION

- ※ Consumer products
- ※ Instrumentation
- ※ Industrial


SPECIFICATION

Contact Rating	50mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	300V AC/1 minute
Operating Force	160±50gf, Brown(N) 260±50gf, Red(R)
Travel	0.25mm
Operating Life	20,000 cycles for 260gf 50,000 cycles for 160gf
Operating Temp.	-25°C ~ +70°C
Storage Temp.	-30°C ~ +80°C

HOW TO ORDER

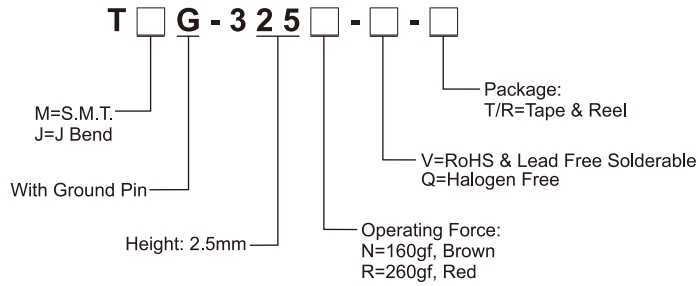



CIRCUIT

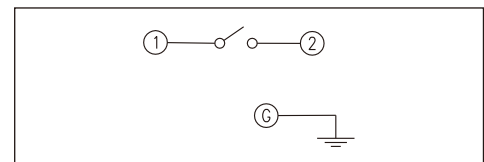



PACKAGE

<Tape & Reel>
2800 pcs

TMG-325

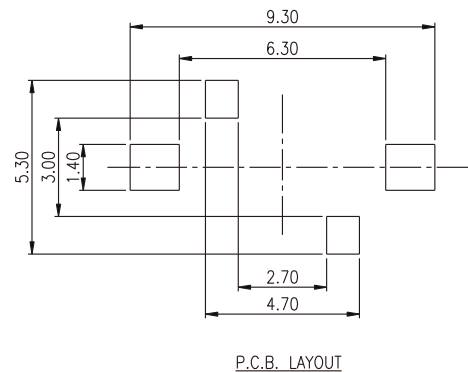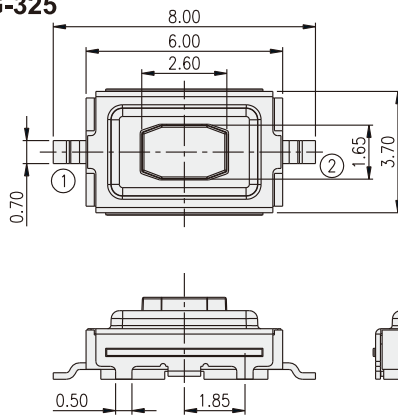

TJG-325

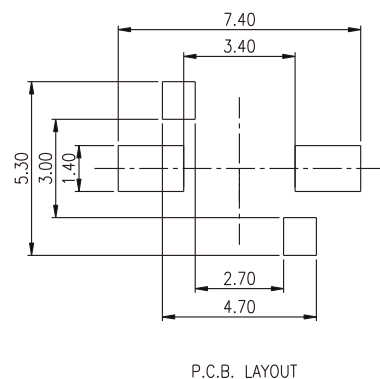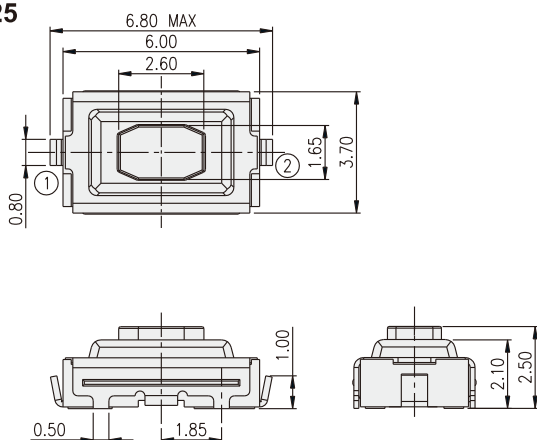

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[TMG-325R-V-T/R](#) [TJG-325R-V-T/R](#) [TJG-325N-V-T/R](#) [TMG-325N-V-T/R](#) [TMG-524-V-T/R](#) [TMG-533-V-T/R](#) [TMG-534-V-T/R](#)