


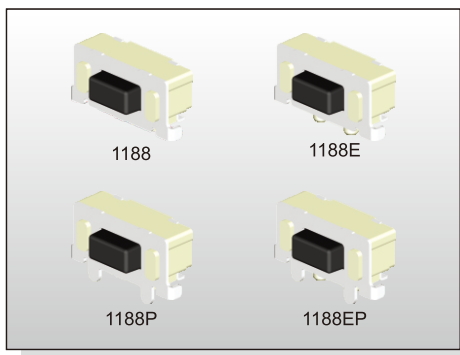

FEATURES

- ※Side actuated
- ※Support / Ground pins options
- ※High solder strength


APPLICATION

- ※Audio, OA equipment
- ※Instrumentation
- ※Remote control


SPECIFICATION

Contact Rating	50mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	250V AC/1 minute
Operating Force	160±50gf/260±50gf
Travel	0.25mm
Operating Life	30,000 cycles for 260gf 50,000 cycles for 160gf
Operating Temp.	-25°C ~ +70°C
Storage Temp.	-40°C ~ +80°C

HOW TO ORDER

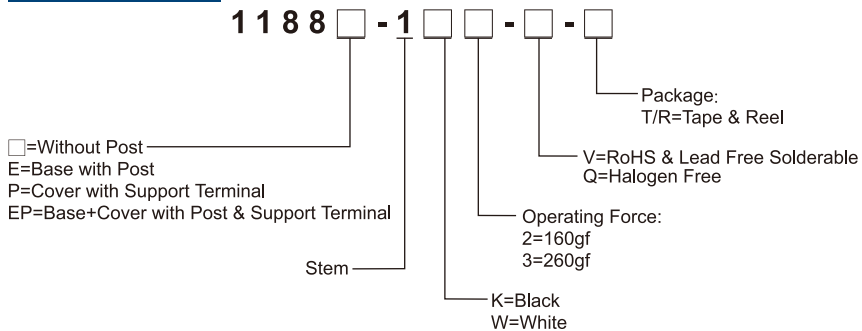


CIRCUIT

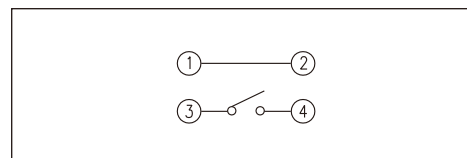


PACKAGE

<Tape & Reel>
1500 pcs


1188

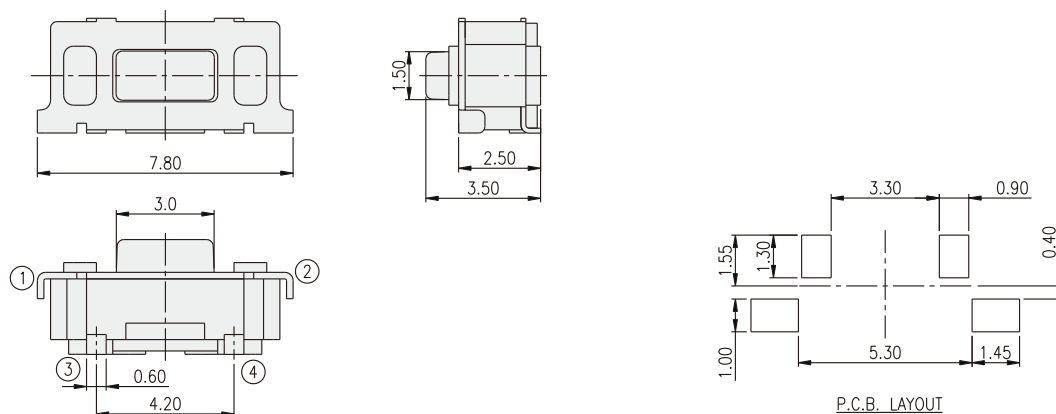


1188E

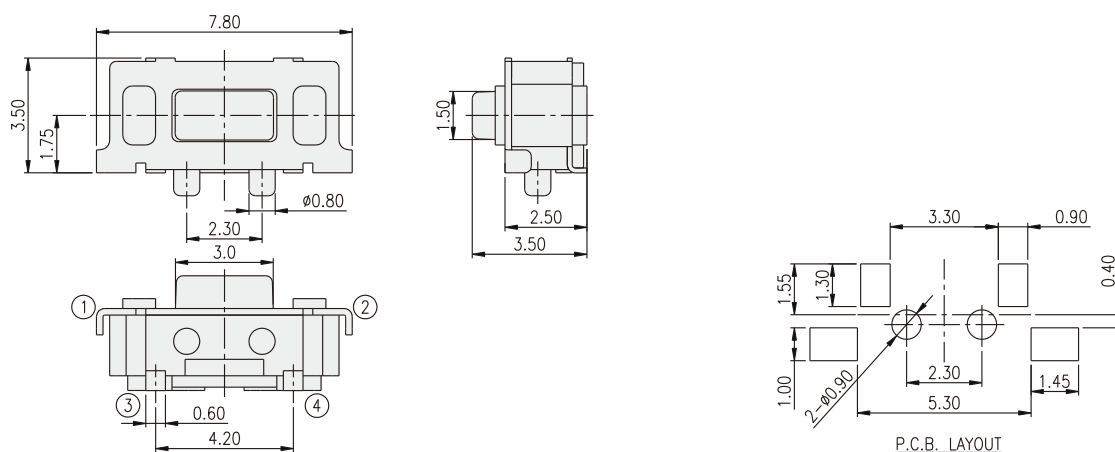

1188P

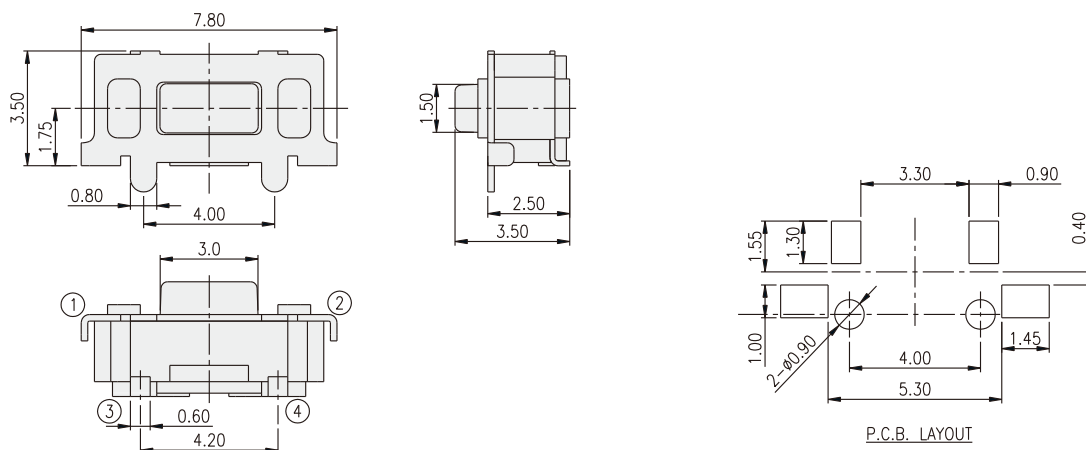

1188EP

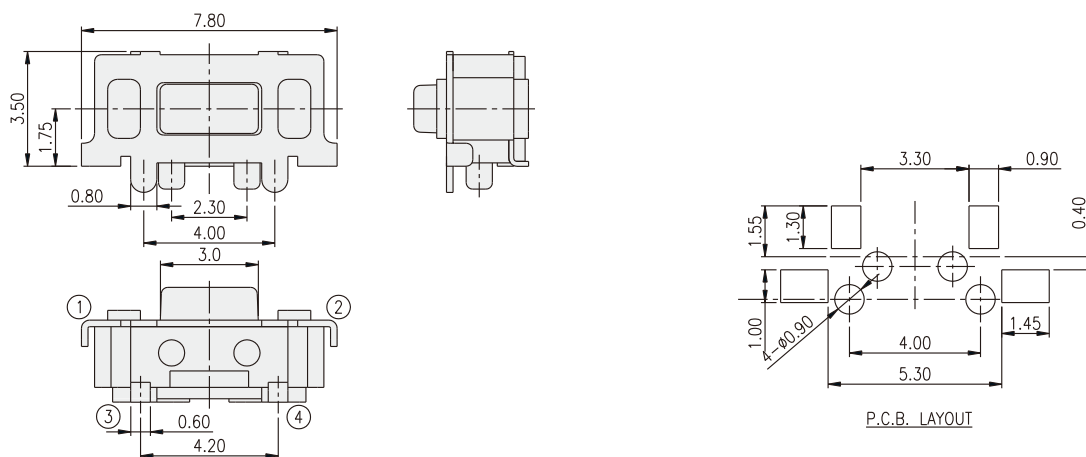

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[1188-1K3-V-T/R](#) [1188E-1K3-V-T/R](#) [1188EP-1K2-V-T/R](#) [1188EP-1W3-V-T/R](#) [1188EP-1W2-V-T/R](#) [1188EP-1K3-V-T/R](#) [1188E-1W2-V-T/R](#) [1188-1W2-V-T/R](#) [1188P-1K2-V-T/R](#) [1188E-1W3-V-T/R](#) [1188E-1K2-V-T/R](#) [1188P-1W3-V-T/R](#)
[1188-1W3-V-T/R](#) [1188-1K2-V-T/R](#) [1188E-1K2-Q-T/R](#)