

FEATURES

- ※Miniature 3.3x4.5mm side push type
- ※High solder strength
- ※Sharp click feeling


APPLICATION

- ※Smart phone
- ※Tablet
- ※Portable personal audio

SPECIFICATION

Contact Rating	50mA, 12V DC
Contact Resistance	500mΩ max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	160±50gf/250±50gf
Travel	0.2mm
Operating Life	100,000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-40°C ~ +85°C

CIRCUIT

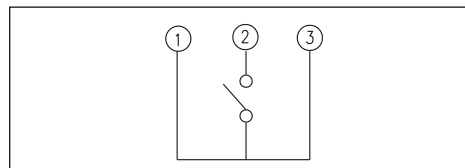

PACKAGE

<Tape & Reel>
1800 pcs

HOW TO ORDER

T A F ☐ - 1 ☐ W Q R

☐=Cover Without Post
G=Cover With Post
G1=Cover With Post & Ground Pin




Package:
Tape & Reel

Halogen Free

2=160gf
3=250gf




Stem Color:
W=White

TAFG

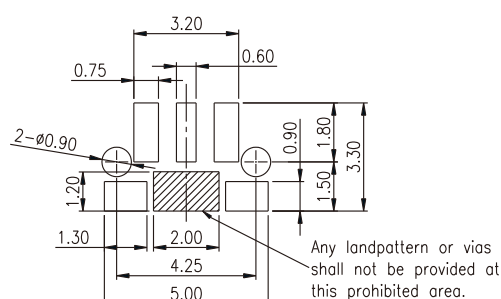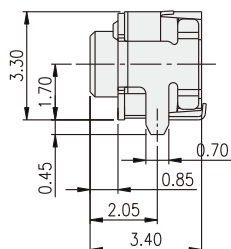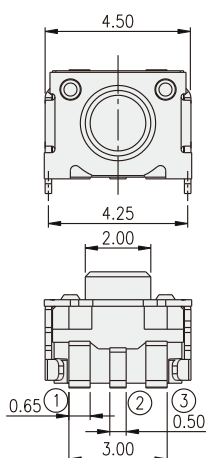

P.C.B. LAYOUT

TAFG1

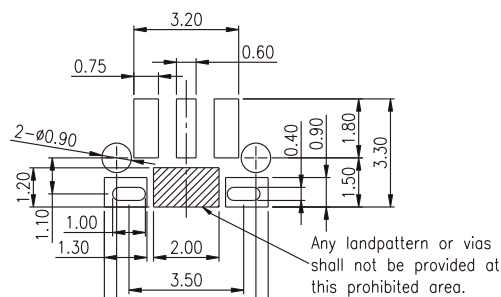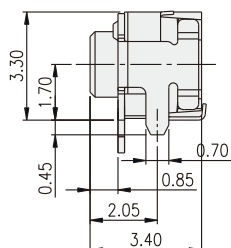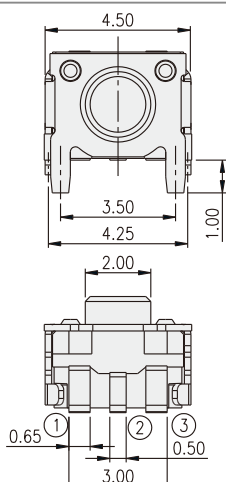

P.C.B. LAYOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[TAFG-13WQR](#) [TAFG-12WQR](#) [TAFG1-13WQR](#) [TAFG1-12WQR](#)