


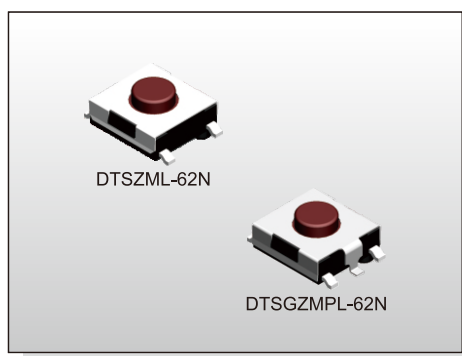

FEATURES

- ※Thinner type with 2.5-5.25mm height
- ※Ground terminal available
- ※Reflow solderable

APPLICATION

- ※Audio, OA equipment
- ※Instrumentation
- ※Consumer electronics

SPECIFICATION

Contact Rating	50mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	250V AC/1 minute
Operating Force	100±50gf, Black(K) 160±50gf, Brown(N) 260±50gf, Red(R)
Travel	0.25mm
Operating Life	100,000 cycles for 260gf 1,000,000 cycles for 160, 100gf
Operating Temp.	-25°C ~ +70°C
Storage Temp.	-30°C ~ +80°C

HOW TO ORDER

D T S ☐ **Z M** ☐ **L - 6** ☐ ☐ **-** ☐ **-** ☐

☐=Without Ground Pin
G=With Ground Pin

Terminal Pitch 4.5mm

☐=Without Post
P=With Post


Package:
☐=Bag
T/R=Tape & Reel
B=Tube
(Only For Without Post)

V=RoHS & Lead Free Solderable
Q=Halogen Free

Operating Force:
K=Black,100gf
N=Brown,160gf
R=Red,260gf

Height:
1=2.50mm
2=3.10mm
3=3.50mm
4=5.25mm

CIRCUIT

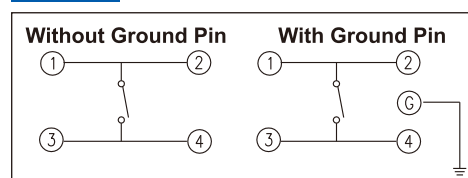

PACKAGE

<Tube>

75 pcs

<Tape & Reel>

DTS(G)ZML-61□: 2500 pcs


DTS(G)ZML-62□: 2500 pcs

DTS(G)ZMPL-61, 62: 1200 pcs




DTS(G)ZM(P)L-63: 1200 pcs

DTS(G)ZML(P)L-64: 900 pcs

DTSZML-6

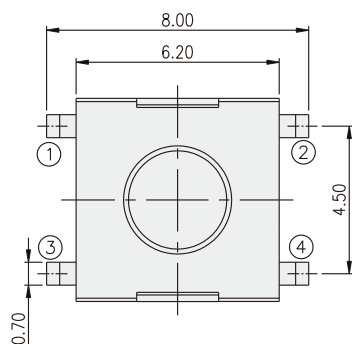


PART NO.	H
DTS□ZML-61	2.50
DTS□ZML-62	3.10
DTS□ZML-63	3.50
DTS□ZML-64	5.25

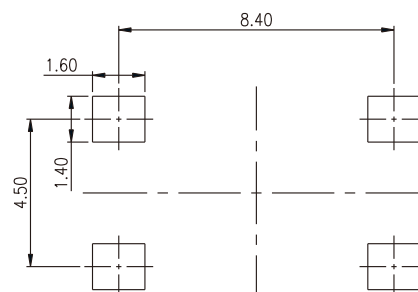
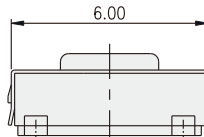
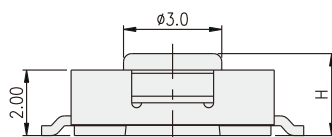


P.C.B. LAYOUT

DTSGZMPL-6

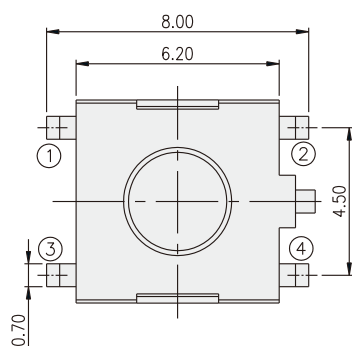

PART NO.	H
DTS□ZMPL-61	2.50
DTS□ZMPL-62	3.10
DTS□ZMPL-63	3.50
DTS□ZMPL-64	5.25

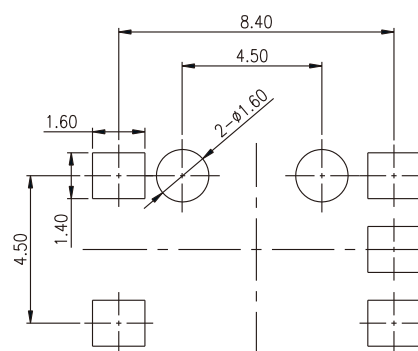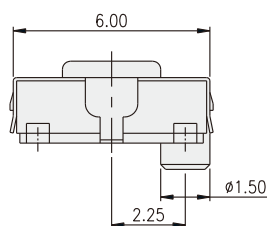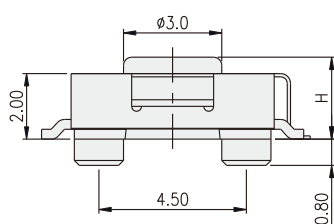

P.C.B. LAYOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[DTSGZMPL-64N-V-T/R](#) [DTSGZML-61R-V-T/R](#) [DTSZML-63K-V-T/R](#) [DTSZML-63R-V-T/R](#) [DTSGZML-62R-V-T/R](#)
[DTSZML-62N-V-T/R](#) [DTSZML-61R-V-T/R](#) [DTSZML-63N-V-T/R](#) [DTSZML-61K-V-T/R](#) [DTSGZMPL-62N-V-T/R](#)
[DTSGZML-62N-V-T/R](#) [DTSZML-62R-V-T/R](#) [DTSGZML-61K-V-T/R](#) [DTSGZML-61N-V-T/R](#) [DTSGZML-62K-V-T/R](#)
[DTSGZMPL-61N-V-T/R](#) [DTSZML-62K-V-T/R](#) [DTSZML-61N-V-T/R](#)