


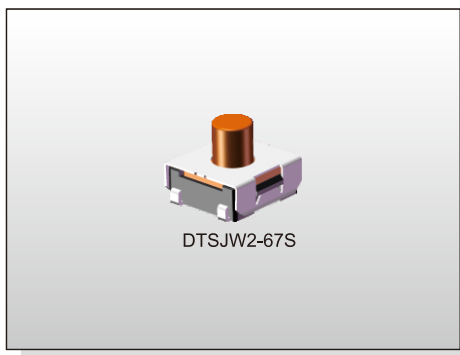

FEATURES

- ※Sealed
- ※Gold contact available
- ※Dust proof with high reliability


APPLICATION

- ※Audio, OA equipment
- ※Instrumentation, Communication
- ※White goods

SPECIFICATION

Contact Rating	50mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	250V AC/1 minute
Operating Force	200±50gf, 400±100gf
Travel	0.4/0.6mm
Operating Life	300, 000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-40°C ~ +85°C

CIRCUIT

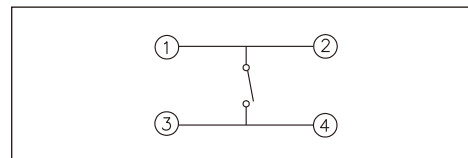


PACKAGE


<Tape & Reel>

DTSJW□-65: 1900 pcs
DTSJW□-67: 900 pcs




HOW TO ORDER

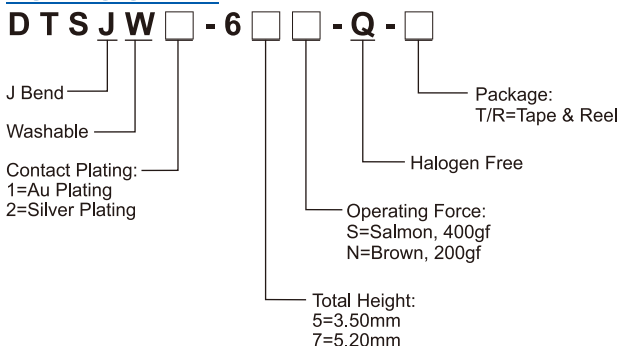

DTSJW□-6

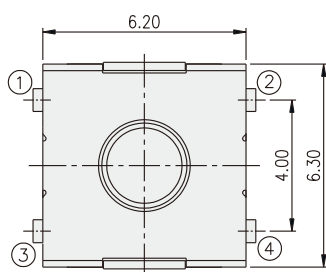

PART NO.	H
DTSJW□-65	3.50
DTSJW□-67	5.20

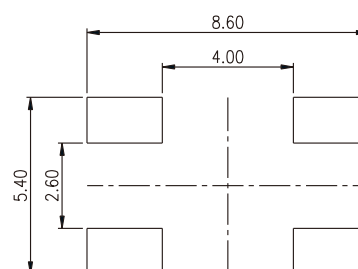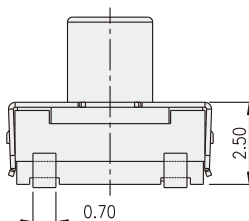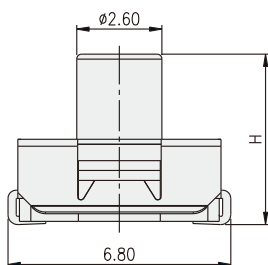

P.C.B. LAYOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[DTSJW1-67S-Q-T/R](#) [DTSJW2-67N-Q-T/R](#) [DTSJW2-67S-Q-T/R](#) [DTSJW1-65S-Q-T/R](#) [DTSJW1-65N-Q-T/R](#)
[DTSJW1-67N-Q-T/R](#) [DTSJW2-65N-Q-T/R](#) [DTSJW2-65S-Q-T/R](#)