


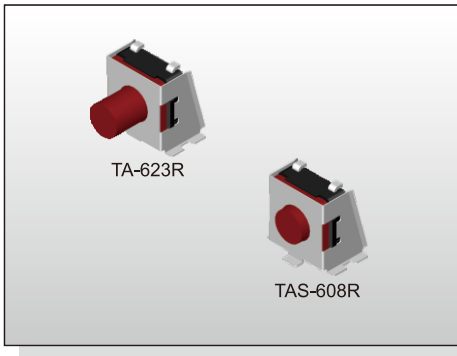

FEATURES

- ※Right angle (SMT type)
- ※Support terminal available
- ※Reflow solderable


APPLICATION

- ※Audio, OA equipment
- ※Instrumentation
- ※Hair dryers


SPECIFICATION

Contact Rating	50mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	250V AC/1 minute
Operating Force	180±50gf, Brown(N) 260±70gf, Red(R)
Travel	0.45mm
Operating Life	500, 000 cycles
Operating Temp.	-25°C ~ +70°C
Storage Temp.	-30°C ~ +80°C

HOW TO ORDER

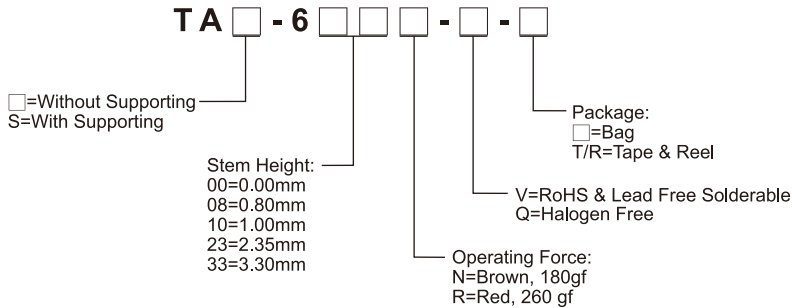

CIRCUIT

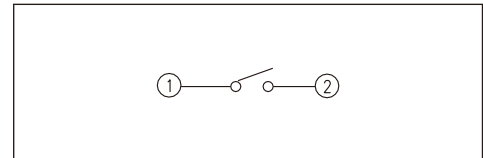

PACKAGE

<Bag>


500 pcs

<Tape & Reel>




TA(S)-600 / 608 / 610 / 623: 700 pcs

TA(S)-633: 500 pcs


TA-6

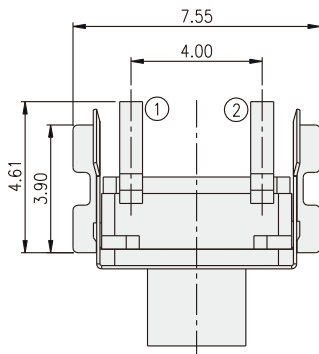




PART NO.	H
TA-600	0
TA-608	0.80
TA-610	1.00
TA-623	2.35
TA-633	3.30

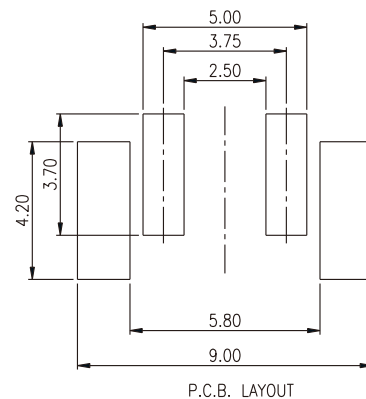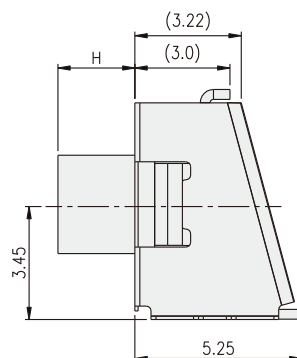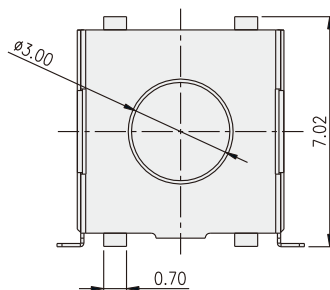

TAS-6

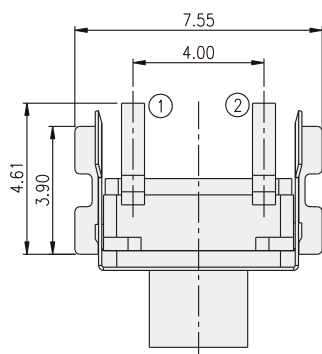

PART NO.	H
TAS-600	0
TAS-608	0.80
TAS-610	1.00
TAS-623	2.35
TAS-633	3.30

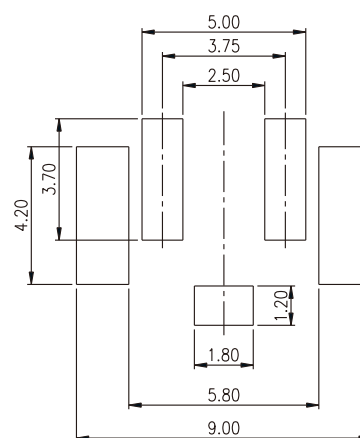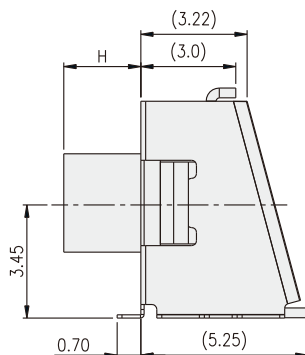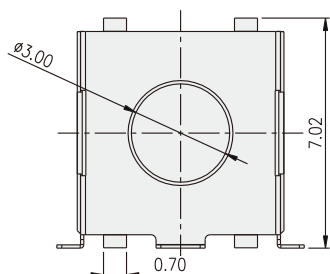

P.C.B. LAYOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[TA-608R-V-T/R](#) [TA-608N-V-T/R](#) [TA-623R-V-T/R](#) [TA-610R-V-T/R](#) [TAS-633R-V-T/R](#) [TA-610N-V-T/R](#) [TA-623N-V-T/R](#)
[TA-633N-V-T/R](#) [TAS-633N-V-T/R](#) [TA-633R-V-T/R](#) [TAS-608R-V-T/R](#) [TAS-600N-V-T/R](#) [TAS-623N-V-T/R](#) [TAS-](#)
[600R-V-T/R](#) [TAS-610N-V-T/R](#) [TAS-610R-V-T/R](#) [TAS-608N-V-T/R](#) [TAS-623R-V-T/R](#)