


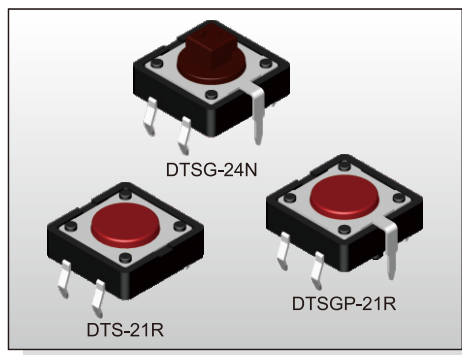

FEATURES

- ※Snap in type with ground pin
- ※Guide bosses available
- ※Cap options


APPLICATION

- ※Audio, OA equipment
- ※Instrumentation
- ※Industrial


SPECIFICATION

Contact Rating	50mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	250V AC/1 minute
Operating Force	130±50gf, Black(K) 160±50gf, Brown(N) 260±50gf, Red(R) 320±80gf, Salmon(S) 520±130gf, Yellow(Y)
Travel	0.35mm
Operating Life	Phosphor Bronze Dome 100,000 cycles for 520/320/260gf 200,000 cycles for 160gf Stainless Steel Dome 300,000 cycles for 520/320gf 500,000 cycles for 260gf 1,000,000 cycles for 160gf 10,000,000 cycles for 130gf
Operating Temp.	-25°C ~ +70°C
Storage Temp.	-30°C ~ +80°C

HOW TO ORDER

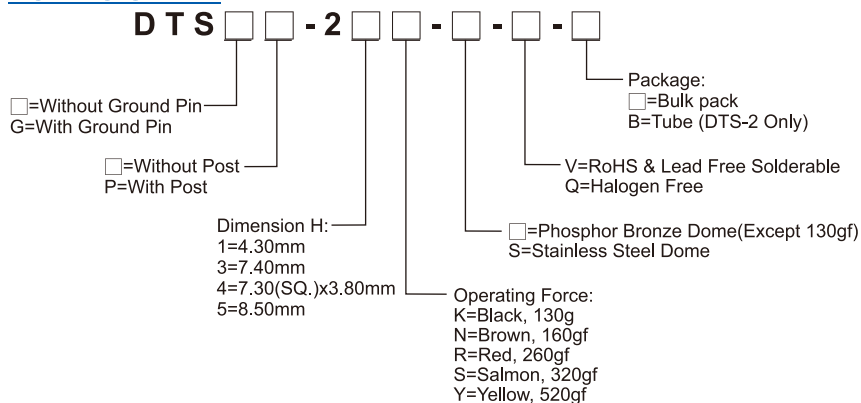

CIRCUIT

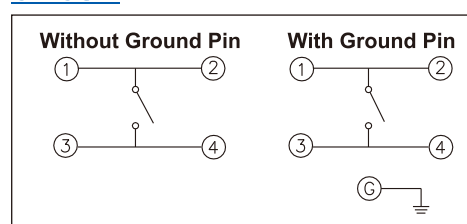

PACKAGE



<Bag>

500 pcs

<Tube>


DTS-2: 40 pcs

DTS-2


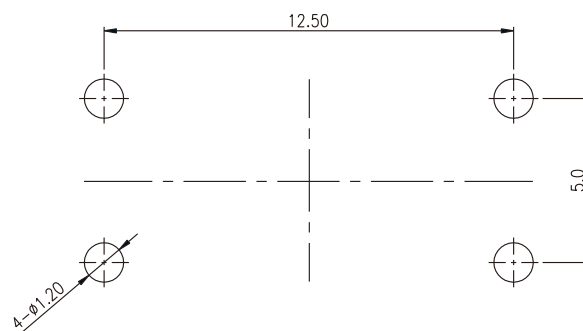
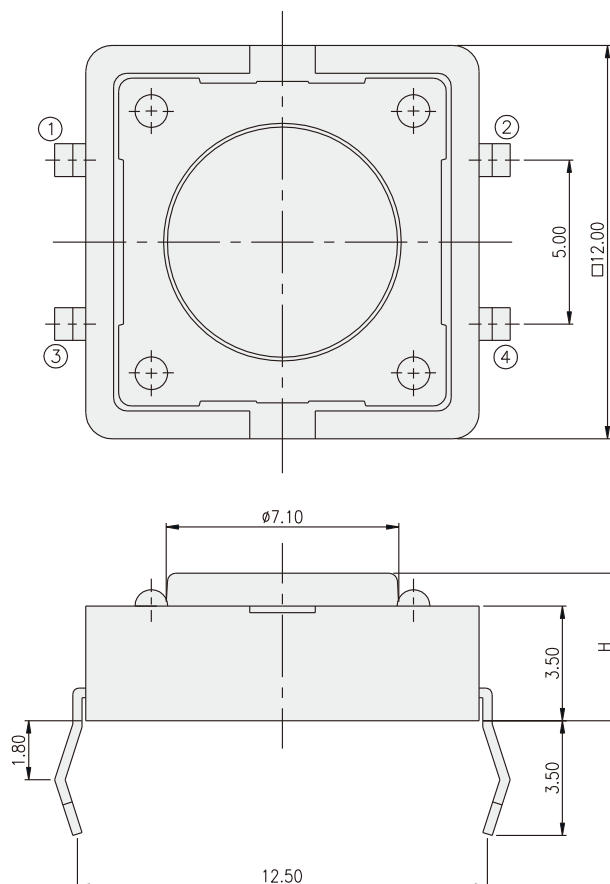


P.C.B. LAYOUT




PART NO.	H
DTS-21	4.30
DTS-23	7.40
DTS-25	8.50

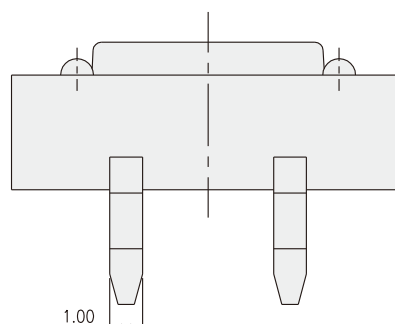



DTS-24

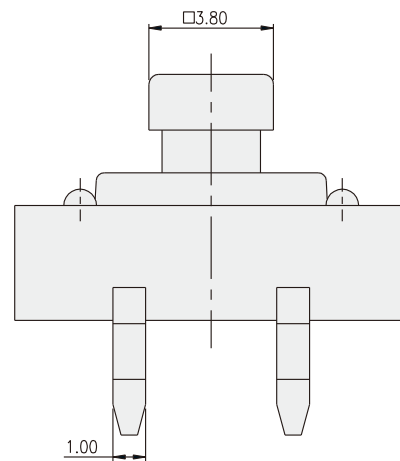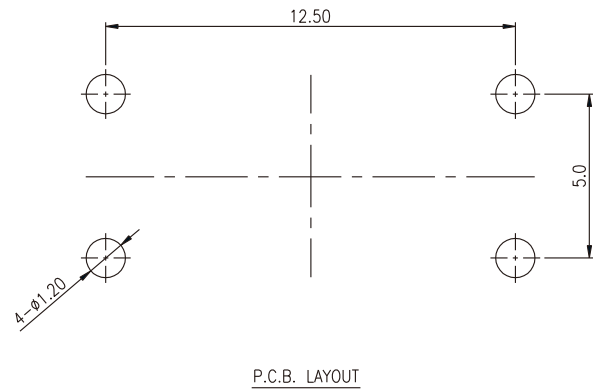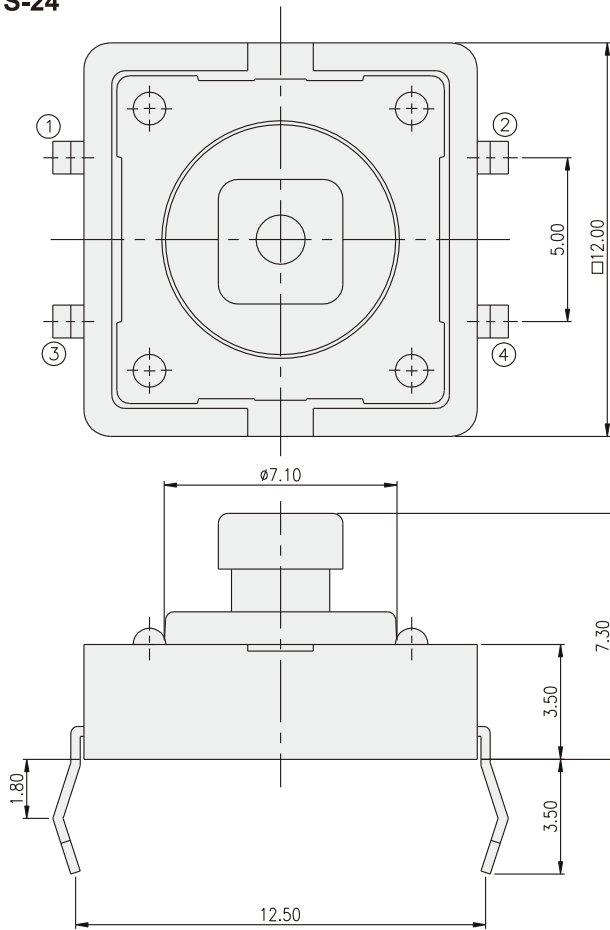

DTSP-24

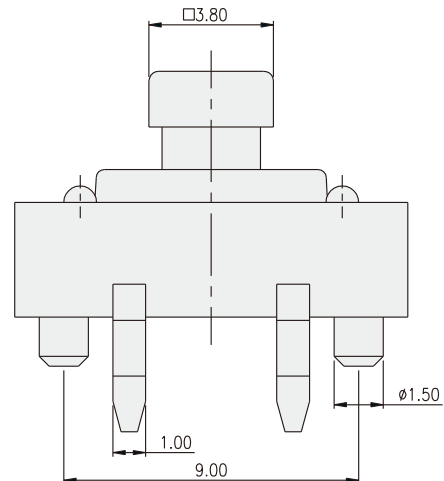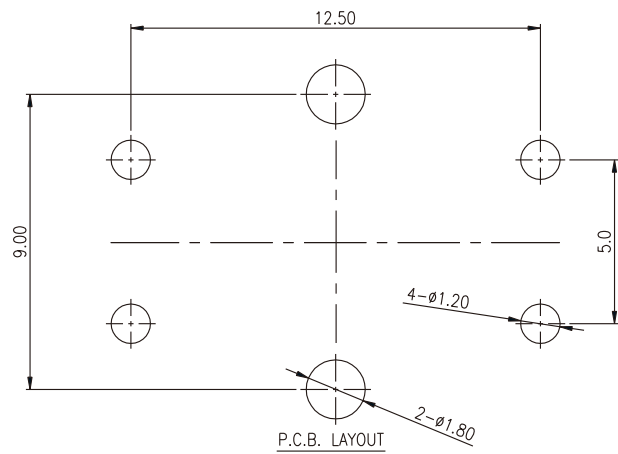
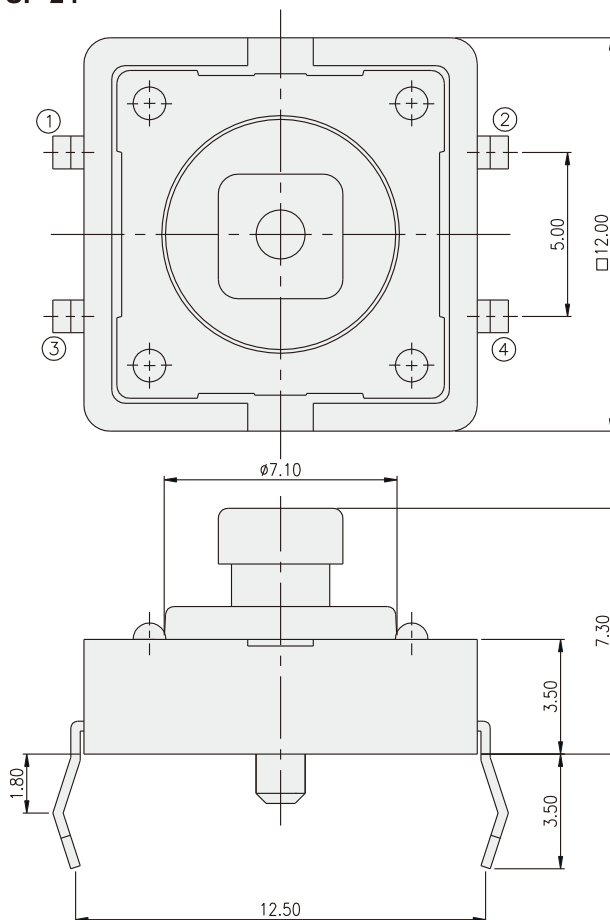


DTSG-2

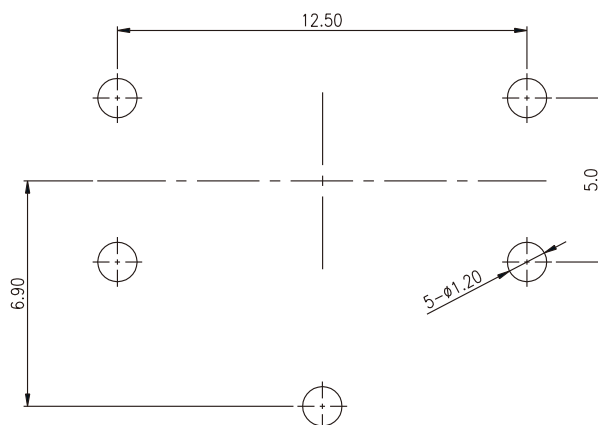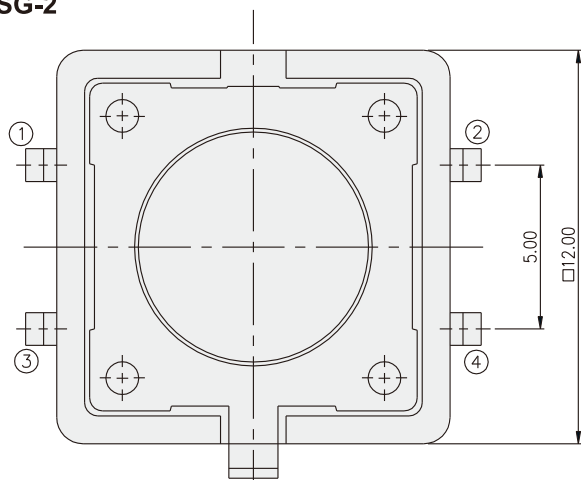



P.C.B. LAYOUT

PART NO.	H
DTSG-21	4.30
DTSG-23	7.40
DTSG-25	8.50

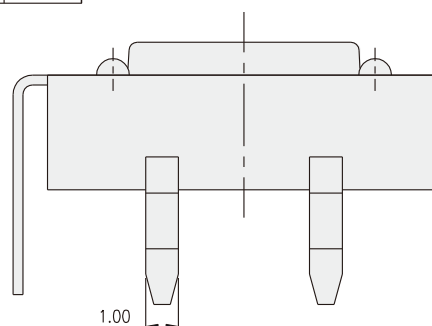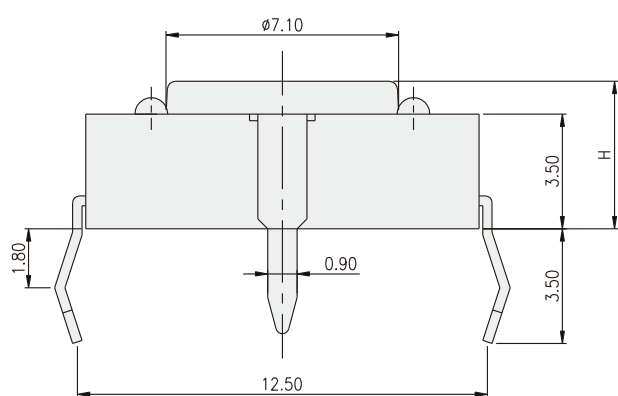



TACT SWITCH

DTSGP-2

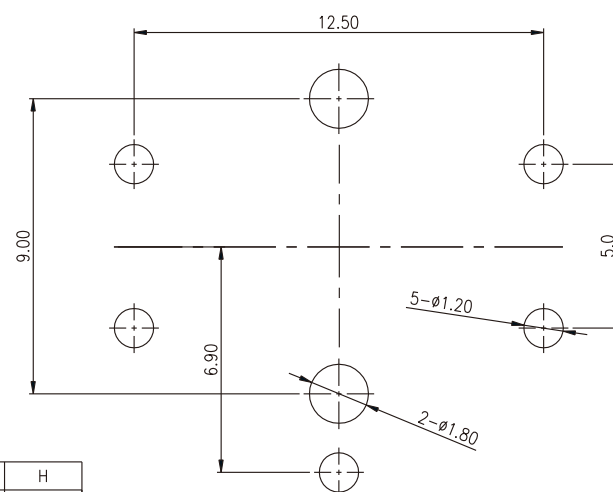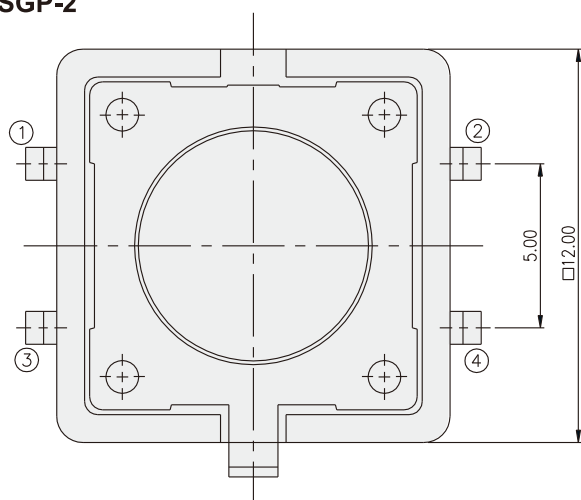

P.C.B. LAYOUT

PART NO.	H
DTSGP-21	4.30
DTSGP-23	7.40
DTSGP-25	8.50

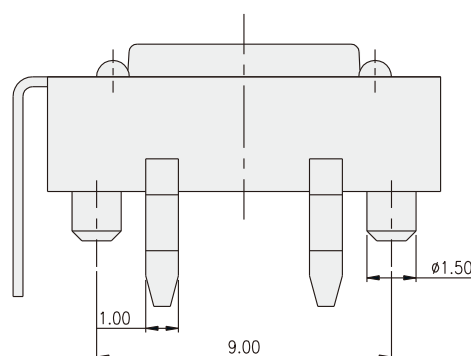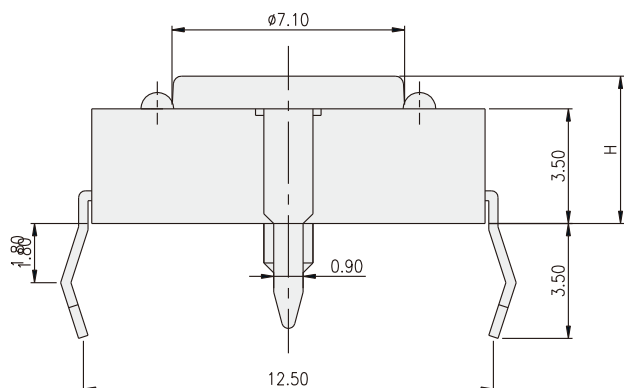

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[DTS-25N-V-B](#) [DTS-24R-V-B](#) [DTSP-24R-V](#) [DTSP-24N-S-V](#) [DTS-21S-S-V](#) [DTSP-21R-S-V](#) [DTS-21R-V-B](#) [DTS-25N-S-V](#) [DTS-24N-V-B](#) [DTS-24Y-V](#) [DTS-24R-S-V](#) [DTSP-21R-V](#) [DTS-23N-V](#) [DTSP-24Y-V](#) [DTSP-25N-S-V](#) [DTS-21N-S-V](#) [DTSP-24N-V](#) [DTS-21R-S-V](#) [DTSP-25R-S-V](#) [DTSP-21N-S-V](#) [DTS-25R-V-B](#) [DTS-25R-S-V](#) [DTSP-25R-V](#) [DTS-21N-V-B](#) [DTSP-24R-S-V](#) [DTSP-21N-V](#) [DTSP-24S-V](#) [DTS-21Y-V](#) [DTS-24N-S-V](#) [DTSP-25N-V](#) [DTS-24S-V](#) [DTS-21S-V](#) [DTS-21R-V](#) [DTS-21N-V](#) [DTS-24R-V](#) [DTS-24N-V](#) [DTS-25S-V](#) [DTS-25R-V](#) [DTS-25N-V](#) [DTS-66K-S-V](#)