


SLIDE SWITCH SD12 SERIES

Slide Type
(1P3T)

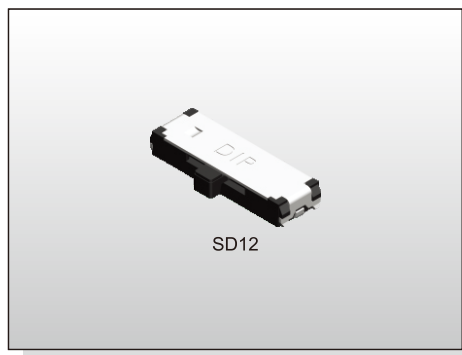

FEATURES

- ※1.45mm height
- ※1P3T model
- ※Single side recoil


APPLICATION

- ※Remote control
- ※Consumer electronics
- ※Instrumentations

SPECIFICATION

Contact Rating	0.3A, 15V DC
Contact Resistance	1Ω max.
Insulation Resistance	10MΩ min. 100V DC
Dielectric Strength	100V AC/1 minute
Operating Force	150±100gf
Travel	1.5mm
Operating Life	5,000 cycles
Operating Temp.	-10°C ~ +60°C
Storage Temp.	-25°C ~ +85°C

CIRCUIT

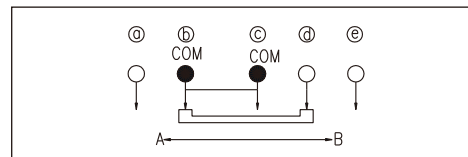

PACKAGE

<Tape & Reel>
3000 pcs

HOW TO ORDER

SD12-LP - V -

Package:
T/R=Tape & Reel

RoHS & Lead Free Solderable



R=Recoil on the Right

With Post

J Bend

Poles-Positions:
1P3T

SD12-LPR

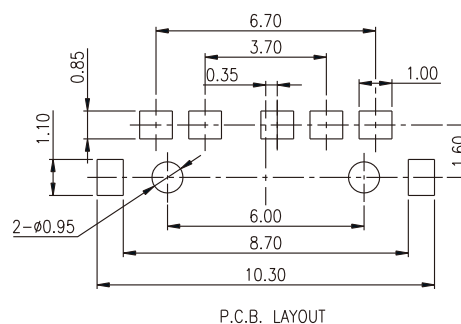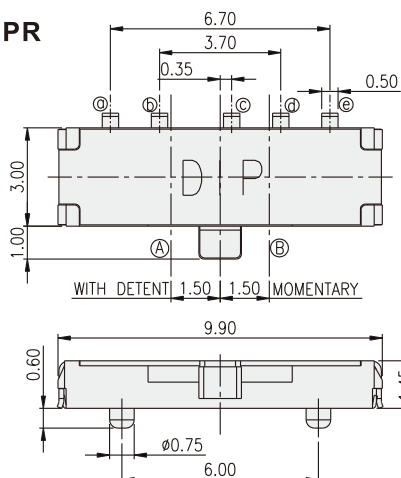

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[SD12-LPR-V-T/R](#)