


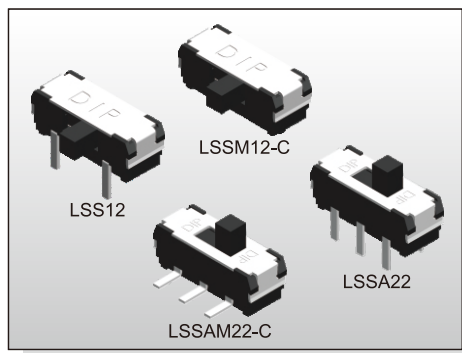

FEATURES

- ※2.0mm stroke
- ※Through hole or SMT
- ※1P2T, 2P2T models


APPLICATION

- ※Remote control
- ※Consumer electronics
- ※Instrumentations

SPECIFICATION

Contact Rating	0.1A, 12V DC
Contact Resistance	60mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	500V AC/1 minute
Operating Force	200±150gf
Travel	2mm
Operating Life	10,000 cycles
Operating Temp.	-10°C ~ +60°C
Storage Temp.	-20°C ~ +70°C

CIRCUIT

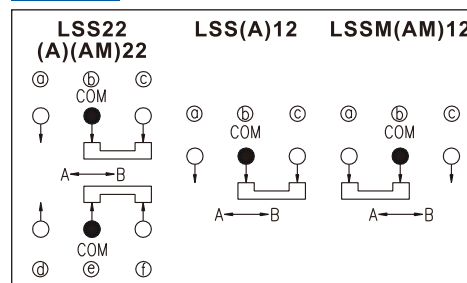

PACKAGE

<Bag>

LSS(A)12, 22: 1000 pcs

<Tube>

LSS□2, LSS□2M, LSS□2L: 50 pcs

<Tape & Reel>

LSS12, 22-N,P,S,Q,R: 900 pcs

LSS12, 22-□,M,L: 800 pcs

LSS12, 12-40-P, 22□-40: 800 pcs

LSSM12-P, LSSM12-40-P: 800 pcs


LSSM12: 1000 pcs

LSSA(M)12, 22: 600 pcs


LSSA12, 22M,L-P: 600 pcs

LSSA12, 22R-P: 500 pcs

HOW TO ORDER



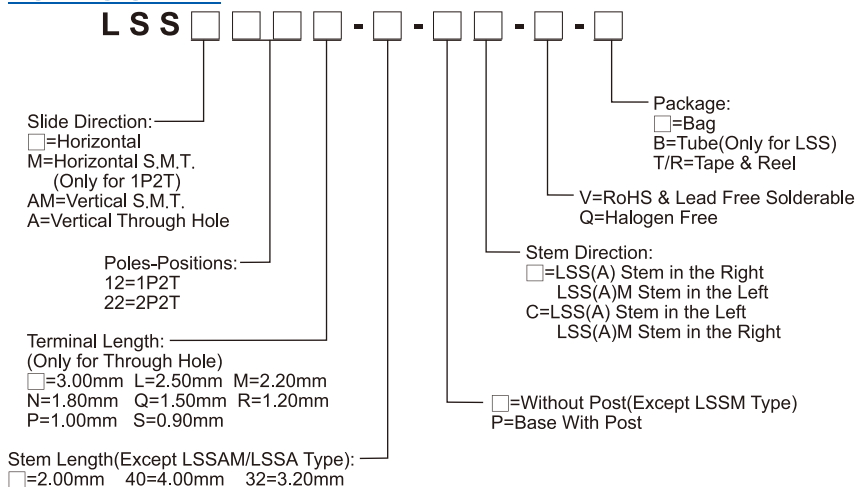


LSS22

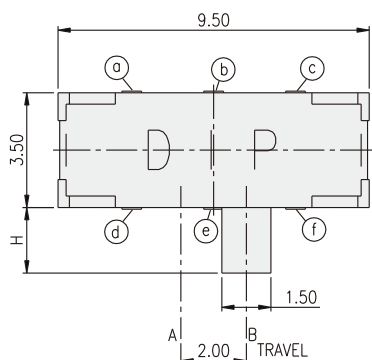


PART NO.	H
LSS22	2.0
LSS22-32	3.20
LSS22-40	4.0

PART NO.	L
LSS22	3.0
LSS22S	0.90
LSS22P	1.0
LSS22R	1.20
LSS22Q	1.50
LSS22N	1.80
LSS22M	2.20
LSS22L	2.50

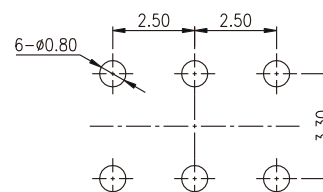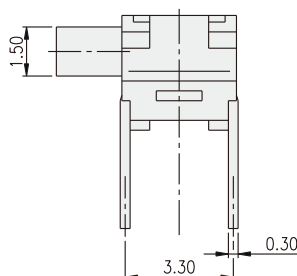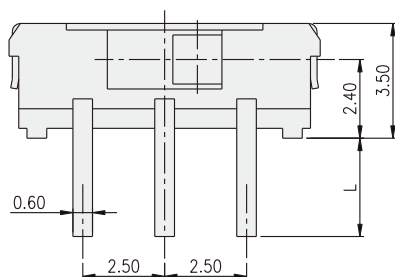



P.C.B. LAYOUT

LSS12

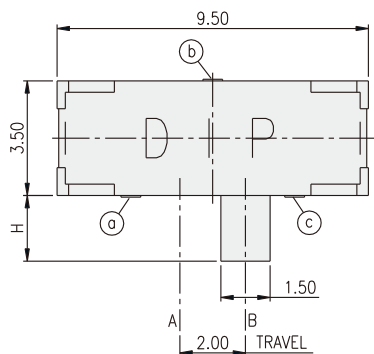


PART NO.	H
LSS12	2.00
LSS12-32	3.20
LSS12-40	4.00

PART NO.	L
LSS12	3.0
LSS12S	0.90
LSS12P	1.0
LSS12R	1.20
LSS12Q	1.50
LSS12N	1.80
LSS12M	2.20
LSS12L	2.50

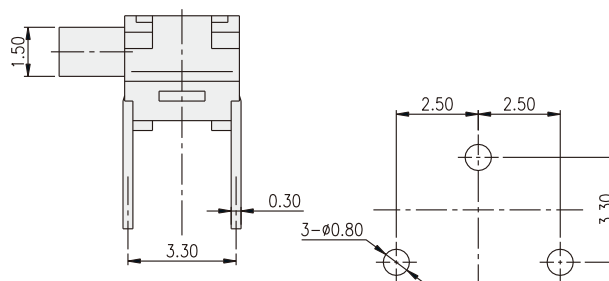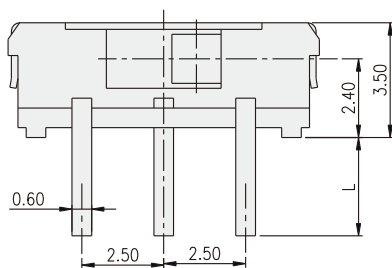


P.C.B. LAYOUT

LSSA22




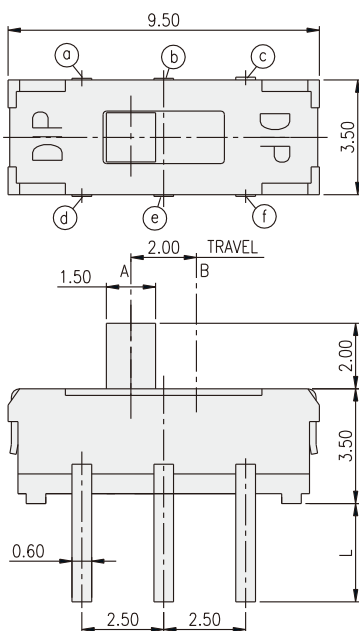


PART NO.	L
LSSA22	3.0
LSSA22S	0.90
LSSA22P	1.0
LSSA22R	1.20
LSSA22Q	1.50
LSSA22N	1.80
LSSA22M	2.20
LSSA22L	2.50




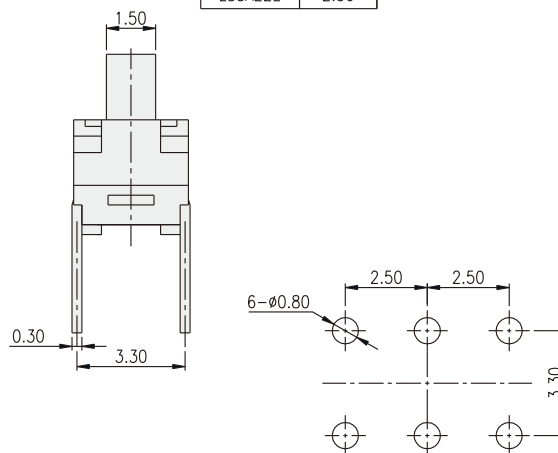


P.C.B. LAYOUT

LSSM12-P

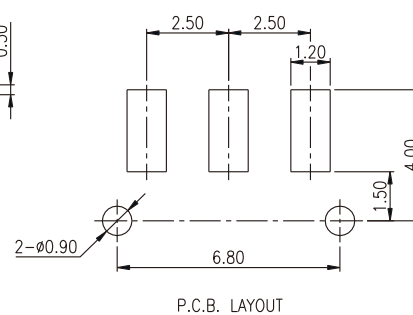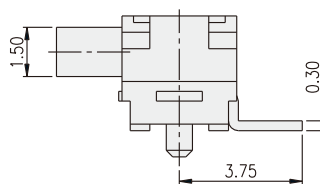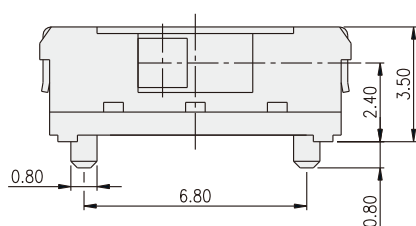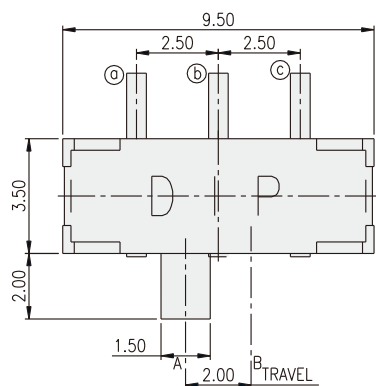

LSSAM22-P

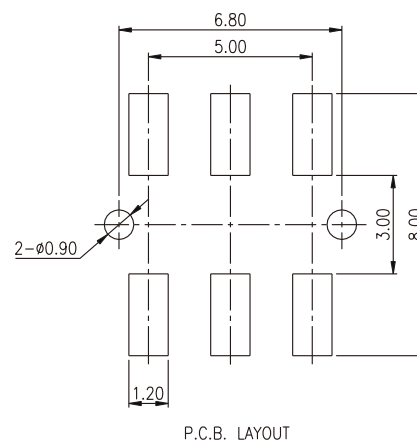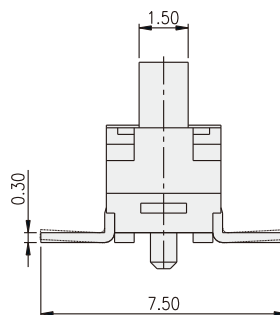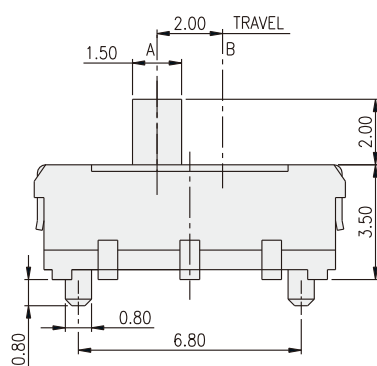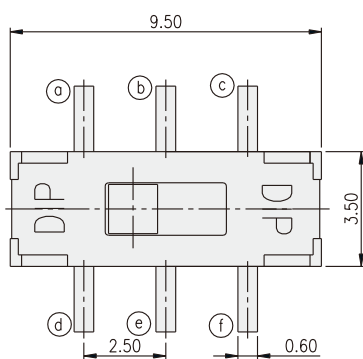

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[LSSAM12-V-T/R](#) [LSSAM22-V-T/R](#) [LSS12-V-B](#) [LSSA12-V-B](#) [LSS22-V-B](#) [LSSA22-V-B](#) [LSSAM12-P-V-T/R](#)
[LSSAM22-P-V-T/R](#)