

### FEATURES

- ※ 3.0mm height
- ※ Through hole type
- ※ 1P2T model


### APPLICATION

- ※ Remote control
- ※ Consumer electronics
- ※ Instrumentations

### SPECIFICATION

Contact Rating	0.3A, 10V DC
Contact Resistance	50mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	500V AC/1 minute
Operating Force	100~300gf
Travel	2.5mm
Operating Life	10, 000 cycles
Operating Temp.	-10°C ~ +60°C
Storage Temp.	-20°C ~ +75°C


### CIRCUIT

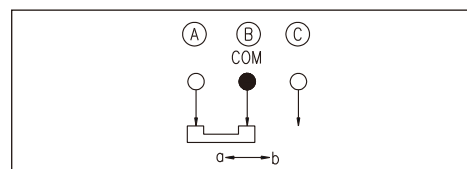


### PACKAGE

<Tape & Reel>  
650 pcs



### HOW TO ORDER

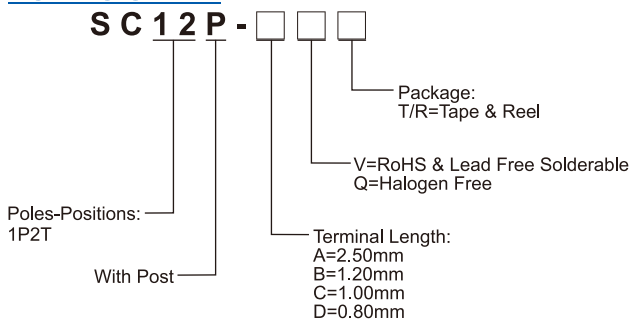

### SC12P

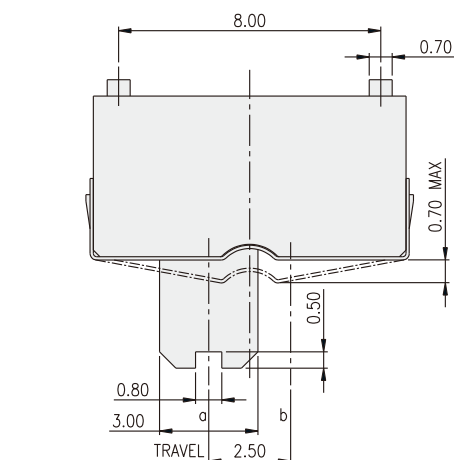

PART NO.	L
SC12P-A	2.50
SC12P-B	1.20
SC12P-C	1.00
SC12P-D	0.80

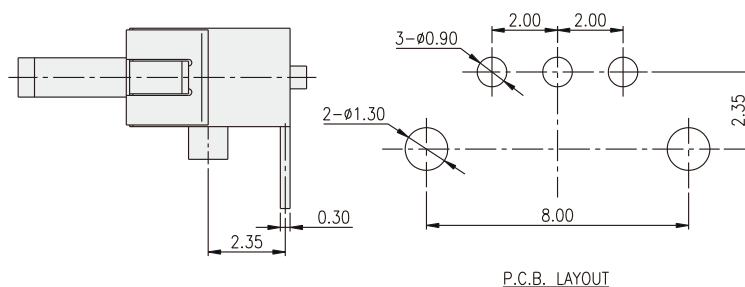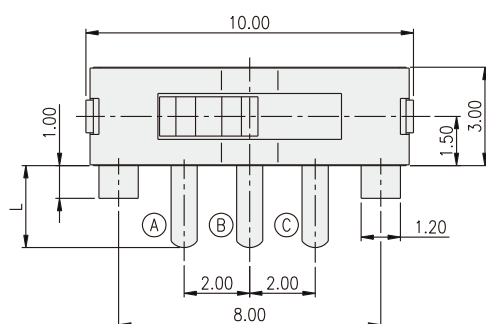

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[SC12P-AQR](#) [SC12P-BQR](#)