

FEATURES

- ※ 1P3T model
- ※ Single-side recoil type
- ※ Reflow solderable

APPLICATION

- ※ Remote control
- ※ Consumer electronics
- ※ Instrumentations

SPECIFICATION

Contact Rating	0.3A, 4V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	500V AC/1 minute
Operating Force	320±150gf (ON-TEST) 320±150gf (OFF-ON) 500+100/-200gf (ON-OFF)
Travel	2mm (ON-TEST) 4mm (OFF-ON) 4mm (ON-OFF)
Operating Life	10, 000 cycles
Operating Temp.	-20°C ~ +70°C
Storage Temp.	-40°C ~ +85°C

HOW TO ORDER

NSS13 - V -

Poles-Positions:
1P3T

L=Spring On The Left
R=Spring On The Right

Package:
T/R=Tape & Reel


RoHS & Lead Free Solderable

C=With Post




PACKAGE

<Tape & Reel>
800 pcs

CIRCUIT


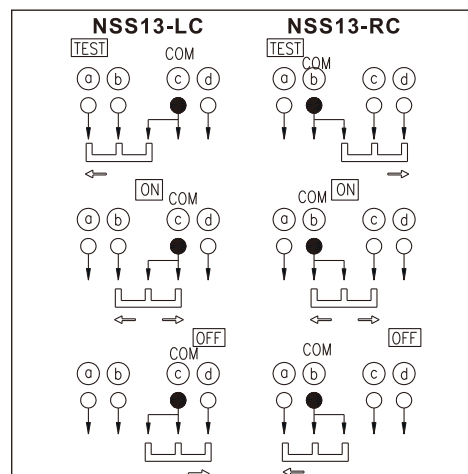


NSS13-LC

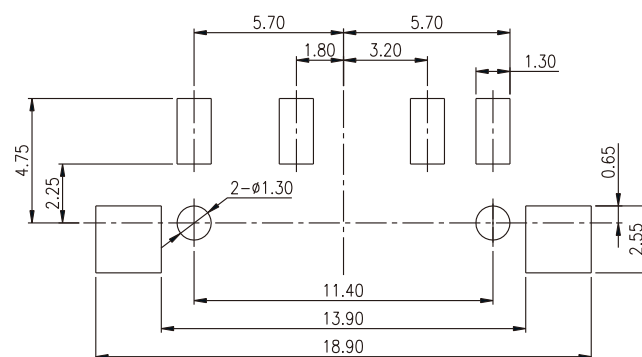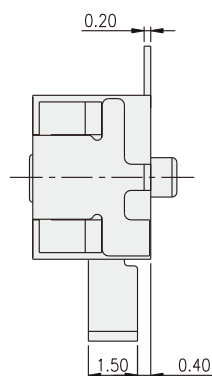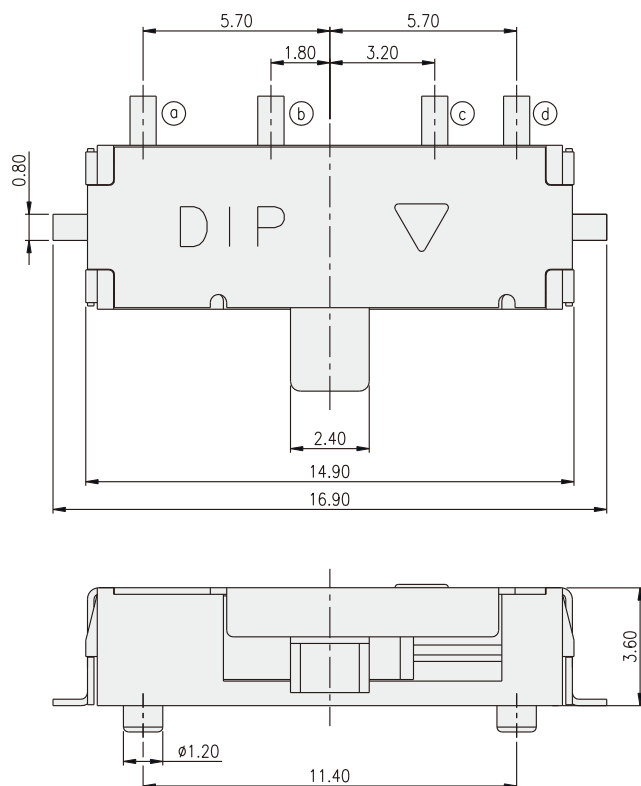

P.C.B. LAYOUT

NSS13-RC

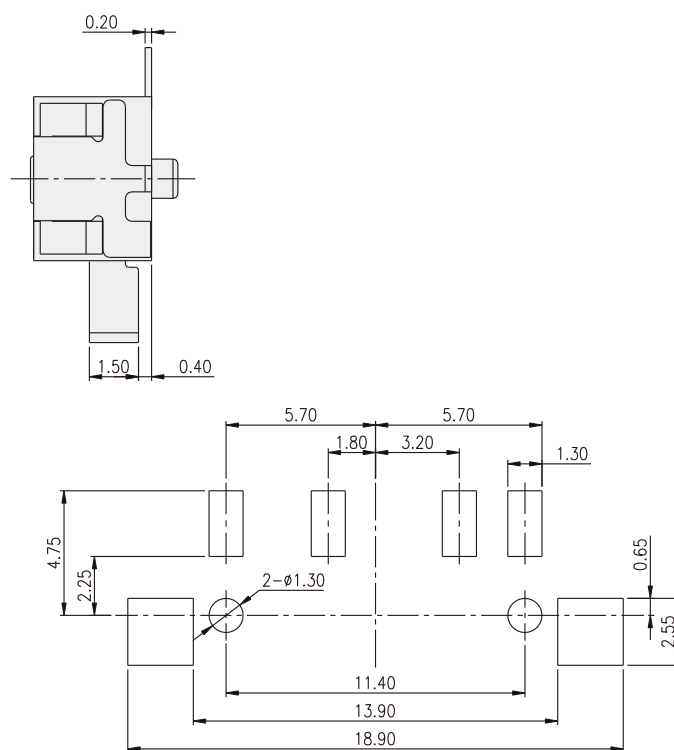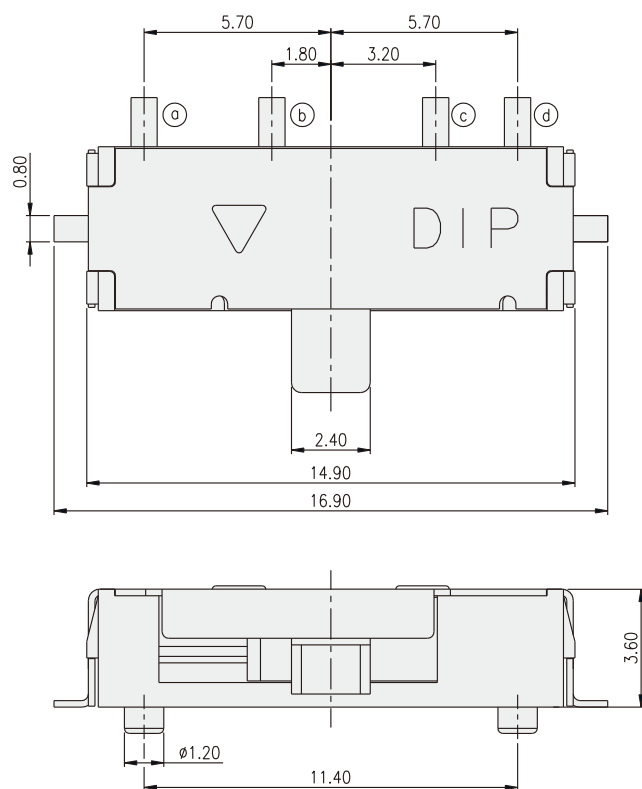

P.C.B. LAYOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[NSS13-LC-V-T/R](#)