

FEATURES

- ※2.0mm height
- ※1P2T model
- ※Stroke 2.7mm

APPLICATION

- ※Remote control
- ※Consumer electronics
- ※Instrumentations

SPECIFICATION

Contact Rating	0.3A, 4V DC
Contact Resistance	70mΩ max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	100V AC/1 minute
Operating Force	180±70gf
Travel	2.7mm
Operating Life	10,000 cycles
Operating Temp.	-10°C ~ +60°C
Storage Temp.	-20°C ~ +75°C

HOW TO ORDER

SSS - 12

Poles-Positions:
1P2T


L=Actuator on the Left
R=Actuator on the Right

Package:
T/R=Tape & Reel

V=RoHS & Lead Free Solderable
Q=Halogen Free

□=Without Ground Pin
G=Ground Pin




CIRCUIT

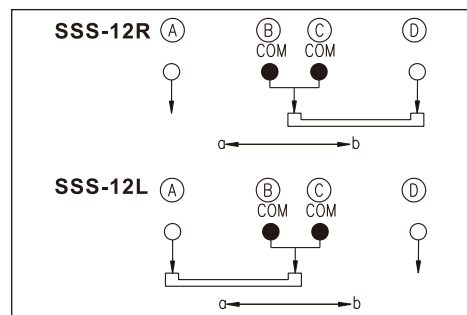




PACKAGE

<Tape & Reel>
2000 pcs

 SSS-12R

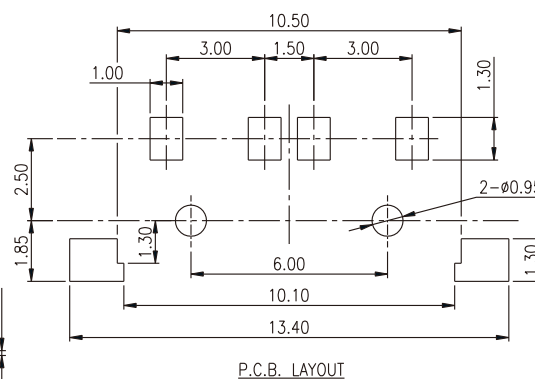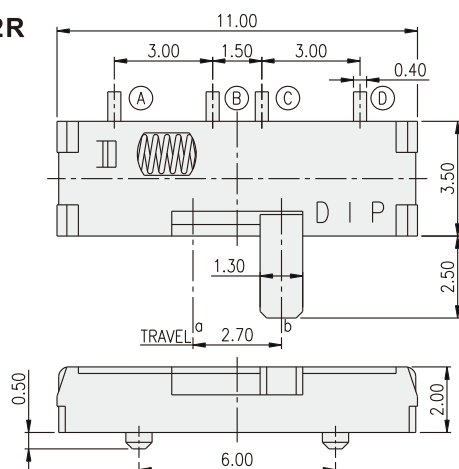

SSS-12LG

 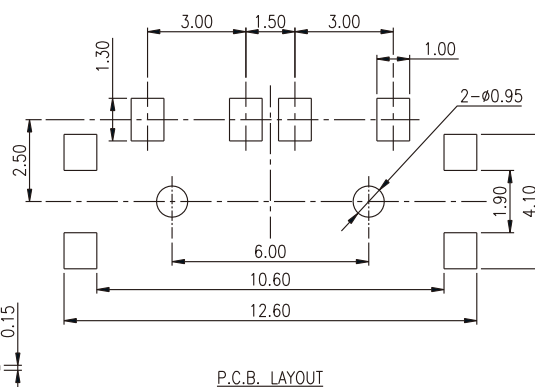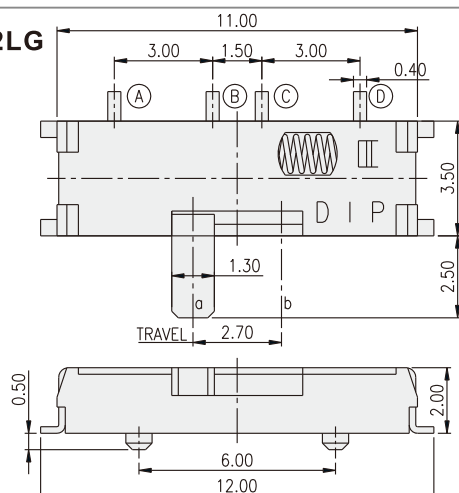

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[SSS-12R-V-T/R](#) [SSS-12L-V-T/R](#) [SSS-12RG-V-T/R](#) [SSS-12LG-V-T/R](#)