

FEATURES

- ※ Guiding post offers easy orientation
- ※ Operation force: 35gf max.


APPLICATION

- ※ Open/close detection
- ※ Notebook
- ※ DSC

SPECIFICATION

Contact Rating	0.1mA~100mA, 20mV~5V DC
Contact Resistance	500mΩ max.
Insulation Resistance	100MΩ min. 250V DC
Dielectric Strength	250V AC/1 minute
Operating Force	35gf max.
Travel	1.05mm
Operating Life	80,000 cycles
Operating Temp.	-15°C ~ +70°C
Storage Temp.	-40°C ~ +85°C


CIRCUIT

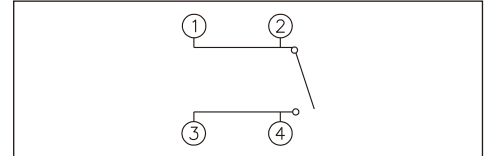




PACKAGE

<Tape & Reel>
1800 pcs

HOW TO ORDER



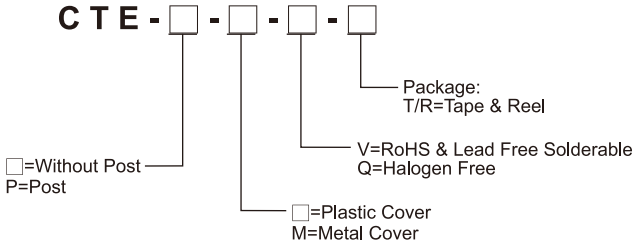


CTE-M

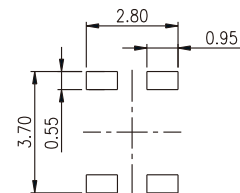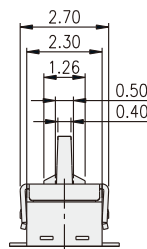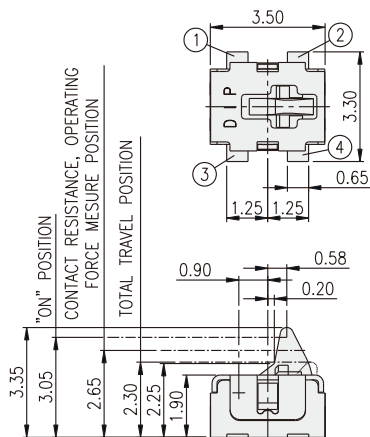

P.C.B. LAYOUT

CTE-P

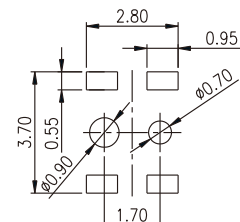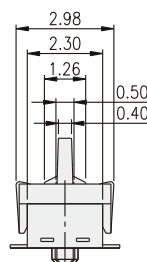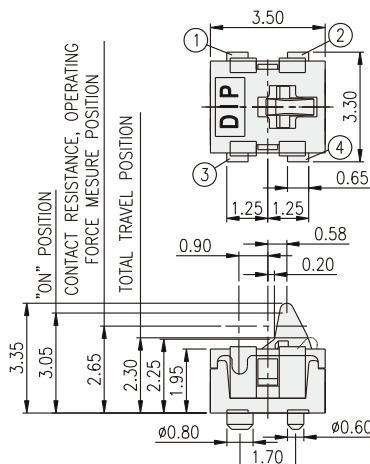

P.C.B. LAYOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Diptronics:](#)

[CTE-P-V-T/R](#) [CTE-V-T/R](#) [CTE-M-V-T/R](#)