

FEATURES

- ※ Compact size
- ※ Two-way operation
- ※ Halogen Free


APPLICATION

- ※ Digital camera
- ※ Notebook
- ※ Automotive

SPECIFICATION

Contact Rating	50μA, 3V DC min. 1mA, 5V DC max.
Contact Resistance	2Ω max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	100V AC/1 minute
Operating Force	35gf max.
Travel	1.15mm
Operating Life	50,000 cycles
Operating Temp.	-10°C ~ +60°C
Storage Temp.	-40°C ~ +85°C


CIRCUIT

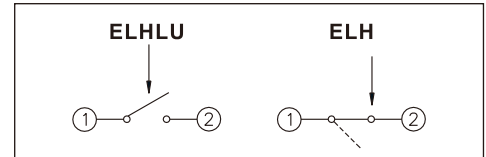


PACKAGE

<Tape & Reel>
3500 pcs

HOW TO ORDER

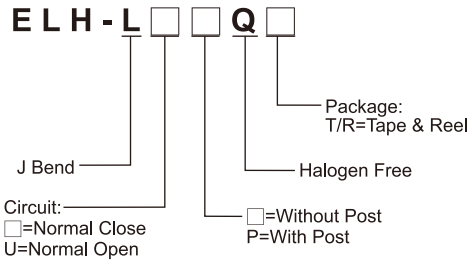

ELH

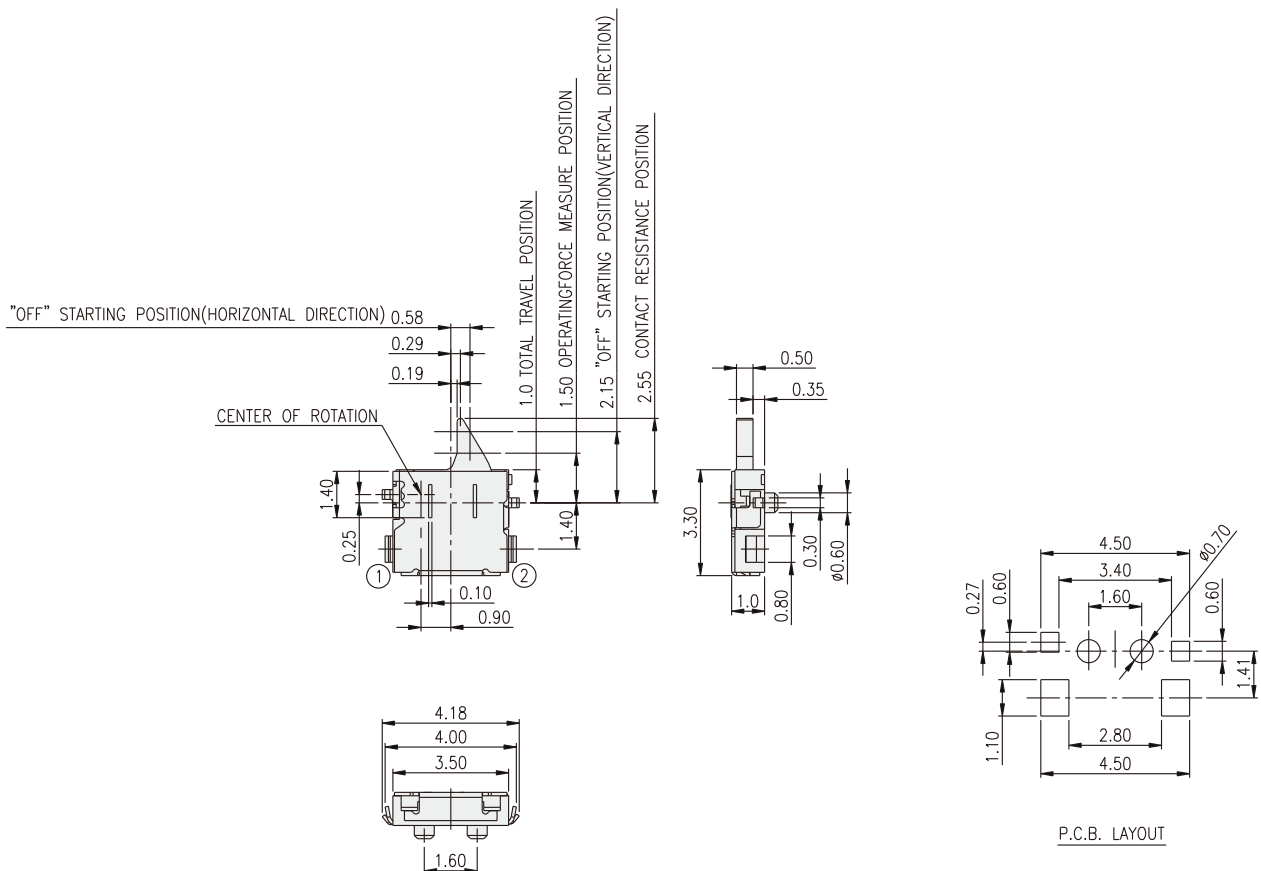

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[ELH-L-Q-T/R](#) [ELH-L-P-Q-T/R](#)