**FEATURES**

- ※Low profile
- ※Mode switching with maximum 8-direction
- ※Non-click structure applicable

APPLICATION

- ※Thermal controller
- ※Camera
- ※Audio

SPECIFICATION

Contact Rating	25mA, 24V DC
Contact Resistance	200mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	300V AC/1 minute
Operating Force	40±30gf, B 130±50gf, N
Operating Life	10,000 cycles
Operating Temp.	-25°C ~ +80°C
Storage Temp.	-40°C ~ +85°C

HOW TO ORDER**S R M - 8 R**

8 Direction

Circuit:

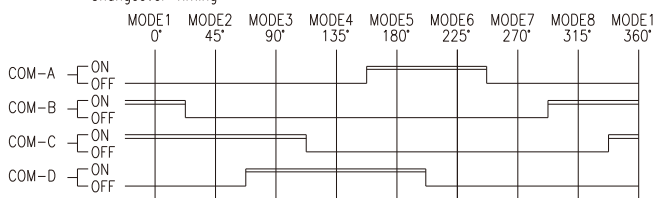
7=7 Circuit, Base: Black
8=8 Circuit, Base: Brown□=Without Ground Pin
G=With Ground PinPackage:
T/R=Tape & Reel□=Non-click, Black
B=40gf, Blue
N=130gf, Brown**PACKAGE**

<Tape & Reel>

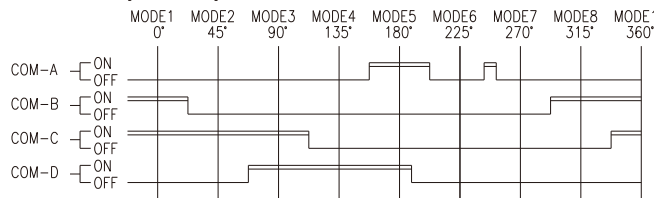
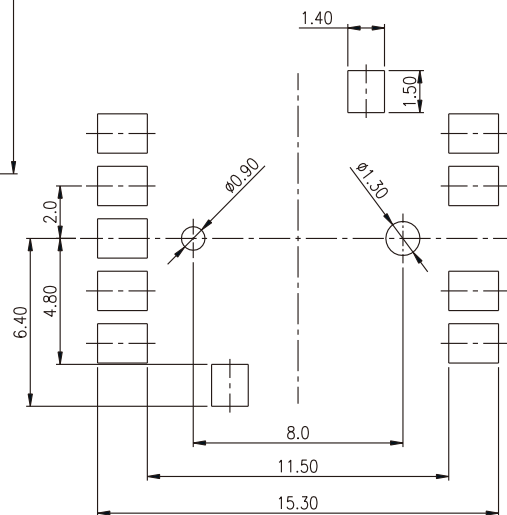
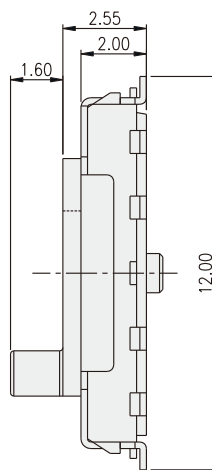
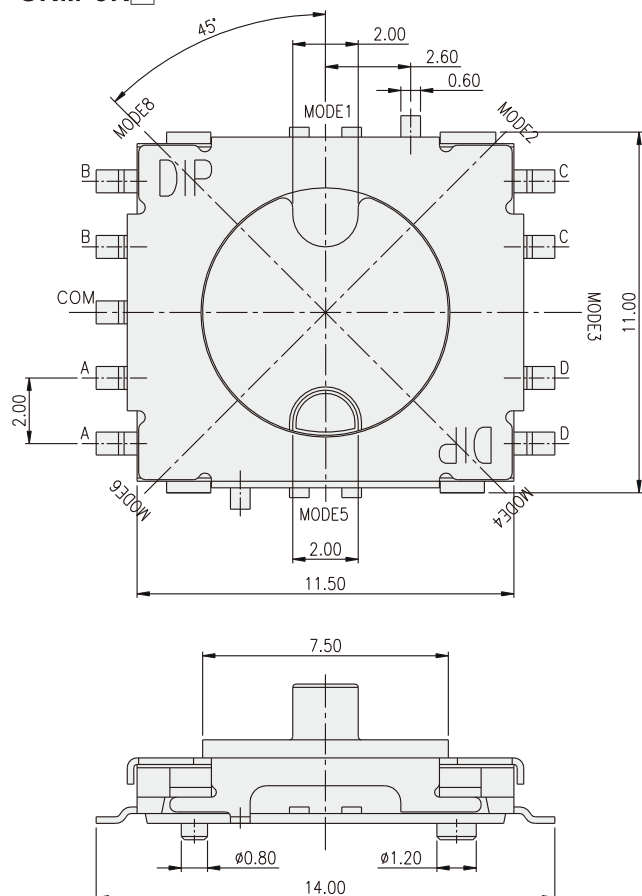
900 pcs

CIRCUIT**SRM-8R7**

Changeover Timing

**SRM-8R8**

Changeover Timing

**SRM-8R□**

P.C.B. LAYOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[SRM-8R8GN-V-T/R](#)