


# MULTI FUNCTION SWITCH MT(4)(5) SERIES

**Multi-direction  
Type**

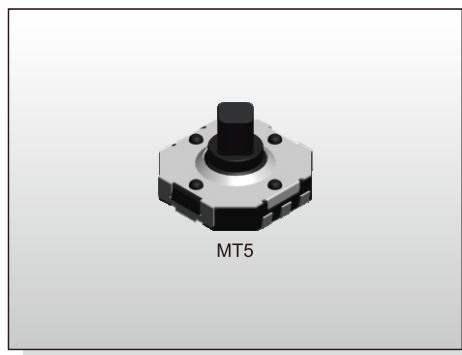

## FEATURES

- ※7.4x7.7mm
- ※Variety of height options
- ※Reflow solderable


## APPLICATION

- ※Medical device
- ※Consumer electronics
- ※Security device


## SPECIFICATION

Contact Rating	50mA, 12V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 100V DC
Dielectric Strength	250V AC/1 minute
Operating Force	160gf, 4-direction 360gf, Center push
Travel	0.25mm, 4-direction 0.15mm, Center push
Operating Life	100,000 cycles
Operating Temp.	-25°C ~ +70°C
Storage Temp.	-40°C ~ +85°C

## HOW TO ORDER

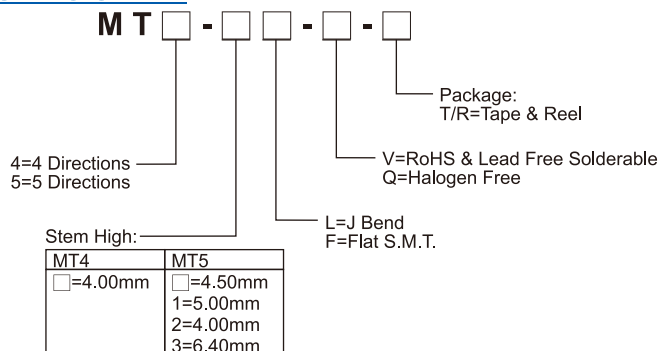

## CIRCUIT

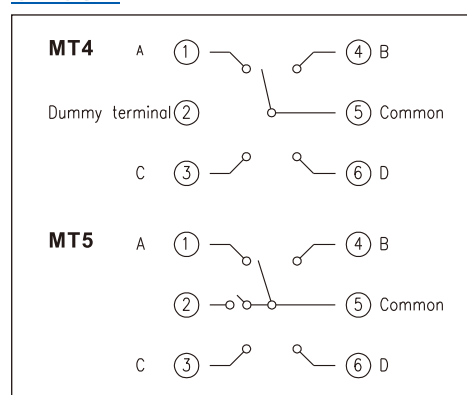


## PACKAGE

<Tape & Reel>


850 pcs

MT5-3☐: 800 pcs

## MT4-F

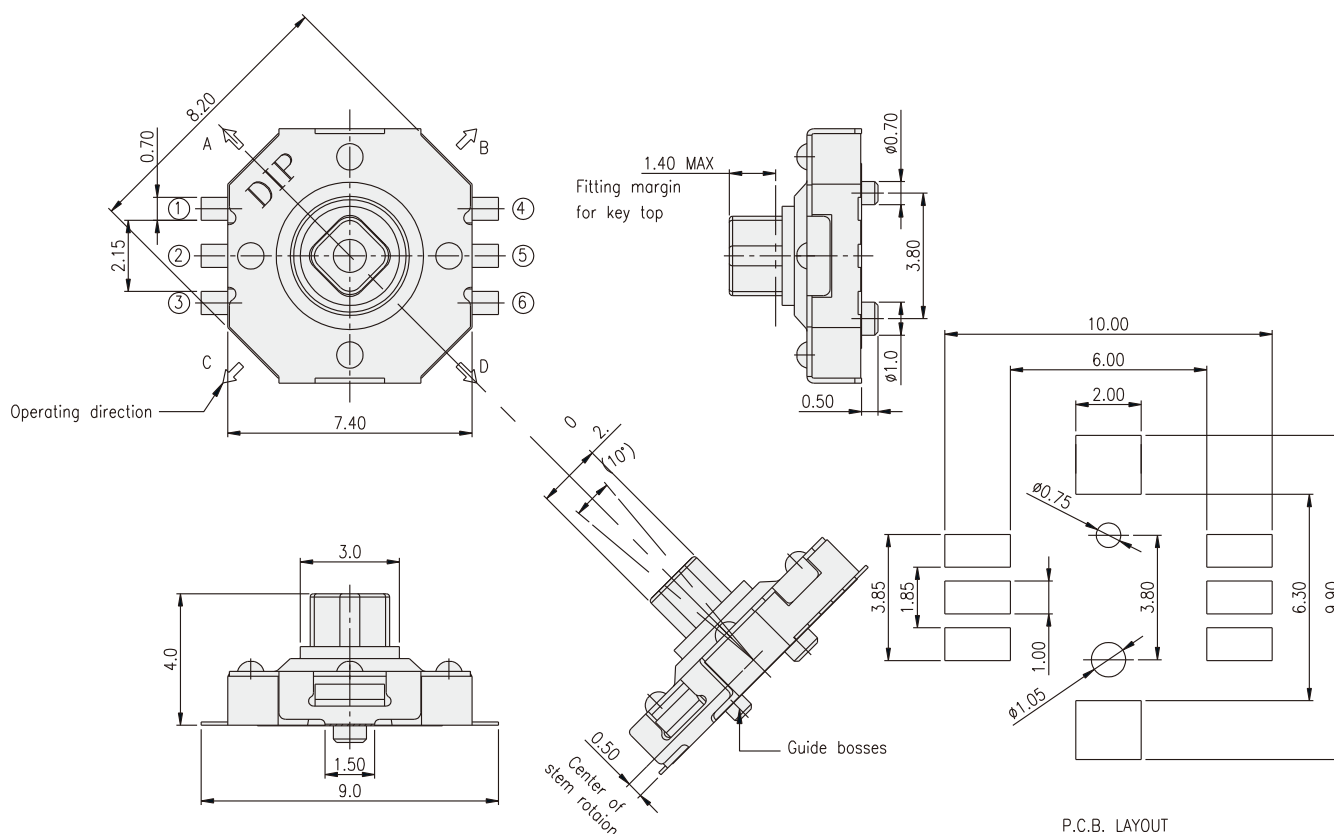

**MT5-L**

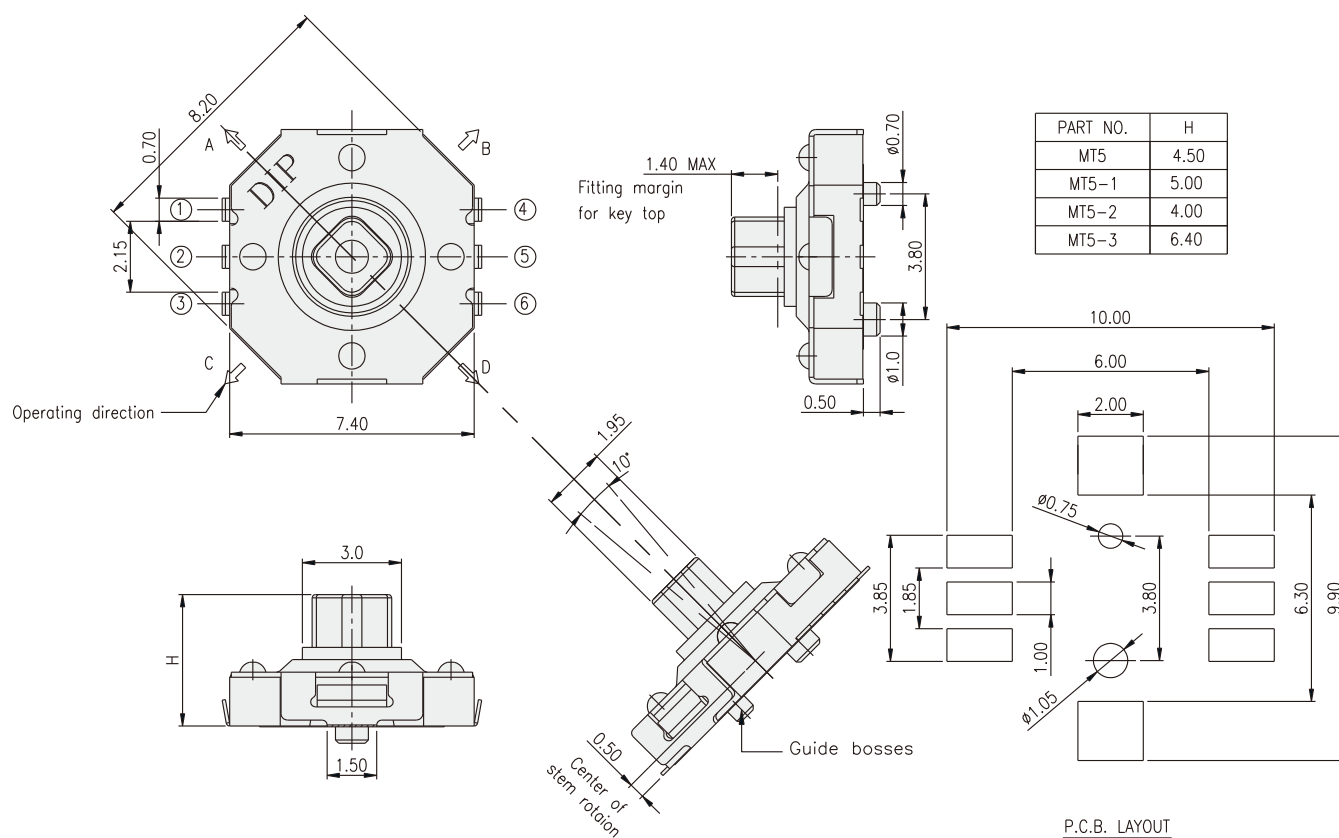

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[MT5-3L-V-T/R](#) [MT5-2L-V-T/R](#) [MT4-L-V-T/R](#) [MT5-F-V-T/R](#) [MT4-F-V-T/R](#) [MT5-1L-V-T/R](#) [MT5-L-V-T/R](#) [MT5-3F-V-T/R](#) [MT5-1F-V-T/R](#) [MT5-2F-V-T/R](#) [MT5-3F-Q-T/R](#)