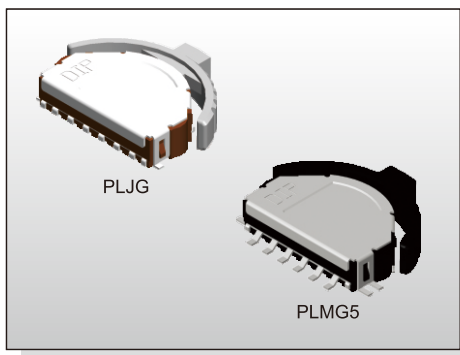
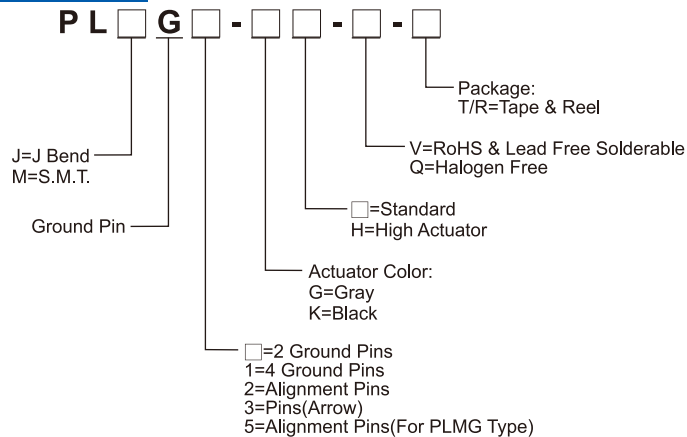
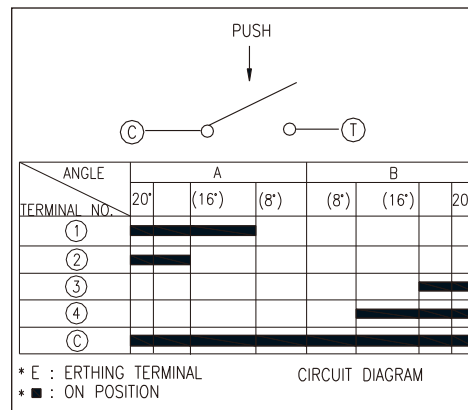


**FEATURES**

※Multi function (Push &amp; Lever)

**APPLICATION**
 ※Remote controls  
 ※Volume control for variety of applications
**SPECIFICATION**

|                       |                                                                  |
|-----------------------|------------------------------------------------------------------|
| Contact Rating        | 10mA, 5V DC                                                      |
| Contact Resistance    | 100mΩ max.                                                       |
| Insulation Resistance | 100MΩ min. 100V DC                                               |
| Dielectric Strength   | 100V AC/1 minute                                                 |
| Operating Force       | 40±20gf, Return actuator<br>150+100/-50gf, Center push direction |
| Operating Life        | 100,000 cycles                                                   |
| Operating Temp.       | -10°C ~ +70°C                                                    |
| Storage Temp.         | -25°C ~ +85°C                                                    |


**HOW TO ORDER****CIRCUIT****PACKAGE**

## &lt;Tape &amp; Reel&gt;


PLJ(G), PLJG1: 1000 pcs

PLJG(2)(3): 800 pcs


PLMG5: 750 pcs

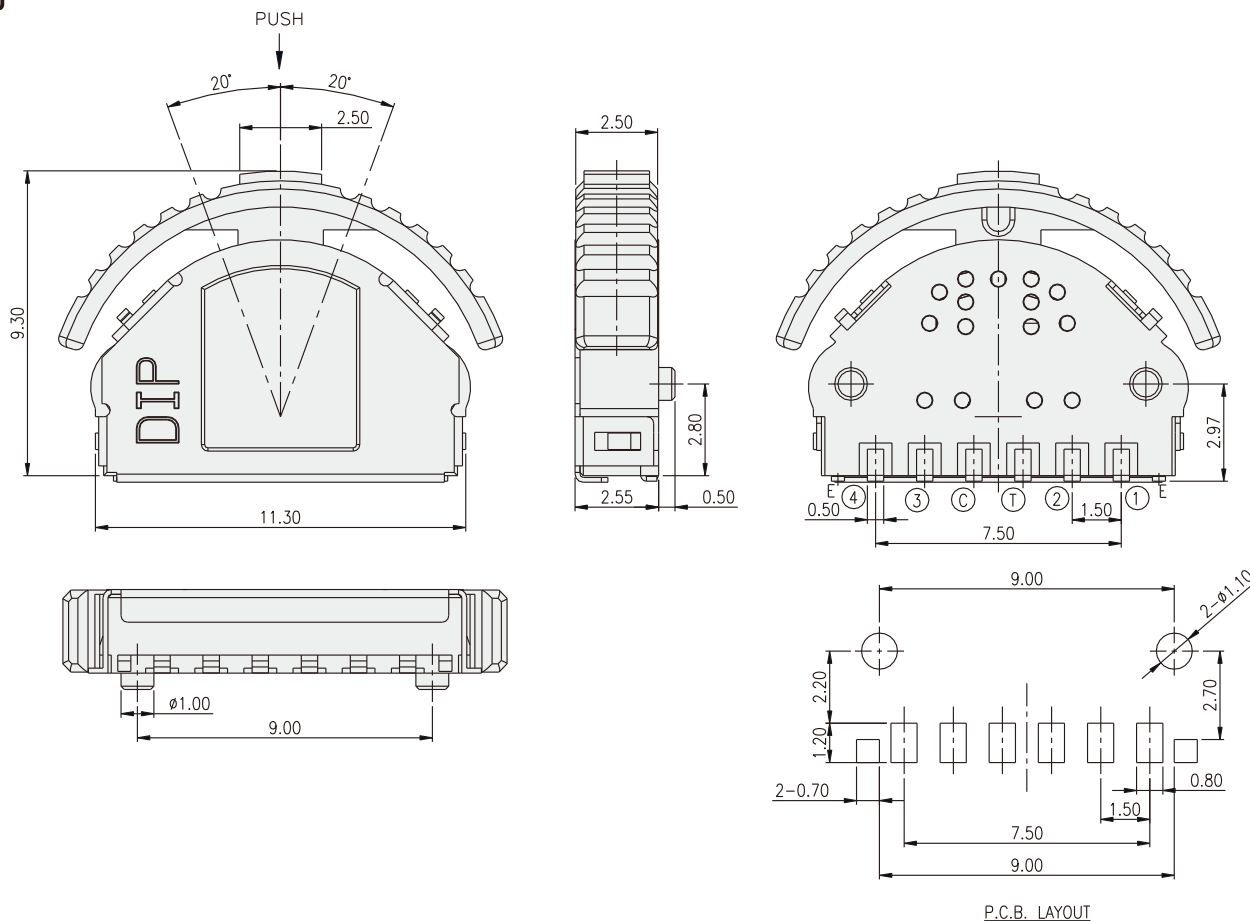**PLJ**


**PLJG**

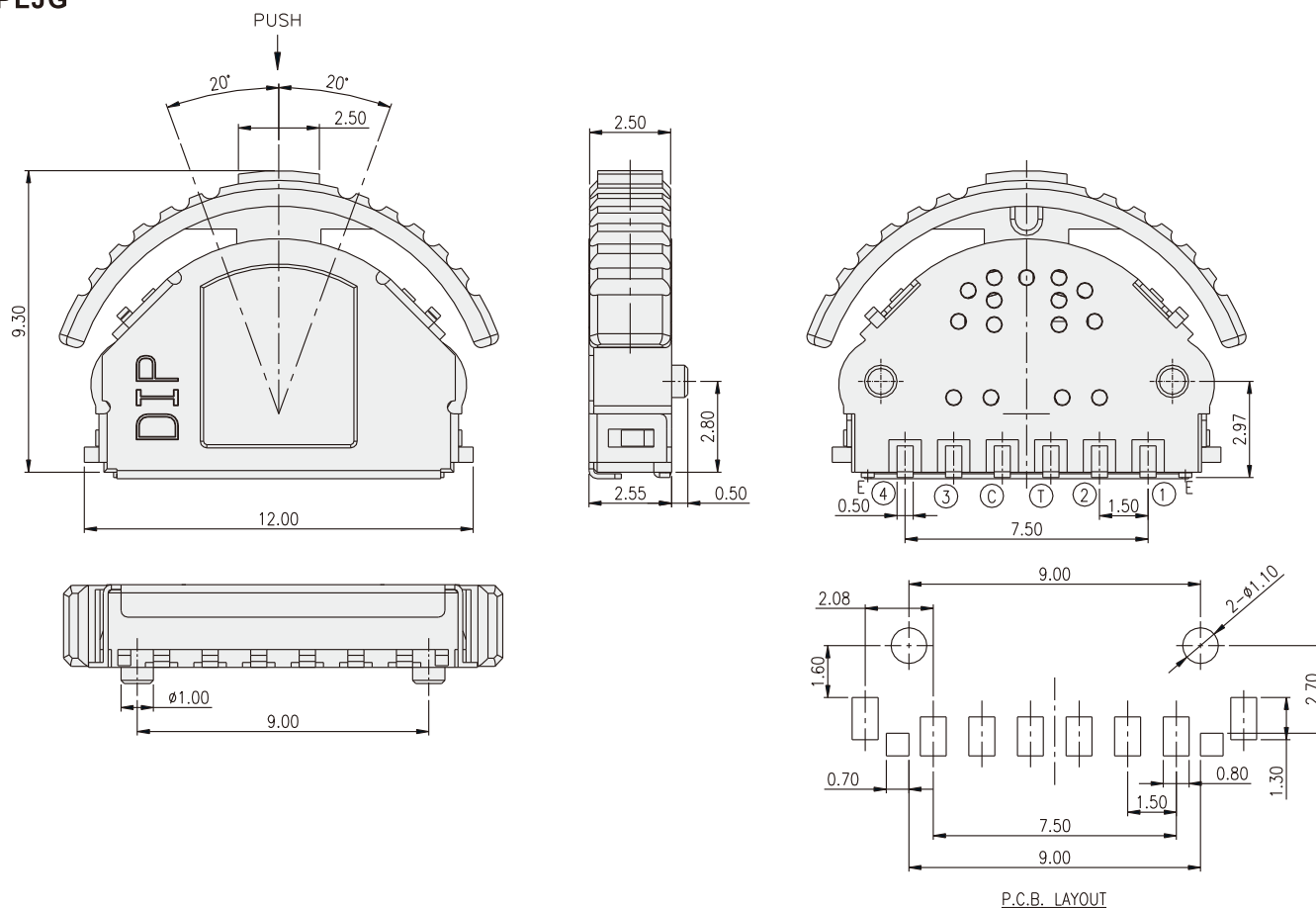


**PLJG1**

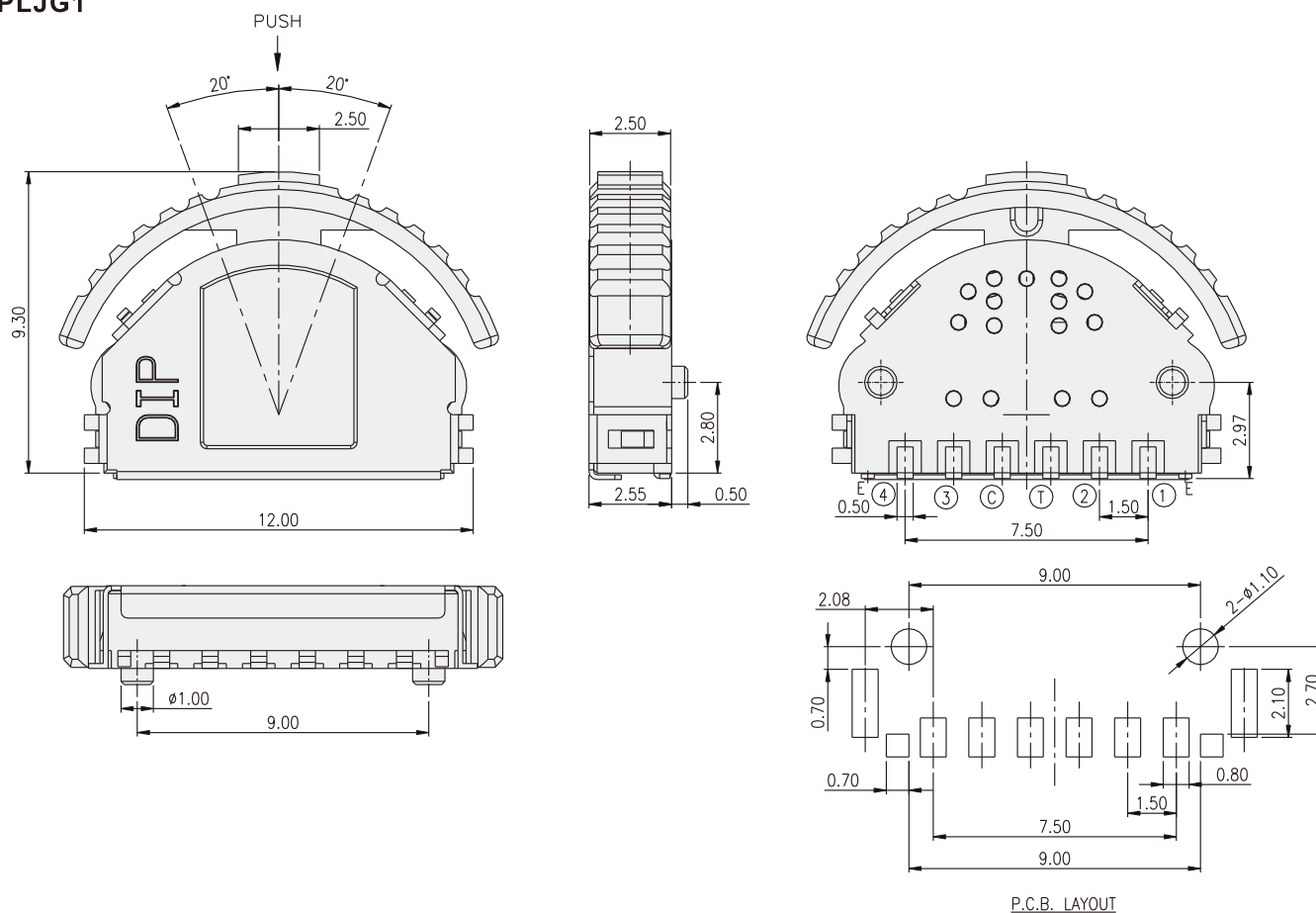


**PLJG□-H**

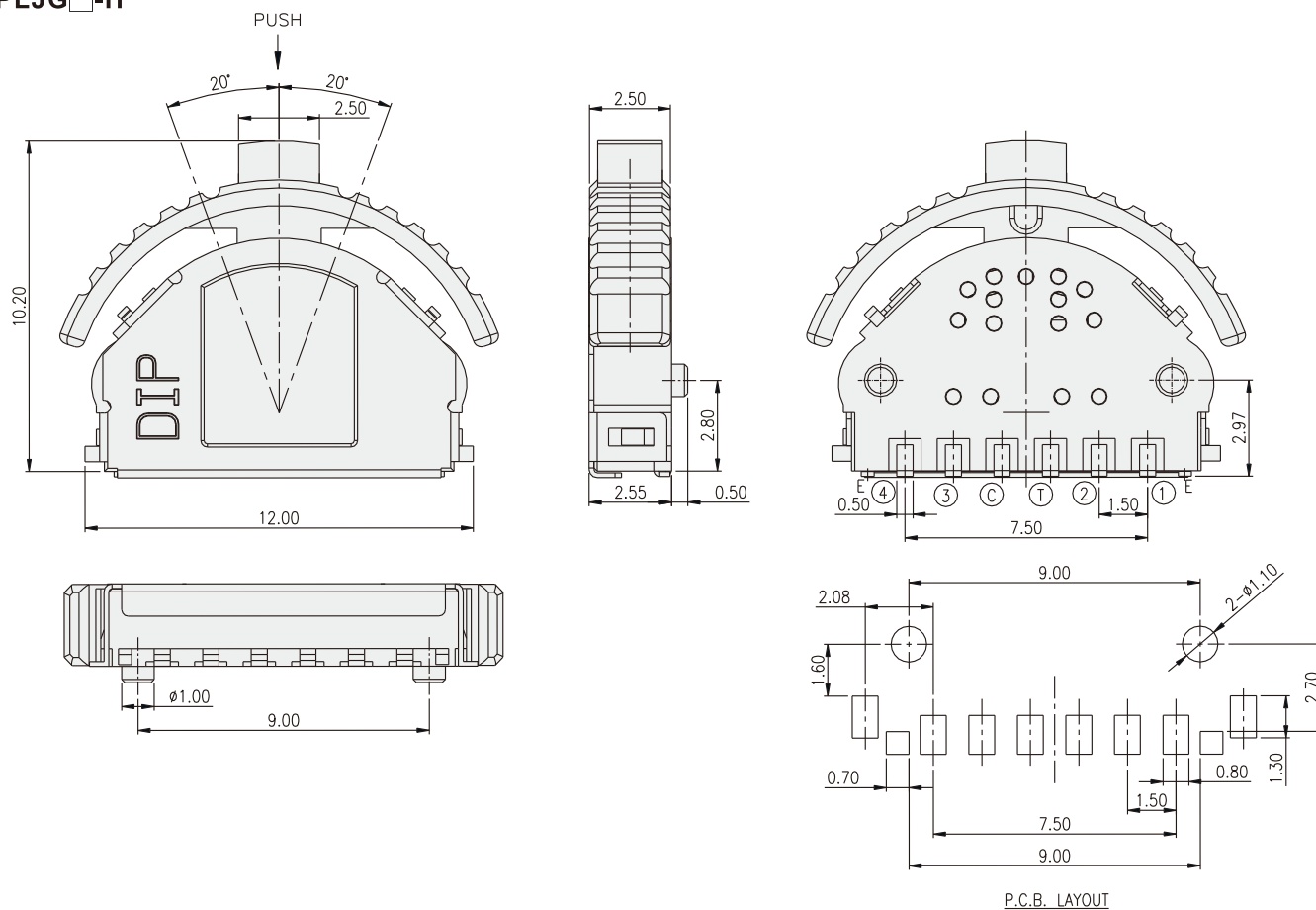


**PLJG2**

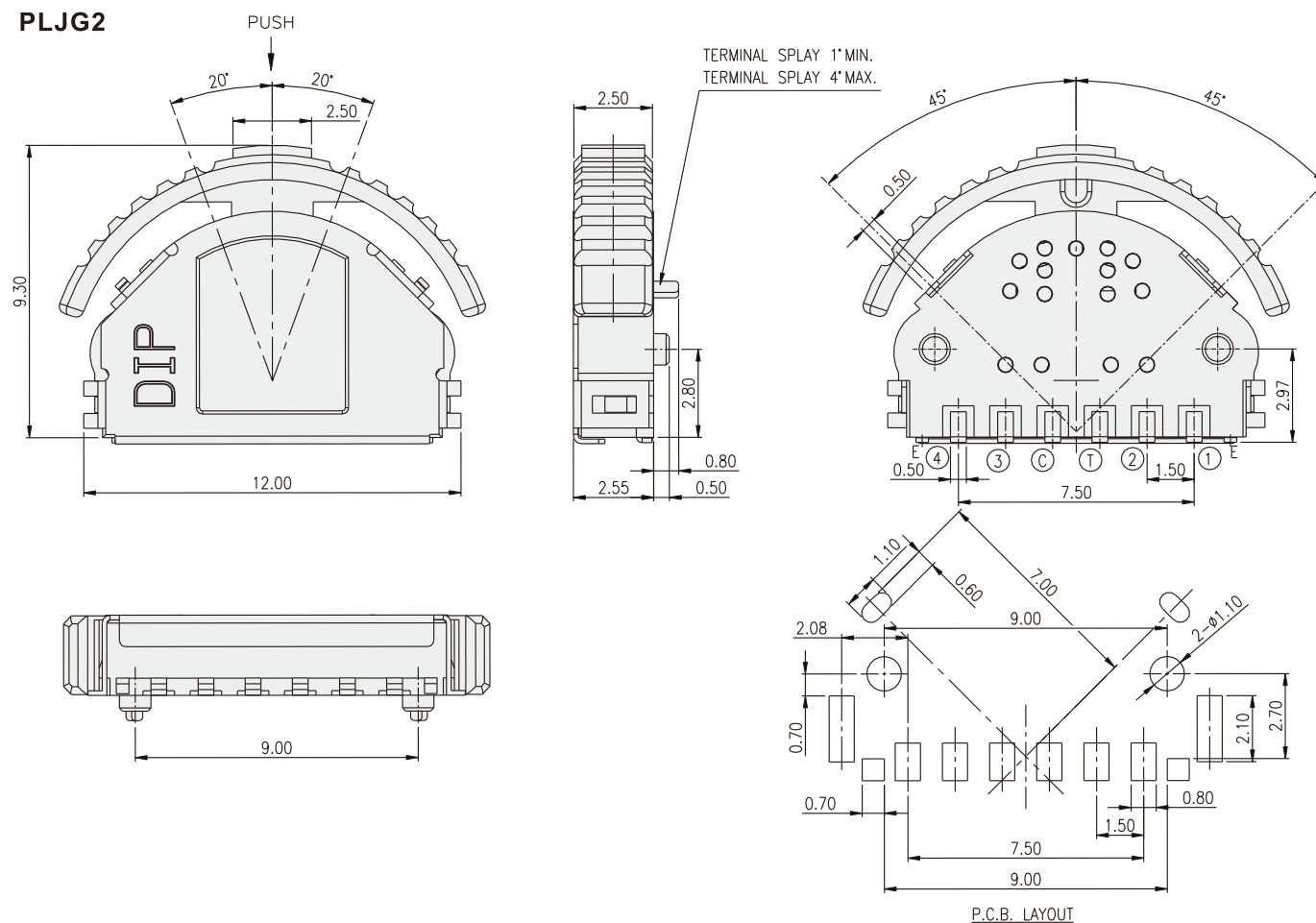

**PLJG3**

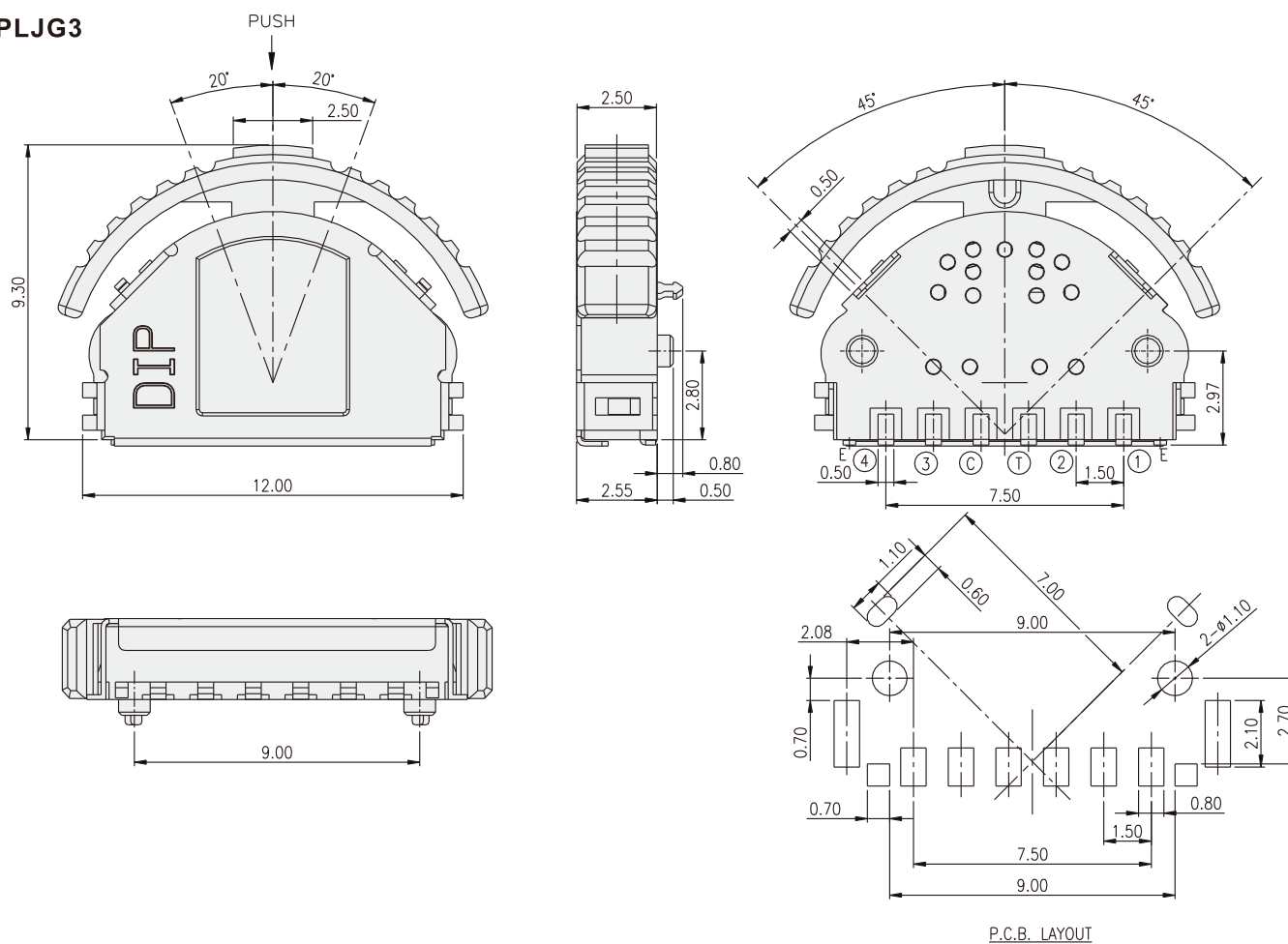

**PLMG5-H**

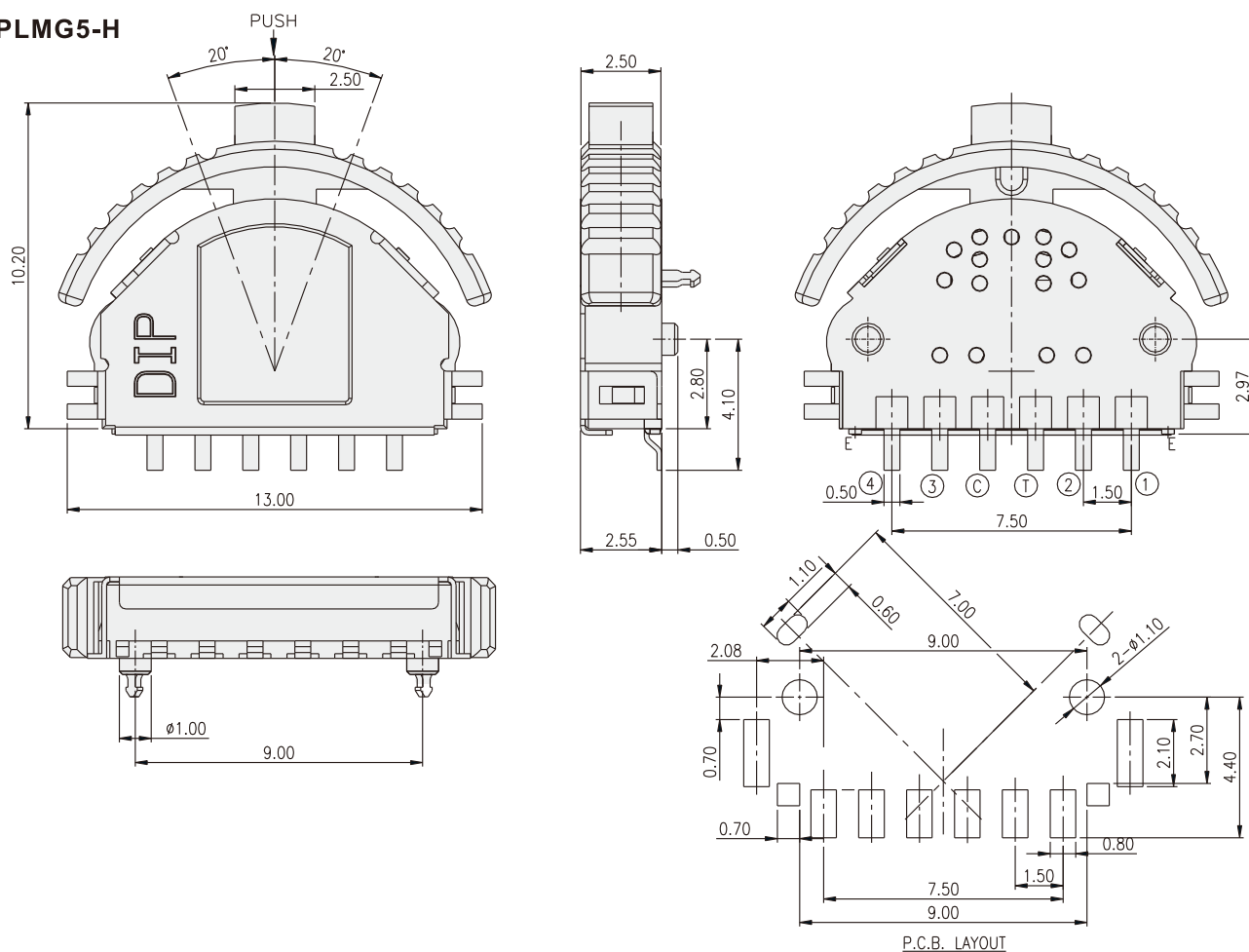

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Diptronics:

[PLJG3-G-V-T/R](#) [PLJG1-G-V-T/R](#) [PLMG5-GH-V-T/R](#) [PLJG-G-V-T/R](#) [PLJG2-G-V-T/R](#) [PLJG1-GH-V-T/R](#) [PLJG3-KH-V-T/R](#) [PLJG3-K-V-T/R](#) [PLJG-GH-V-T/R](#) [PLJG-KH-V-T/R](#) [PLJG-K-V-T/R](#) [PLJG1-KH-V-T/R](#) [PLJG1-K-V-T/R](#) [PLJG2-GH-V-T/R](#) [PLJG2-KH-V-T/R](#) [PLJG2-K-V-T/R](#) [PLJG3-GH-V-T/R](#)