


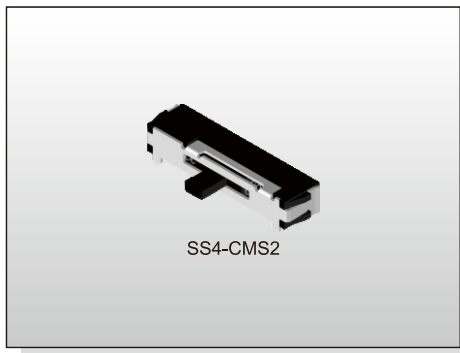

SS4-CMS2

FEATURES

- ※2.0mm height
- ※1P3T model
- ※Reflow solderable


APPLICATION

- ※Remote control
- ※Consumer electronics
- ※Instrumentations


SPECIFICATION

Contact Rating	25mA, 24V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	500V AC/1 minute
Operating Force	100gf min./350gf max.(Detent Type) 150±100gf (Recoil Type)
Travel	2mm
Operating Life	10,000 cycles
Operating Temp.	-20°C ~ +70°C
Storage Temp.	-40°C ~ +85°C

HOW TO ORDER

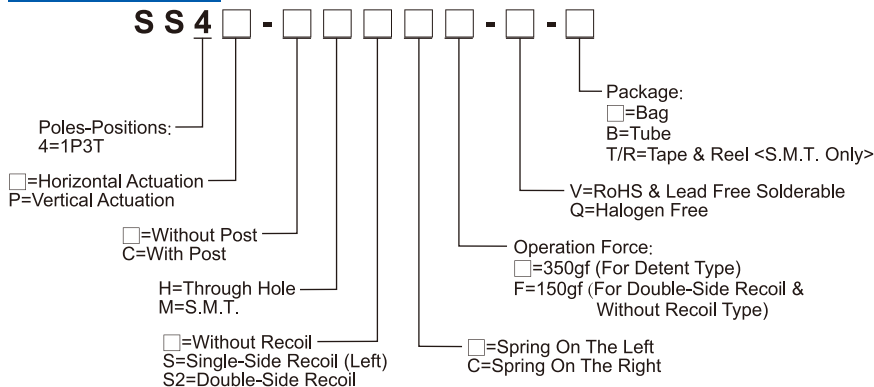


CIRCUIT

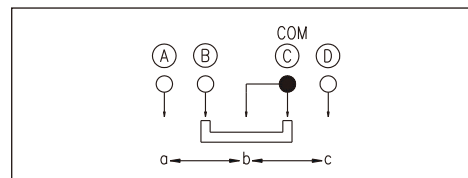


PACKAGE

- <Bag>
1500 pcs
- <Tube>
38 pcs
- <Tape & Reel>
1900 pcs


SS4-H

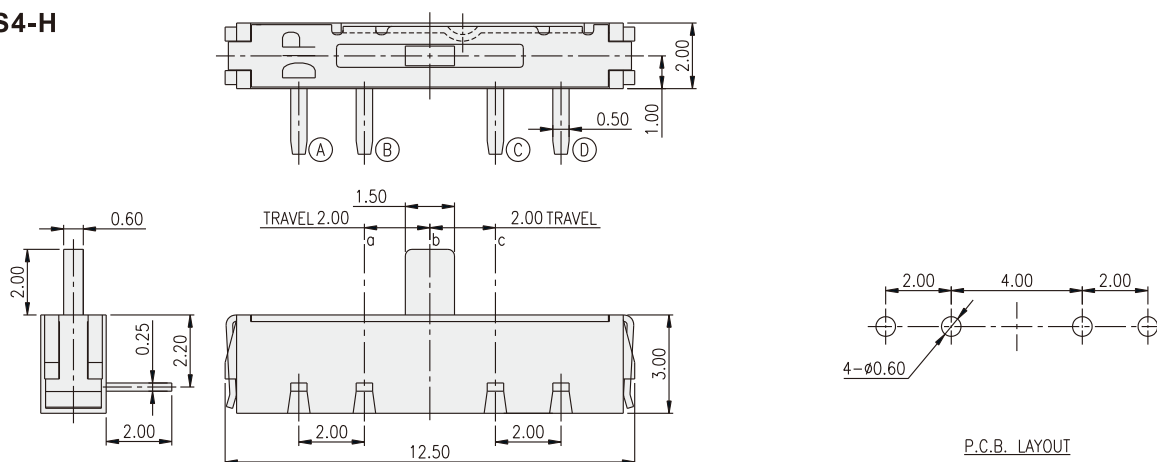


SS4-CMS

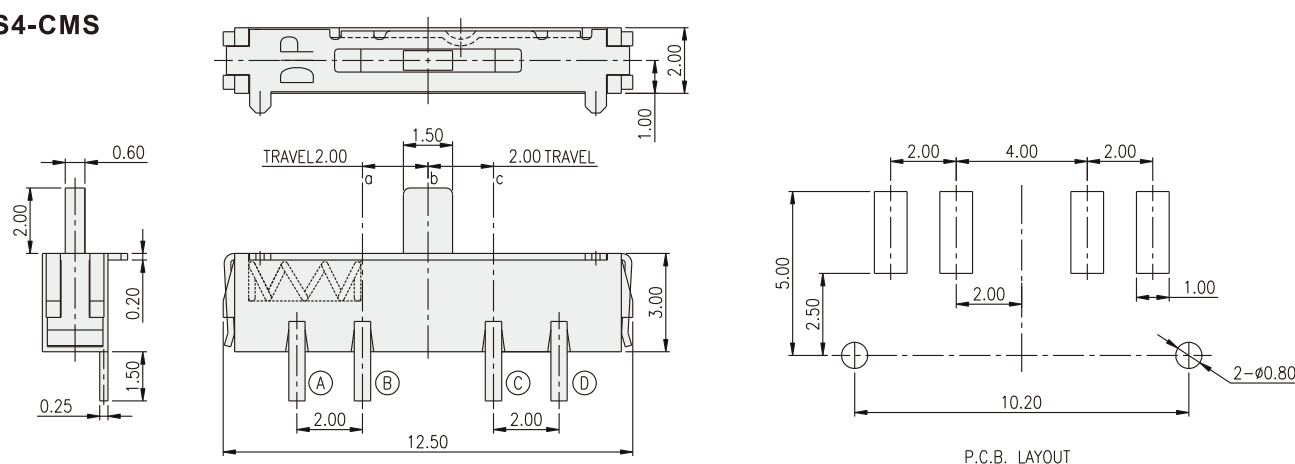

SS4P-HS2

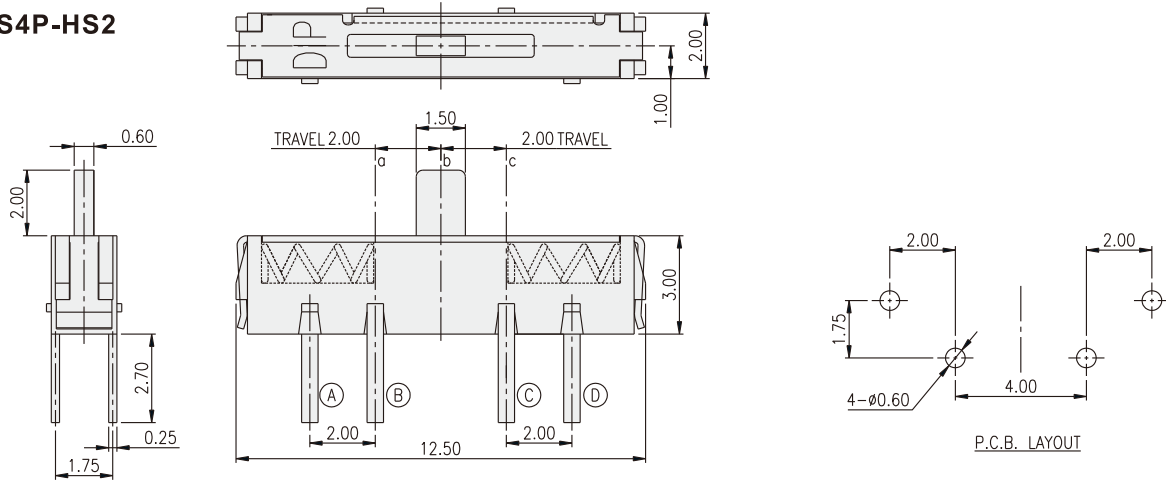

SS4-CM

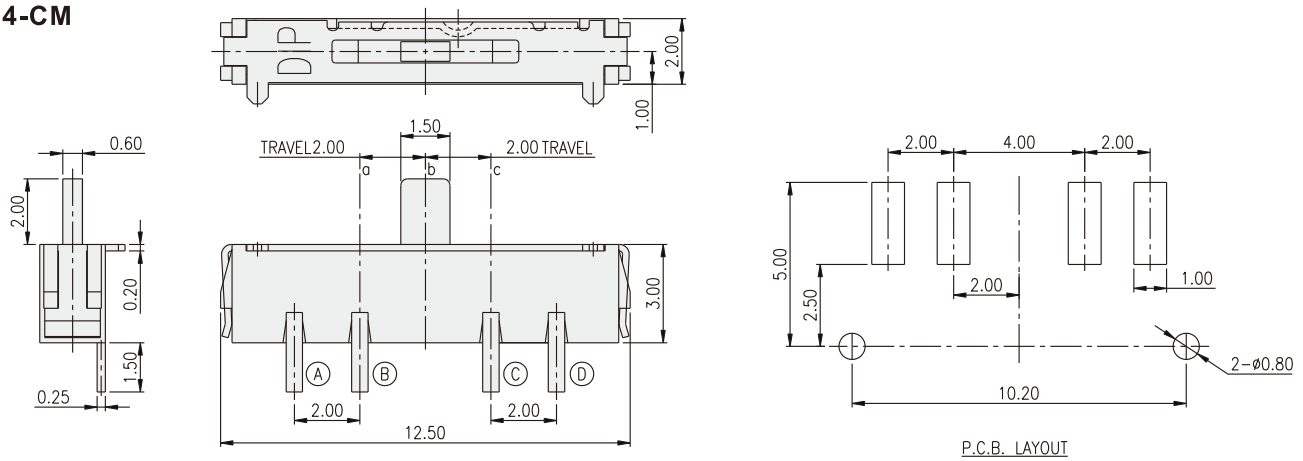

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[SS4-H-V-B](#) [SS4-CM-V-B](#) [SS4P-HS2-V-B](#) [SS4-CM-V-T/R](#) [SS4-CMS-V-T/R](#) [SS4-CMS2-V-B](#) [SS4P-H-V-B](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[SS4-\(C\)MS2-V-T/R](#) [SS4-\(C\)HS2-V-B](#) [SS4-\(C\)HS-V-B](#) [SS4-\(C\)H-V-B](#) [SS4-CHS2VB](#) [SS4-CHSVB](#) [SS4-CHVB](#) [SS4-CMS2VTR](#) [SS4-CMSC-V-T/R](#)