


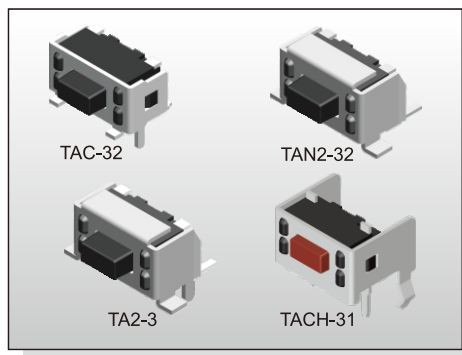

FEATURES

- ※Side actuated
- ※Support/Ground pin option
- ※High solder strength


APPLICATION

- ※Data storage, Server
- ※Instrumentation
- ※Audio, OA equipment


SPECIFICATION

Contact Rating	50mA, 12V DC		
Contact Resistance	100mΩ max.		
Insulation Resistance	100MΩ min. 500V DC		
Dielectric Strength	250V AC/1 minute		
Operating Force	160±50gf, 260±50gf	TAC-3	
	160±50gf, White(W)		
	160±50gf, Brown(N)	TA2-3	
	320±50gf, Salmon(S)		
Travel	0.25mm		
Operating Life	50,000 cycles		
Operating Temp.	-25°C ~ +70°C		
Storage Temp.	-40°C ~ +80°C		

HOW TO ORDER

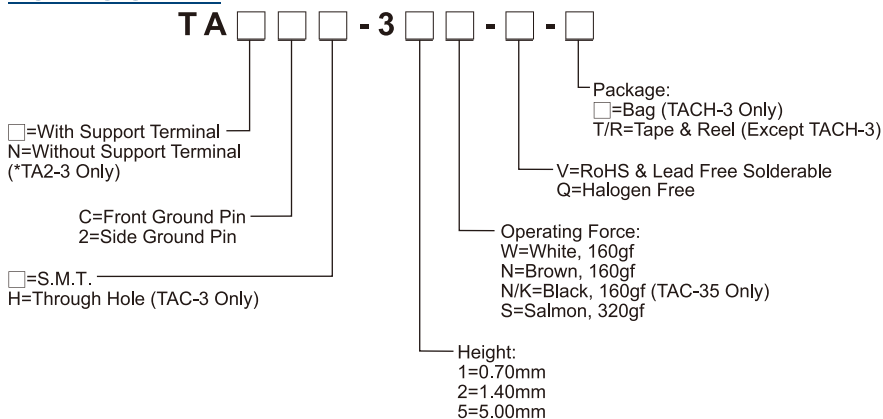




CIRCUIT

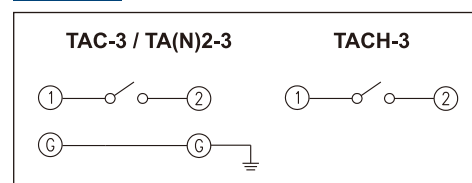


PACKAGE

<Bag>
500 pcs(TACH-3 Only)
<Tape & Reel>
900 pcs

TAC-3

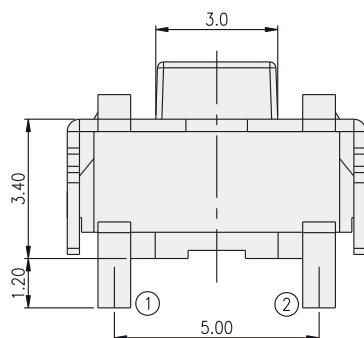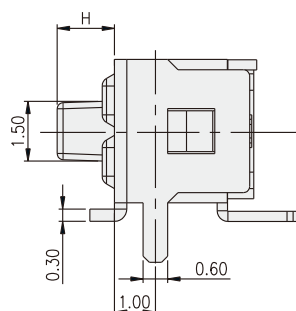
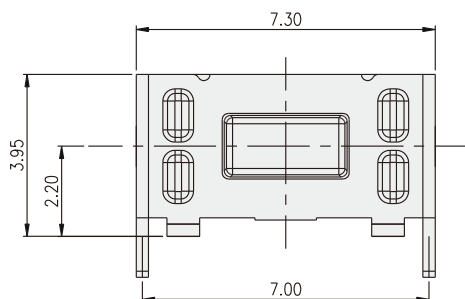


PART NO.	H
TAC-31	0.70
TAC-32	1.40
TAC-35	5.00

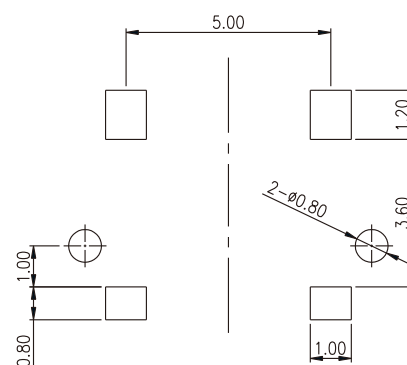


P.C.B. LAYOUT

TA2-3

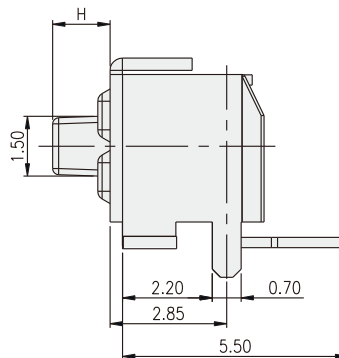
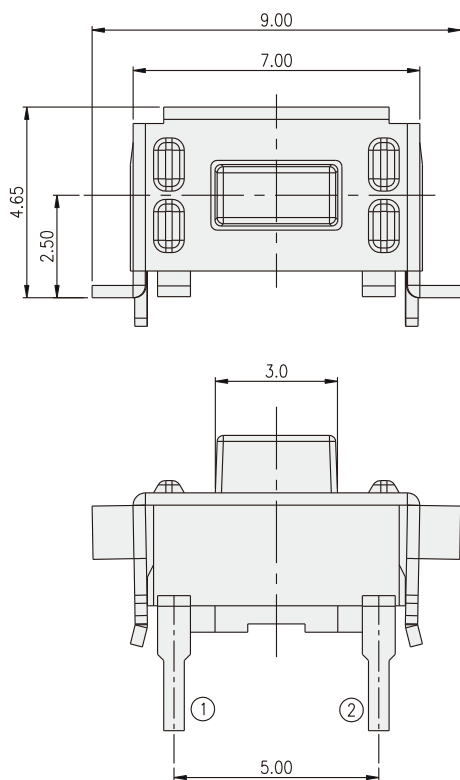


PART NO.	H
TA2-31	0.70
TA2-32	1.40
TA2-35	5.00

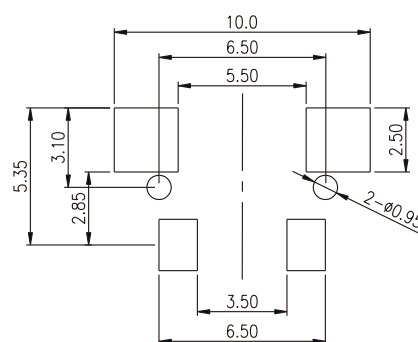


P.C.B. LAYOUT

TAN2-3

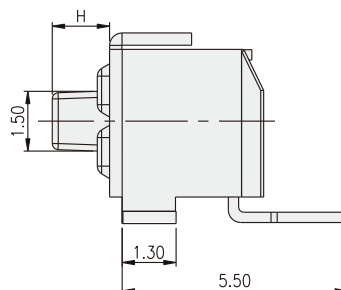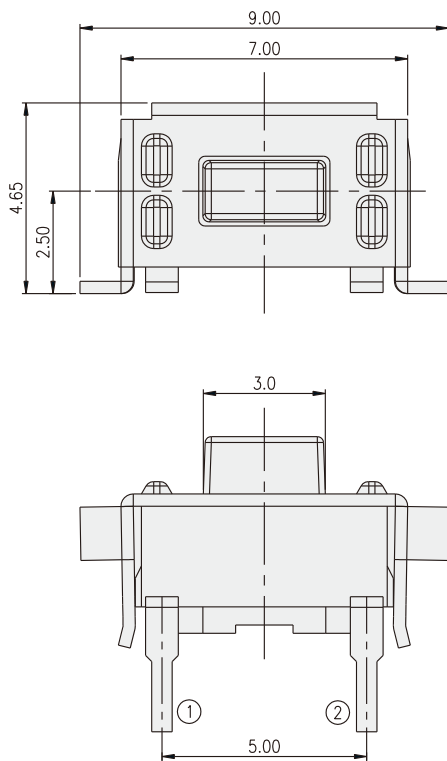


PART NO.	H
TAN2-31	0.70
TAN2-32	1.40
TAN2-35	5.00



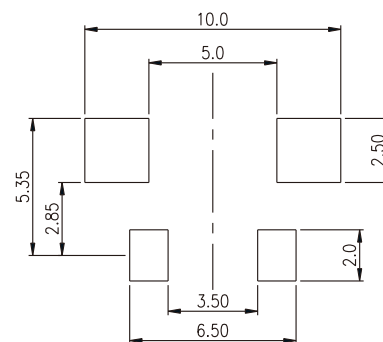


P.C.B. LAYOUT

TACH-3

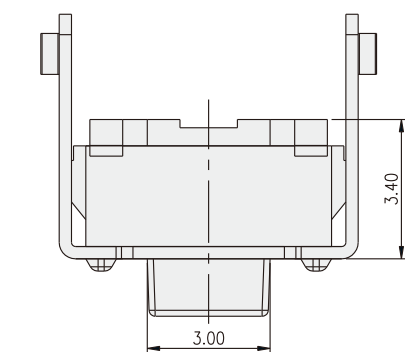

PART NO.	H	L
TACH-31	0.70	3.15
TACH-32	1.40	3.85
TACH-35	5.00	7.45

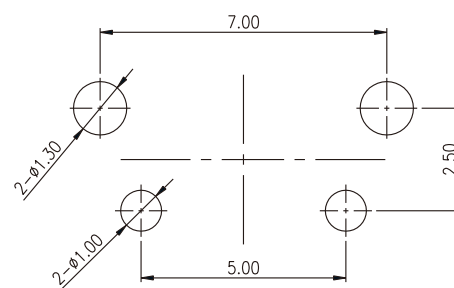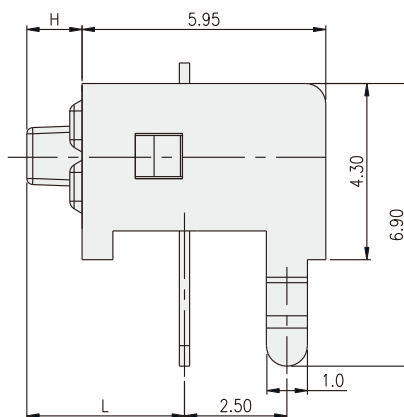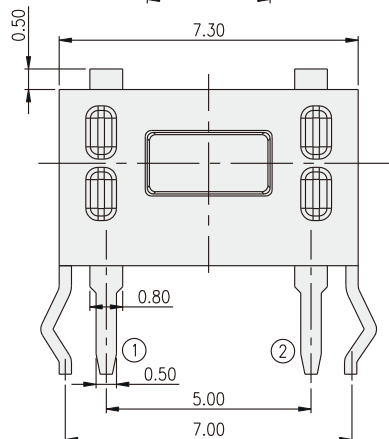

P.C.B. LAYOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[TA2-32W-V-T/R](#) [TAC-35S-V-T/R](#) [TAC-32S-V-T/R](#) [TA2-32N-V-T/R](#) [TAC-31N-V-T/R](#) [TA2-31N-V-T/R](#) [TACH-35N-Q](#)
[TAN2-35N-V-T/R](#) [TACH-31N-V](#) [TA2-35N-V-T/R](#) [TAC-35N-V-T/R](#) [TAN2-32N-Q-T/R](#) [TA2-32S-V-T/R](#) [TAC-35W-V-T/R](#)
[TACH-32N-Q](#) [TAC-32W-V-T/R](#) [TA2-31W-V-T/R](#) [TA2-31S-V-T/R](#) [TAC-32N-V-T/R](#) [TAN2-32S-V-T/R](#) [TAN2-32W-V-](#)
[T/R](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[TAN2-31S-V-T/R](#) [TAN2-31W-V-T/R](#)