

FEATURES

- ※4.7mm height
- ※A sharp click feeling
- ※10,000 operation life cycles

APPLICATION

- ※Portable audio
- ※Instrumentation
- ※Radio cassette

SPECIFICATION

Contact Rating	0.1A, 12V DC
Contact Resistance	20mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	500V AC/1 minute
Operating Force	200±150gf
Travel	2mm
Operating Life	10,000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-20°C ~ +60°C

HOW TO ORDER

S L 6 N C H V R

Poles-Positions:
2P2T

Timing:
Non-Shorting


Package:
Tape & Reel

RoHS & Lead Free Solderable

Through Hole

With Post


CIRCUIT

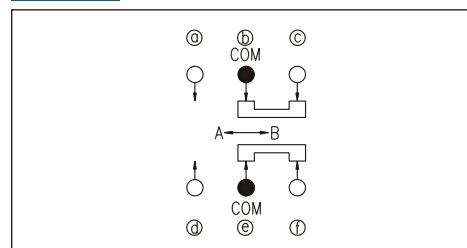

PACKAGE

<Tape & Reel>
300 pcs

SL6

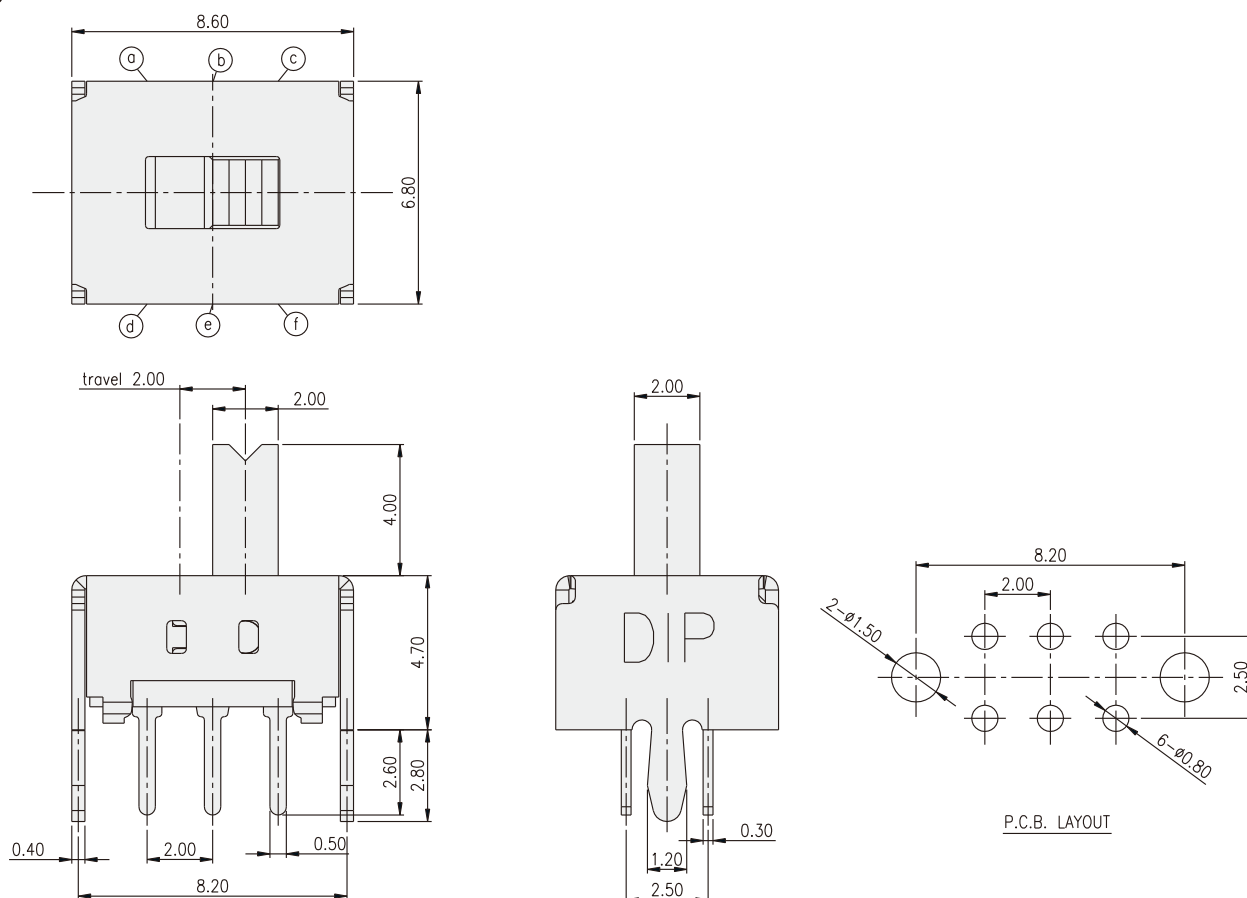

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

SL6NCHVR