


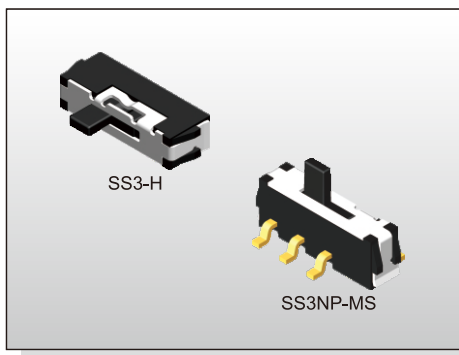

FEATURES

- ※2.0mm height
- ※1P2T model
- ※Reflow solderable


APPLICATION

- ※Remote control
- ※Consumer electronics
- ※Instrumentations


SPECIFICATION

Contact Rating	25mA, 24V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	500V AC/1 minute
Operating Force	100gf min./350gf max.(Detent Type) 150±100gf(Recoil Type)
Travel	2mm
Operating Life	10,000 cycles
Operating Temp.	-20°C ~ +70°C
Storage Temp.	-40°C ~ +85°C

HOW TO ORDER

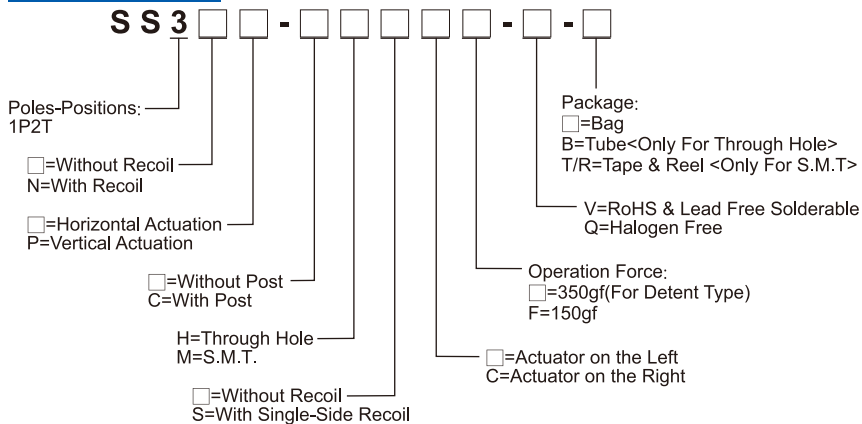


CIRCUIT

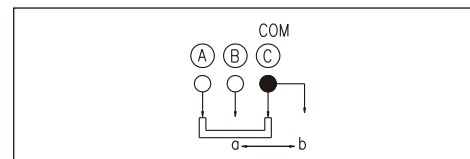


PACKAGE

- <Bag>
2000 pcs
- <Tube>
53 pcs
- <Tape & Reel>
SS3-CM: 1900 pcs
SS3NP: 1000 pcs


SS3-H

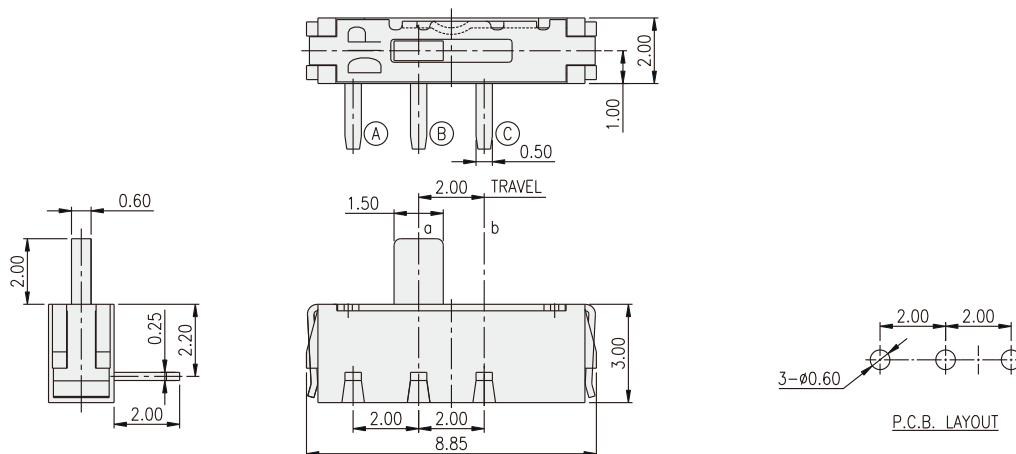


SS3N-MS

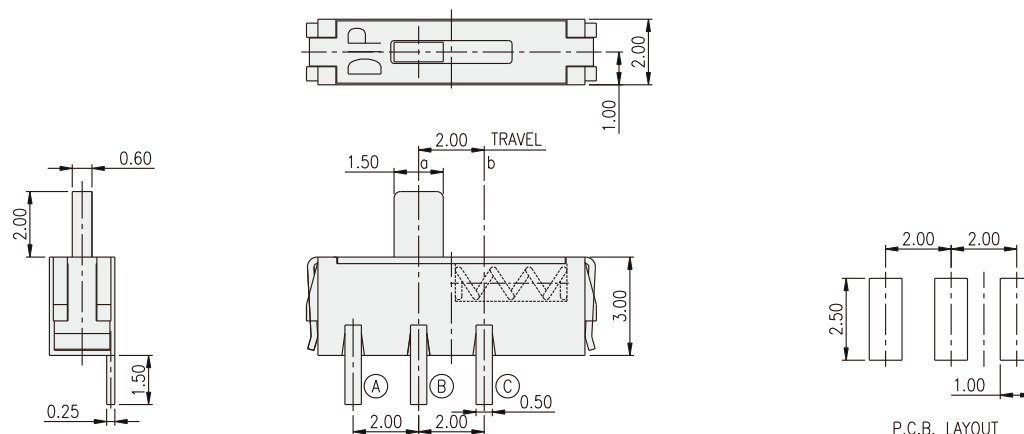


SS3NP-MS

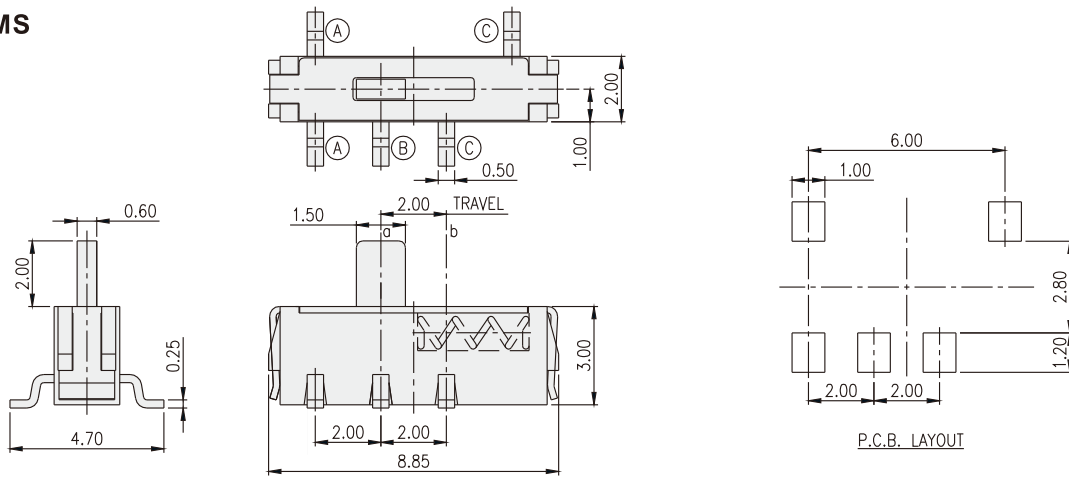

SS3P-H

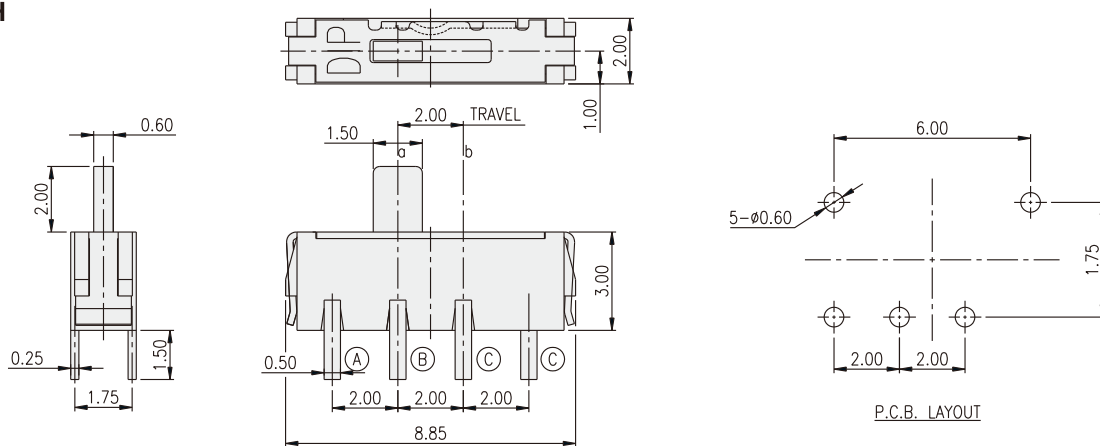

SS3-CM

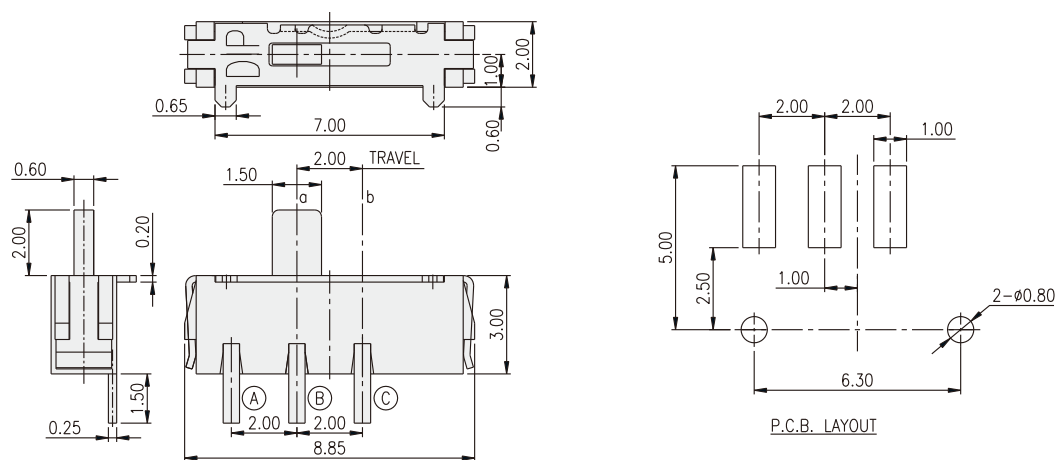

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Diptronics:

[SS3N-CHSC-V-B](#) [SS3NP-H-V](#) [SS3NP-M-V-T/R](#) [SS3-HSC-V](#) [SS3P-CMSCF-V](#) [SS3N-CMS-V-T/R](#) [SS3NP-HSC-V-B](#)
[SS3P-CMF-V-T/R](#) [SS3N-MCF-V](#) [SS3P-HS-V](#) [SS3-HS-V-B](#) [SS3-MS-V](#) [SS3N-CHSCF-V-B](#) [SS3NP-CHSC-V-B](#)
[SS3NP-CHSCF-V-B](#) [SS3-HC-V](#) [SS3P-MF-V-T/R](#) [SS3N-CMF-V-T/R](#) [SS3N-HCF-V](#) [SS3NP-MSF-V](#) [SS3NP-HC-V](#)
[SS3P-CH-V](#) [SS3P-CMSCF-V-T/R](#) [SS3NP-CMSF-V-T/R](#) [SS3NP-HS-V](#) [SS3-CMF-V](#) [SS3P-HF-V-B](#) [SS3NP-CHCF-V](#)
[SS3-M-V](#) [SS3-CMS-V](#) [SS3N-HC-V](#) [SS3NP-CMSCF-V](#) [SS3P-HSC-V-B](#) [SS3P-CMSC-V](#) [SS3P-CHCF-V-B](#) [SS3P-](#)
[CHSCF-V-B](#) [SS3NP-CHF-V](#) [SS3NP-CMF-V-T/R](#) [SS3N-HSF-V](#) [SS3N-CMSC-V-T/R](#) [SS3NP-CHSCF-V](#) [SS3P-MS-V-](#)
[T/R](#) [SS3NP-CHCF-V-B](#) [SS3-CHF-V](#) [SS3-CHSC-V-B](#) [SS3P-CMSF-V](#) [SS3-CHSF-V](#) [SS3-MSCF-V-T/R](#) [SS3-MSF-V](#)
[SS3P-CHS-V-B](#) [SS3-MF-V](#) [SS3N-CM-V-T/R](#) [SS3N-CMSCF-V](#) [SS3NP-CM-V-T/R](#) [SS3NP-CHSF-V-B](#) [SS3-MSC-V-](#)
[T/R](#) [SS3P-CMC-V](#) [SS3N-CHSF-V](#) [SS3NP-CHS-V-B](#) [SS3NP-M-V](#) [SS3P-CMCF-V](#) [SS3-HSC-V-B](#) [SS3-CMC-V-T/R](#)
[SS3P-CMCF-V-T/R](#) [SS3-CHCF-V](#) [SS3NP-MSC-V](#) [SS3N-MC-V](#) [SS3P-CHSC-V-B](#) [SS3N-CMS-V](#) [SS3-CHCF-V-B](#)
[SS3NP-MCF-V](#) [SS3-CMSCF-V-T/R](#) [SS3N-CHF-V-B](#) [SS3NP-CMF-V](#) [SS3-CHSC-V](#) [SS3N-HF-V](#) [SS3N-CMC-V-T/R](#)
[SS3N-H-V-B](#) [SS3-HCF-V-B](#) [SS3P-CMS-V-T/R](#) [SS3NP-CMSF-V](#) [SS3-MSCF-V](#) [SS3P-CHSF-V](#) [SS3N-MSCF-V](#)
[SS3NP-HCF-V-B](#) [SS3P-CHF-V](#) [SS3NP-HC-V-B](#) [SS3-CMCF-V-T/R](#) [SS3P-HSCF-V](#) [SS3-CMSC-V-T/R](#) [SS3P-H-V](#)
[SS3N-CM-V](#) [SS3NP-MC-V-T/R](#) [SS3-CHSCF-V-B](#) [SS3P-CM-V](#) [SS3P-MSC-V-T/R](#) [SS3N-CMCF-V](#) [SS3P-MSF-V](#)
[SS3-HF-V](#) [SS3P-CHS-V](#)